


May not be suitable for all medical and aerospace applications.

Specifications: Contact Mallory Sonalert to discuss your application.

Impedance (Ω)	25 $\pm$ 15% at 1000 Hz at 1.0 V
Rated Power (W)	0.2
Max Power (W)	0.5
Frequency Range (Hz)	Fo ~ 12000
Resonance Freq Fo (Hz)	350 $\pm$ 20% at 1.0V
Output S.P.L. (dB)	92 $\pm$ 3 at 0.2w/.1m 1.0k, 1.2k, 1.5k, 2.0kHz 79 $\pm$ 3 at 1w/1m 1.0k, 1.2k, 1.5k, 2.0kHz
Magnet	Nd-Fe-B
Frame Material	ABS (Black)
Operating Temp	-20 to 50°C
Weight (g)	11.0
Options	For other options contact factory

Dimensions: ± 0.5 (units: mm)

ROHS Compliant

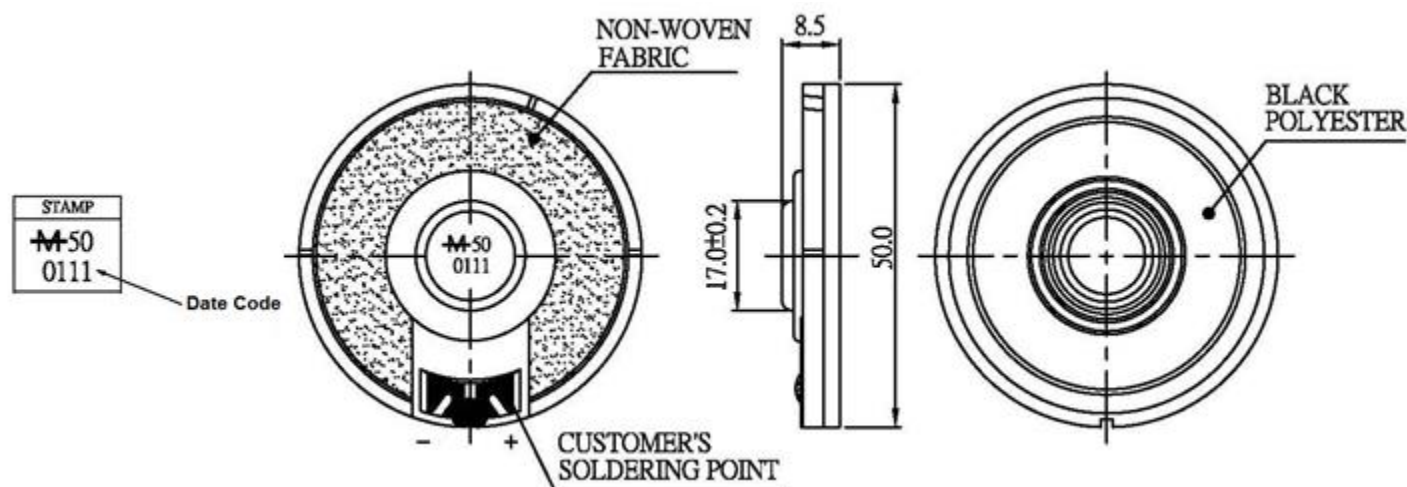

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Mallory Sonalert:](#)

[PSR50F25SK](#)