

May not be suitable for all medical and aerospace applications.


Specifications: Contact Mallory Sonalert to discuss your application.

Voice Coil Impedance (Ω)	$8 \pm 15\%$ at 2000 Hz / 1.0 V
Rated Input (W)	0.25
Max. Input (W)	0.25
Lowest Resonance Freq Fo (Hz)	$1000 \pm 20\%$
Frequency Range (Hz)	Fo ~ 4000
Output S.P.L. (dB)	76 ± 3 at 0.25W 0.1m 1k,1.2k,1.5k,2.0 kHz 62 ± 3 at 1W 1M 1k, 1.2k, 1.5, 2.0 kHz
Operation / Storage Temp	-25 to 50°C / -25 to 55°C
Weight (g)	12.0
Housing Color	Green
Options	For other options contact factory

Dimensions: (units: mm)

ROHS Compliant

A=20 $\pm$ 0.5 ; B=14.5 $\pm$ 0.5 ; C=7 $\pm$ 0.5

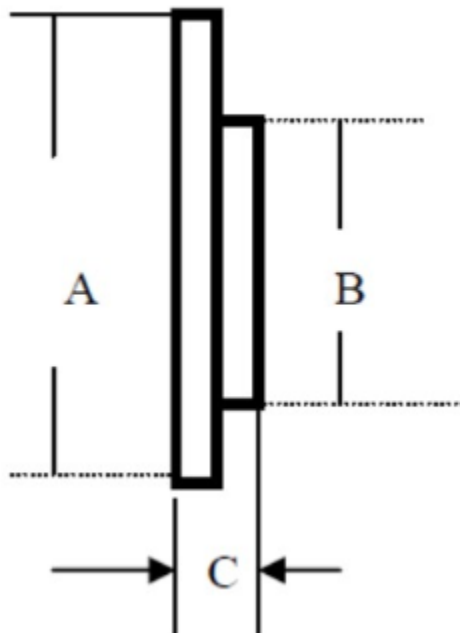

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Mallory Sonalert:](#)

[PSR-20F08S-YHQ](#)