


**May not be suitable for all medical and aerospace applications.**

**Specifications: Contact Mallory Sonalert to discuss your application.**

|                                |  |
|--------------------------------|--|
| Resonant Frequency (Hz)        | 3000 $\pm$ 500                                 |
| Operating Voltage (Vdc)        | 5 ~ 15   |
| Rated Voltage (Vdc)            | 12   |
| Current Consumption Max. (mA)  | 200 at Rated Voltage                           |
| Sound Pressure Level Min. (dB) | 105 at 100cm at Rated Voltage                  |
| Tone/Pulse Rate (Hz)           | Pulse 1.2 $\pm$ 20%                            |
| Operating Temperature (°C)     | -20 ~ +70                                      |
| Storage Temperature (°C)       | -30 ~ +80                                      |
| Housing                        | ABS 757 UL94HB plastic resin<br>(Color: Black) |
| Leading Wire                   | 22 AWG   |
| Weight (Grams)                 | 55.8   |
| Options                        | For other options contact factory              |

**Dimensions:** (units: mm)

**ROHS Compliant**

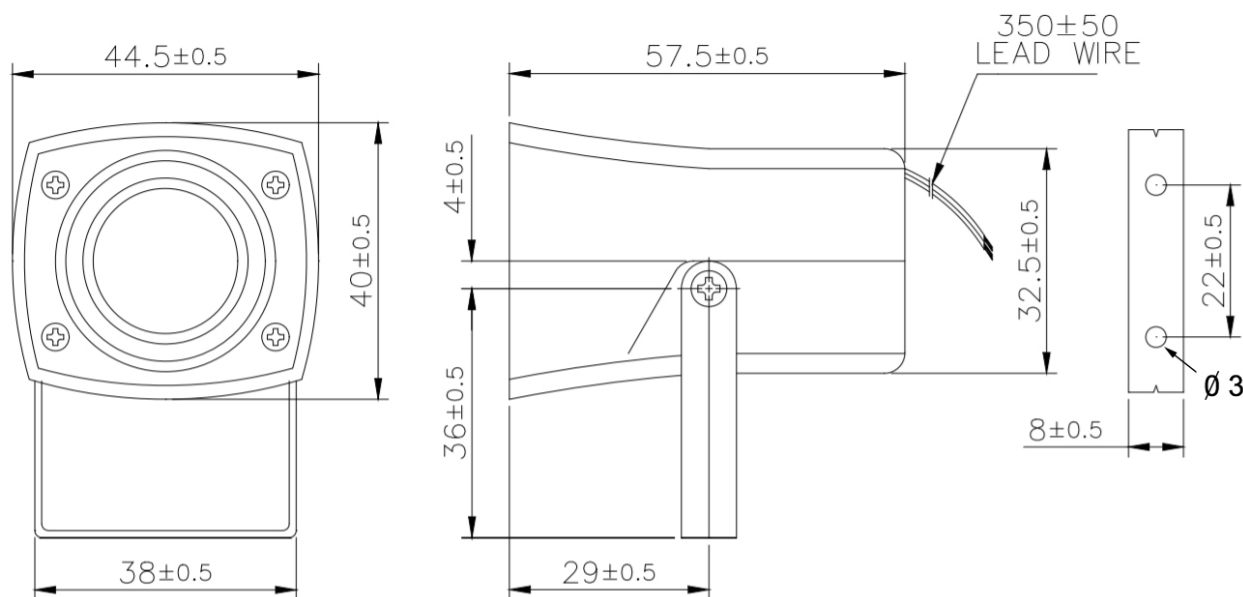

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Mallory Sonalert:](#)

[PS-521Q](#)