


May not be suitable for all medical and aerospace applications.

Specifications: Contact Mallory Sonalert to discuss your application.

Resonant Frequency (Hz)	4000 ± 500
Operating Voltage Max (Vdc)	3 ~ 28
Rated Voltage (Vdc)	9
Current Consumption Max. (mA)	10 at Rated Voltage
Sound Pressure Level Min. (dB)	85 at 30cm at Rated Voltage
Operating Temperature (°C)	-20 ~ +90
Storage Temperature (°C)	-30 ~ +100
Housing	ABS 777D UL94HB plastic resin (Color: Black)
Leading Pin	Tin Plated Brass
Weight (Grams)	2.9
Condition by Wave (°C)	260 ± 5 / within 5 sec
Condition by Hand (°C)	350 ± 20 / within 5 sec
Options	For other options contact factory

Dimensions: (units: mm)

RoHS Compliant

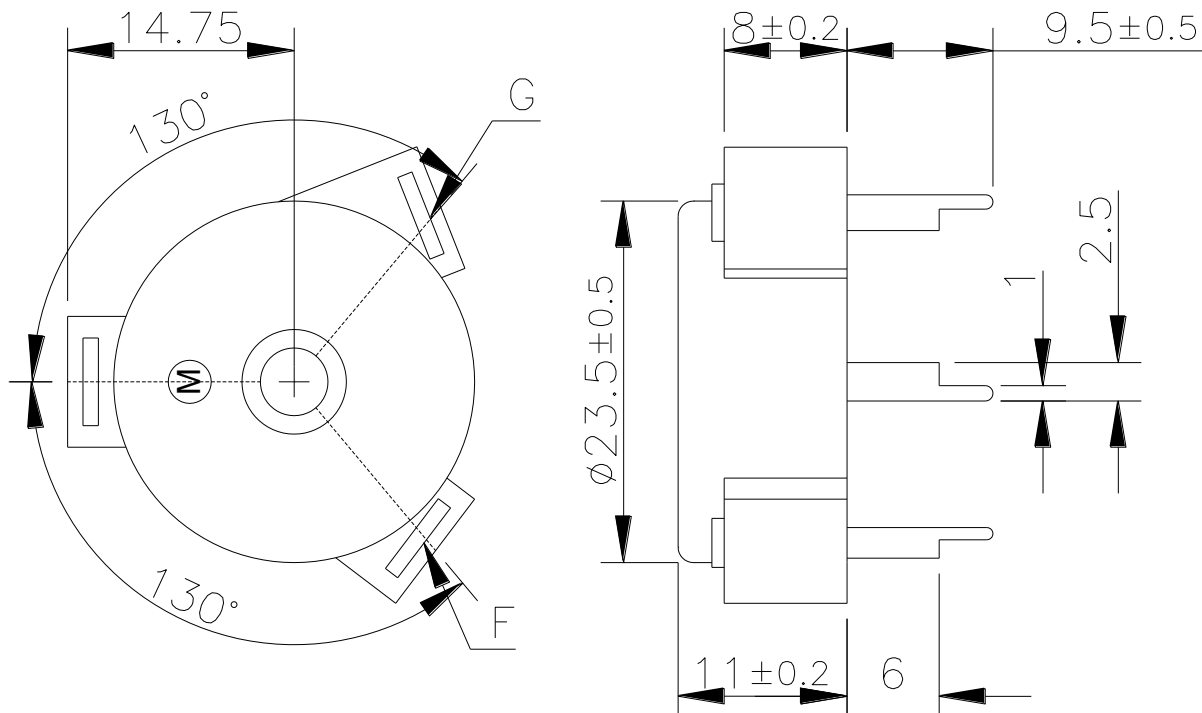

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Mallory Sonalert:](#)

[PT-2040FPQ](#)