

**Sales Outline Drawing**

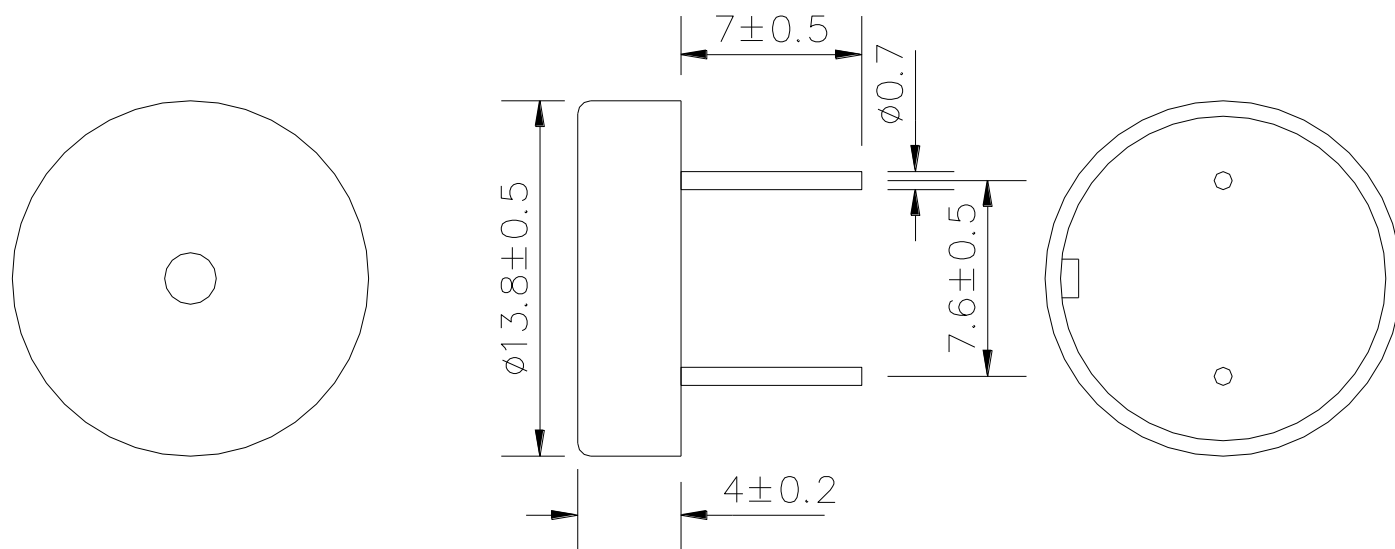
Revision

**C**

**May not be suitable for all medical and aerospace applications.**

**Specifications: Contact Mallory Sonalert to discuss your application.**

Resonant Frequency (Hz)	5000 $\pm$ 500
Operating Voltage (Vp-p/max)	25
Rated Voltage (Vp-p)	5.0
Current Consumption (mA/max)	1.5 at Rated Voltage
Sound Pressure Level (dB/min)	80 at 10cm at Rated voltage
Capacitance (pF)	15,000 $\pm$ 30% at 120Hz
Operating Temperature (°C)	-20 ~ +90
Storage Temperature (°C)	-30 ~ +100
Housing	ABS 777D plastic resin (Color: Black)
Lead Pins	Tin Plated Brass
Weight (Grams)	0.8
Condition by wave soldering (°C)	260 $\pm$ 5 / within 5 sec
Condition by hand soldering (°C)	350 $\pm$ 20 / within 5 sec
Options	For other options contact factory

**NO CIRCUITRY****Dimensions:** (units: mm)**ROHS Compliant**

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Mallory Sonalert:](#)

[PT-1250PQ](#)