

**Sales Outline Drawing**

**May not be suitable for all medical and aerospace applications.**


**Specifications: Contact Mallory Sonalert to discuss your application.**

Resonant Frequency (Hz)	6000 $\pm$ 500
Operating Voltage (Vp-p)	3 ~ 28
Rated Voltage (Vp-p)	12
Current Consumption (mA/max)	8.0 at Rated Voltage
Sound Pressure Level (dB/min)	85 at 30cm at Rated voltage
Operating Temperature (°C)	-20 ~ +70
Storage Temperature (°C)	-30 ~ +80
Housing	ABS 777D UL94HB plastic resin (Color: Black)
Lead Wires	32 AWG      M = Main (Ceramic); F = Feedback; G = Ground (Metal)
Weight (Grams)	2.2
Options	For other options contact factory

**NO CIRCUITRY**

**Dimensions:** (units: mm)

**ROHS Compliant**

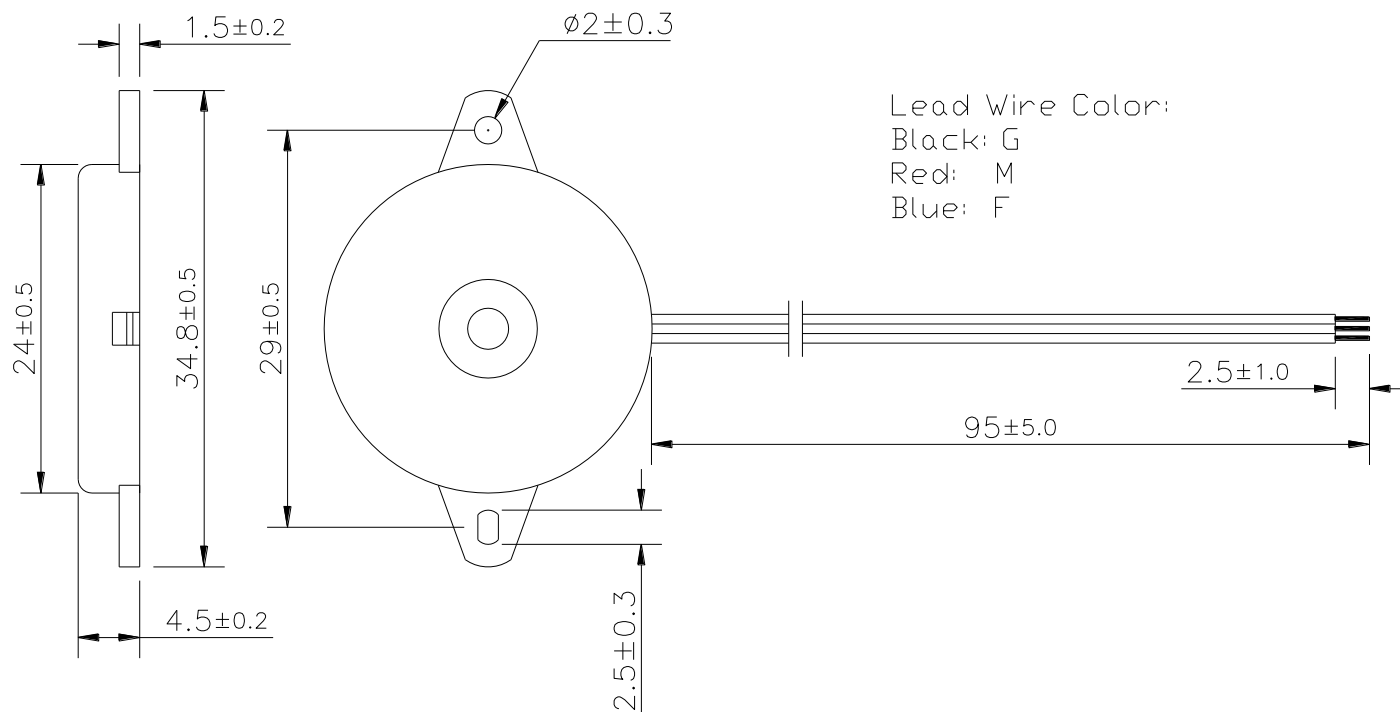

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Mallory Sonalert:](#)

[PT-2065FWQ](#)