

**May not be suitable for all medical and aerospace applications.**

**Specifications: Contact Mallory Sonalert to discuss your application.**


Resonant Frequency (Hz)	3000 $\pm$ 500
Operating Voltage Max (Vp-p)	30
Rated Voltage (Vp-p)	5.0
Current Consumption Max. (mA)	5.0 at Rated Voltage
Sound Pressure Level Min. (dB)	90 at 10cm at Rated Voltage
Capacitance (pF)	26,000 $\pm$ 30% @ 120Hz
Operating Temperature (°C)	-20 ~ +90
Storage Temperature (°C)	-30 ~ +100
Housing	ABS 777D UL94HB plastic resin (Color: Black)
Leading Pin	Tin Plated Brass
Weight (Grams)	2.4
Condition by Wave (°C)	260 $\pm$ 5 / within 5 sec
Condition by Hand (°C)	350 $\pm$ 20 / within 5 sec
Options	For other options contact factory

## NO CIRCUITRY

**Dimensions:** (units: mm)

PS: Vp-p = 1/2duty, square wave

**RoHS Compliant**

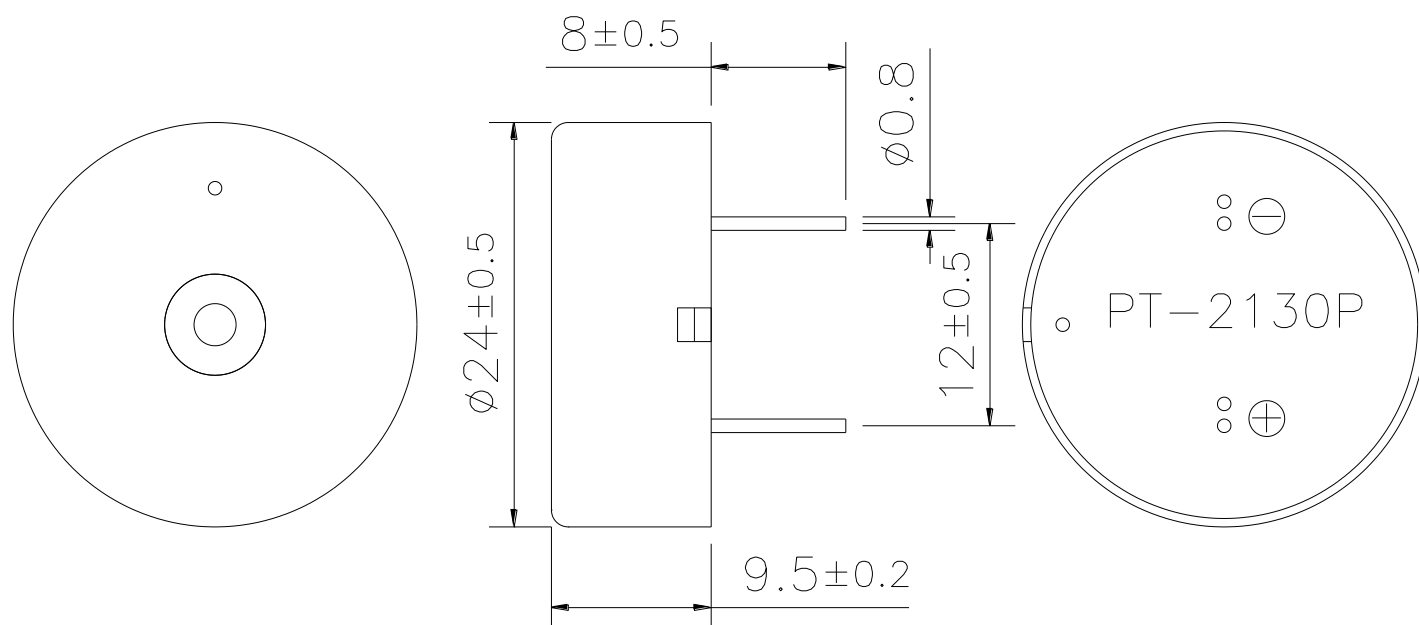

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Mallory Sonalert:](#)

[PT-2130PSQ](#)