



Mallory Sonalert Products, Inc.

Part #:

SBM616JR

Sales Outline Drawing

Revision:


B

Specifications:

Sound Level Category	Medium
Mode of Operation	Slow Pulse @ 0.5 - 2.5 PPS
Voltage Rating	6 to 16 Vdc
Frequency	2900 \pm 500 Hz
Loudness @ Min Vdc	68 dB(A) @ 2 Feet and 6 Vdc
Loudness @ Max Vdc	78 dB(A) @ 2 Feet and 16 Vdc
Current Draw	3-12 mA
Duty Cycle (%)	50
Mounting	Printed Circuit Board (See Note B)
Housing Material	6/6 Nylon, Color: Black
Storage Temperature	-40° to +85° C
Operating Temperature	-30° to +65° C
Weight (Typical)	0.6 oz (17g)
Options	Please contact factory.

Dimensions: Inches (mm)

ROHS Compliant

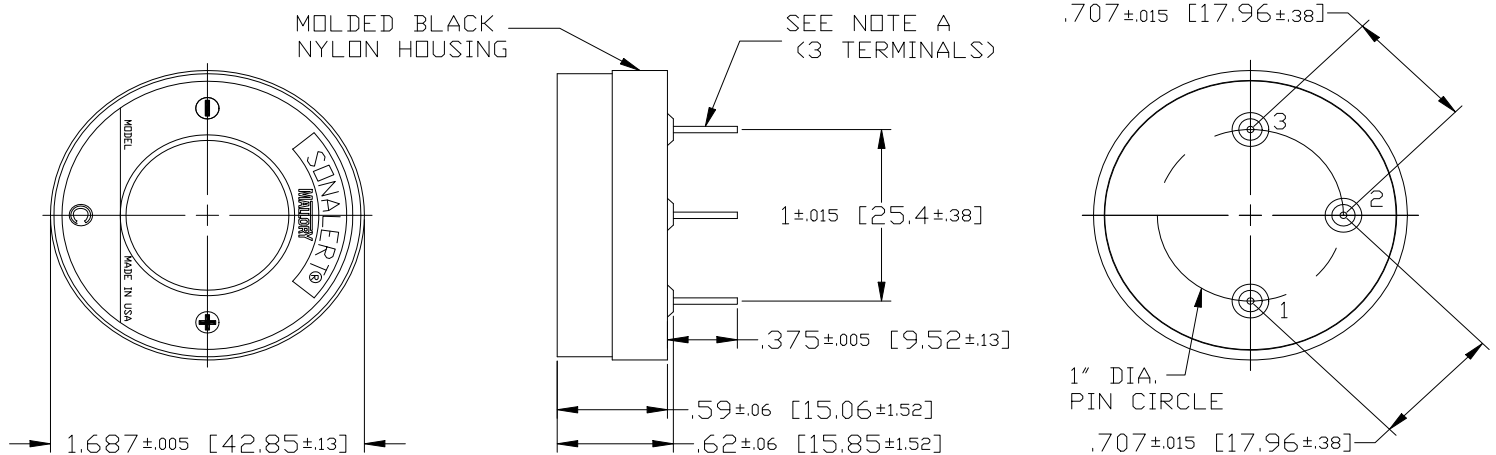

NOTE A:

TERMINALS - .031" DIA. SOLDER COATED COPPER-CLAD STEEL. TERMINAL 1 IS POSITIVE, TERMINAL 3 IS NEGATIVE. TERMINAL 2 IS FOR SUPPORT ONLY - NO ELECTRICAL CONNECTION.

NOTE B:

MOUNTING - INSERT INTO PRINTED CIRCUIT BOARD AND HAND OR MACHINE SOLDER.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Mallory Sonalert:](#)

[SBM616JR](#)