

**Mallory Sonalert Products, Inc.**

Part #:

SBS300PC**Sales Outline Drawing**

Revision:

D**Specifications:**

Sound Level Category:	Extra Loud
Mode of Operation:	Medical Spec IEC60601-1-8
Voltage Rating:	2.8Vp-p Square Wave
Frequency:	150 to 4000 Hz
Loudness @ 10cm:	95 to 105 dB(A) Typ.
Ipk Current*:	1W Rated 1.5W Max.
Housing Material:	ABS 777D Plastic Resin, Black
Storage Temperature:	-40° to +85° C
Operating Temperature:	-30° to +65° C
Weight Typical:	1.1 oz (32g)
Options:	Please contact factory.
Condition by wave solder (°C)	260 ± 5 within 5 sec
Condition by hand solder (°C)	350 ± 20 within 5 sec

Dimensions:

Inches (mm)


cUL Recognized**ROHS Compliant**

PATENT NUMBER: 7880593

Before Code Date: 1546

Not cUL Recognized

After Code Date: 1547 cUL Recognized

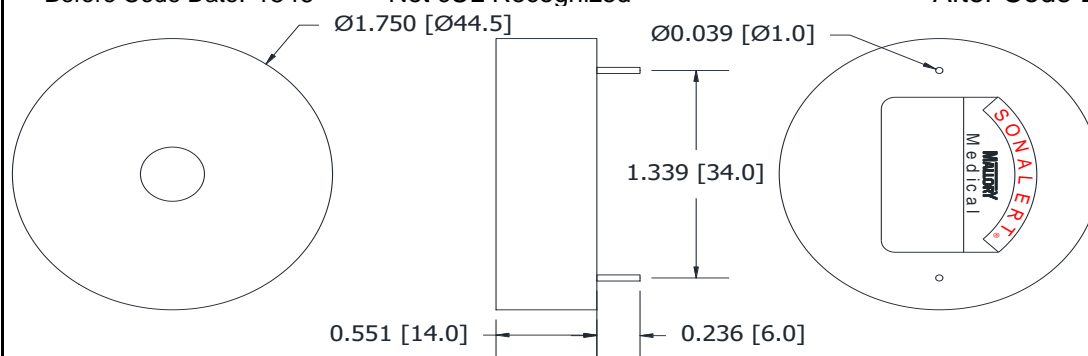

*Ipk = Instantaneous Peak

tolerances:

±0.01 [±0.3]

±0.005 [±0.1]

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Mallory Sonalert:](#)

[SBS300PC](#)