


<b>Mallory</b> <b>Mallory Sonalert Products, Inc.</b>	Part #: <b>SBT5CHFL</b>
<b>Sales Outline Drawing</b>	Revision: <b>A</b>

Specifications:	cUL Recognized to IEC60601-1-8 Cardiac Melody - High Priority Only
Sound Level Category:	Loud
Mode of Operation:	High Priority Alarm - 10 beeps repeating every 2.5 sec
Voltage Rating:	3.3 to 5 VDC
Frequency:	150 to 4000 Hz
Loudness @ 10cm:	85 to 95 dB(A) Typ.
Average Current Draw:	<35mA Typ.
Ipk Current*:	300mA
Housing Material:	ABS 777D Plastic Resin, Black
Storage Temperature:	-40° to +85° C
Operating Temperature:	-30° to +65° C
Weight Typical:	0.6 oz (17g)
Options:	Please contact factory.

**Dimensions:**      Inches (mm)      **cUL Recognized**      **ROHS Compliant**

PATENT NUMBER: 7880593

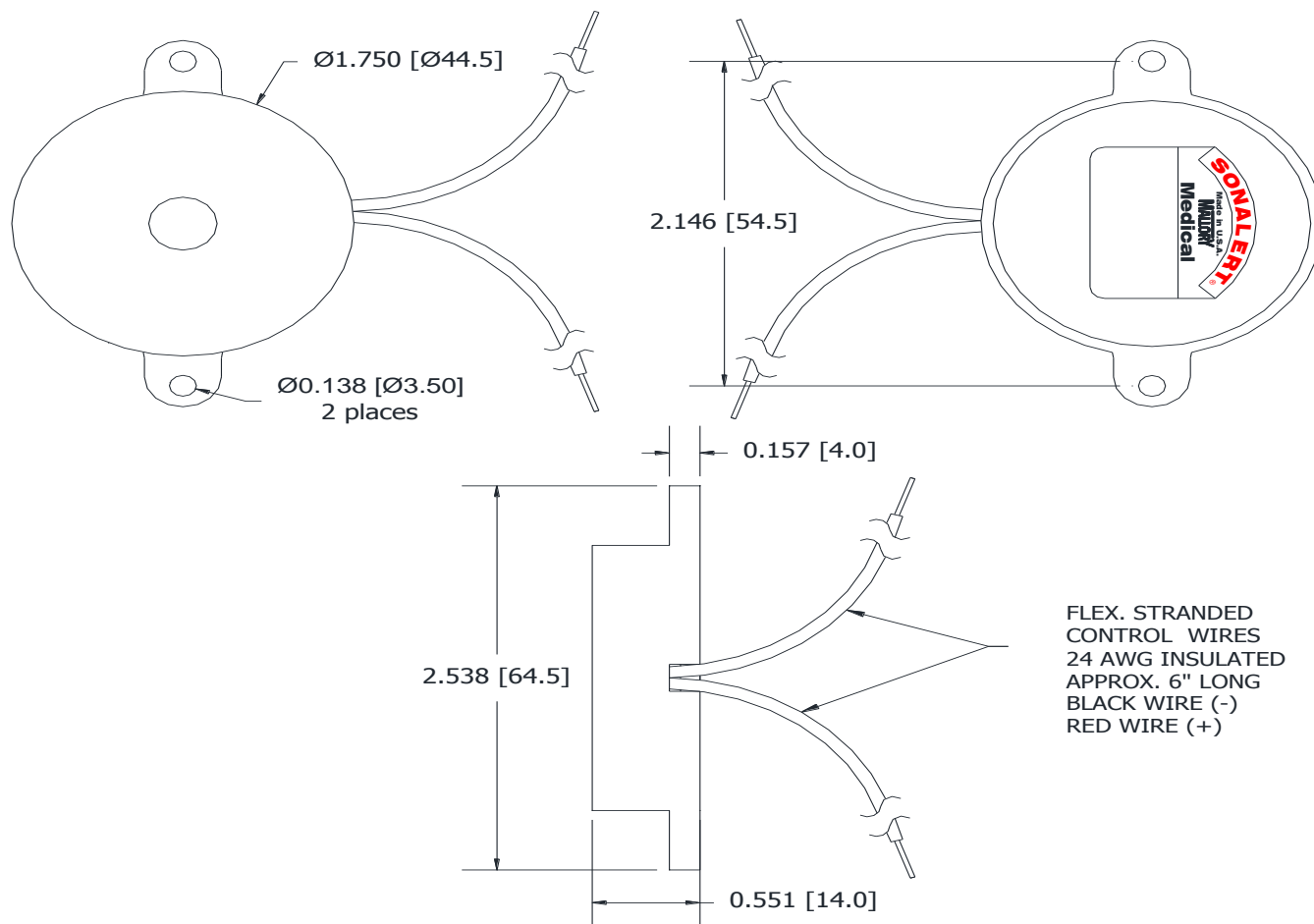

\*Ipk = Instantaneous Peak

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Mallory Sonalert:](#)

[SBT5CHFL](#)