

# Mallory Sonalert Products, Inc.

Part #:

**SC628AF**

## Sales Outline Drawing


Revision:

**D**

### Specifications:

|                       |  |
|-----------------------|--|
| Sound Level Category  | Soft   |
| Mode of Operation     | Continuous   |
| Voltage Rating        | 6 to 28 VAC/DC   |
| Frequency             | 2900 $\pm$ 500 Hz  |
| Loudness @ 2 FT       | 55 to 74 dB(A) Typ.  |
| Loudness @ Min Vdc    | 50/63 dB(A) @ 2 Feet and Vdc   |
| Loudness @ Max Vdc    | 65/78 dB(A) @ 2 Feet and Vdc   |
| Current Draw          | 2-4mA  |
| Housing Material      | 6/6 Nylon, Color: Black  |
| Storage Temperature   | -40° to +85° C   |
| Operating Temperature | -30° to +65° C   |
| Panel Mounting        | Recommended hole size is 1.25"(31.75mm). Thread front will fit standard 30mm(1.181") hole. |
| Knurled Nut           | Used to attach part to panel. The max recommended torque is 10 in-lbs.                     |
| Weight (Typical)      | 1.6 oz (45g)   |
| NEMA 3R,4X, & 12      | Approved with use of ACC03.  |
| Options               | Please contact factory.  |

### Dimensions: Inches (mm)

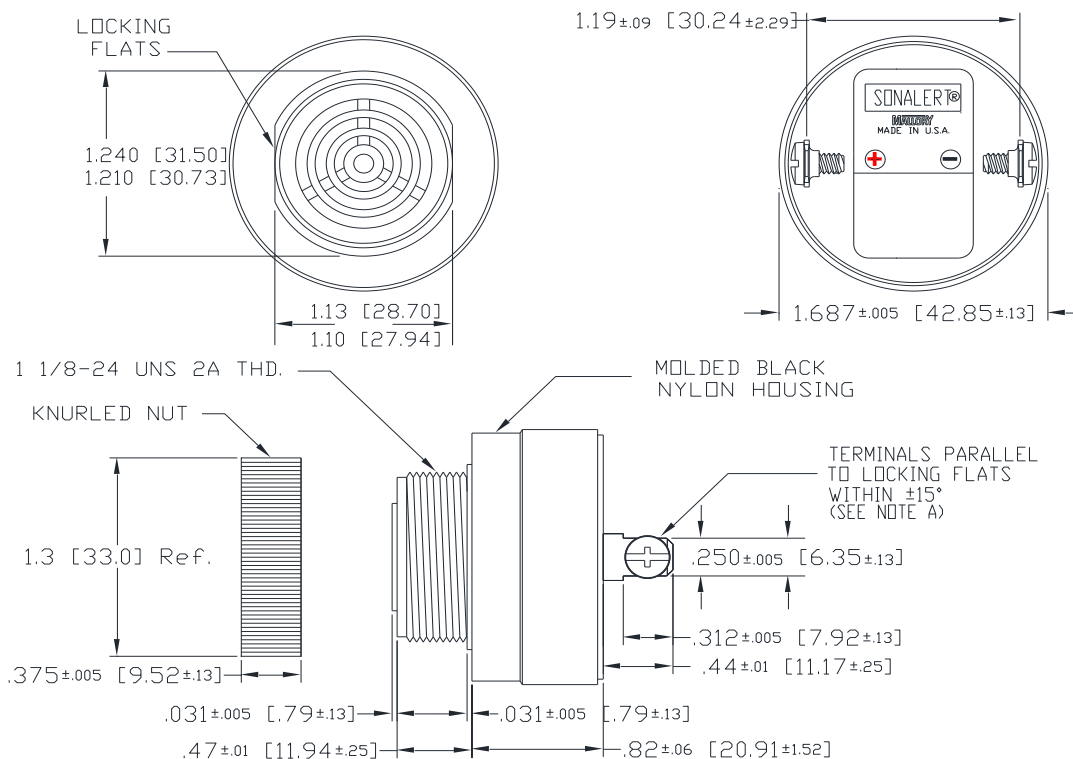

NOTE A: TERMINALS-.032 BRASS TIN PLATED, TAPPED FOR #6-32 SCREW. TWO #6-32 NICKEL PLATED BRASS SCREWS INCLUDED. WILL ACCEPT 1/4" QUICK CONNECT.

NOTE B: MOUNTING- REMOVE BLACK PLASTIC NUT AND INSERT THREADED FRONT THROUGH 1.25" HOLE PUNCHED IN PANEL, IF ORIENTATION IS NEEDED, NOTE LOCKING FLATS ON DRAWING. SCREW NUT BACK ON. DO NOT OVERTIGHTEN.

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Mallory Sonalert:](#)

[SC628AF](#)