



Mallory Sonalert Products, Inc.

Part #:

SCE028XD2MG7B

Sales Outline Drawing

Revision:


D

Specifications:

Sound Level Category:	Extra Loud	Loud		
Mode of Operation:	Continuous	Ding Dong 2.0 - 1.6 kHz		
Pulse Rate (PPS):	N/A	1.2		
Loudness @ 2 FT:	95 to 105 dB(A) Typ.	85 to 95 dB(A) Typ.		
Frequency:	2000 \pm 500 Hz	2000 \pm 500 Hz		
Connection:	T-BLOCK ONLY	T-BLOCK; BLACK WIRE TO (-)		
Voltage Rating:	16 to 28 VDC			
Current Draw:	40mA MAX			
Housing Material:	6/6 Nylon, Color: Black			
Storage Temperature:	-40° to +85° C			
Operating Temperature	-40° to +85° C			
Panel Mounting:	Recommended hole size is 1.25"(31.75mm). Thread front will fit standard 30mm(1.181") hole.			
Knurled Nut:	Used to attach part to panel. The max recommended torque is 10 in-lbs.			
Weight (Typical):	2.1 oz (60g)			
NEMA 3R, 4X, & 12:	Approved with use of ACC03.			
cUL Recognition:	cUL Recognized			
Options:	Please contact factory.			

Dimensions: Inches (mm)

ROHS Compliant

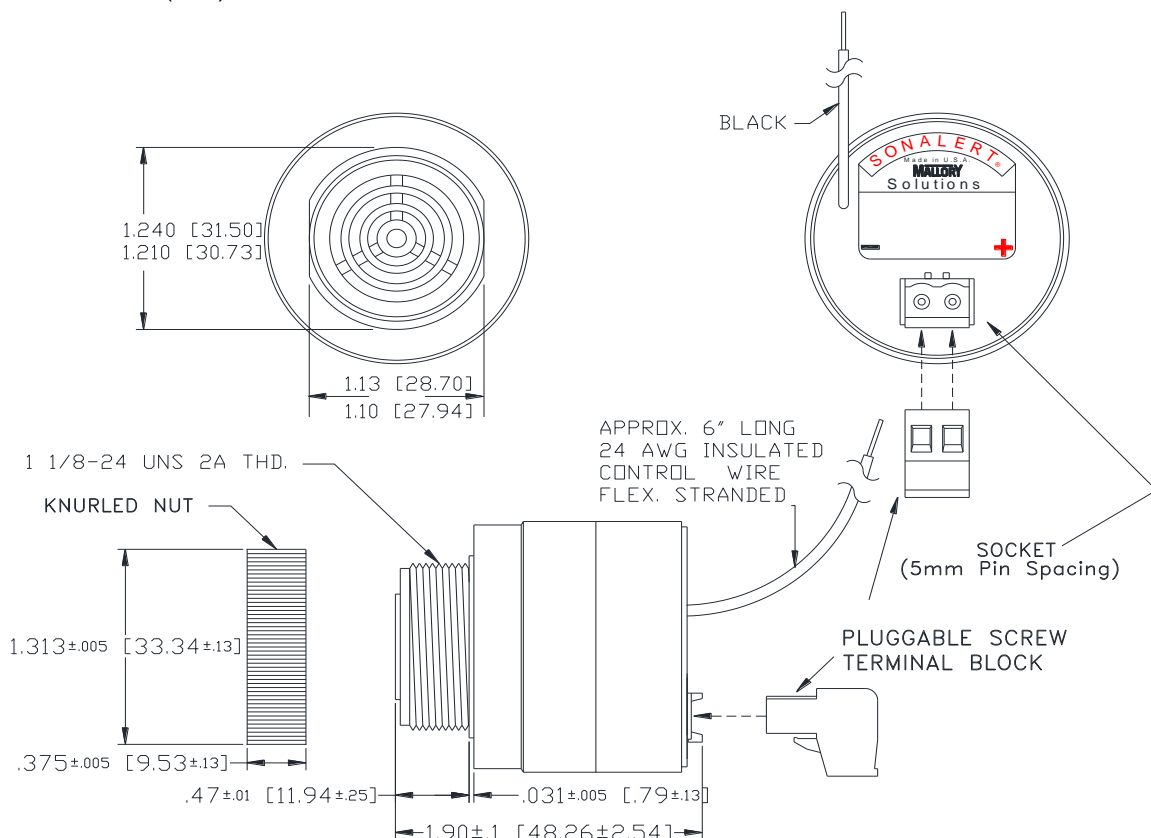

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Mallory Sonalert:](#)

[SCE028XD2MG7B](#)