

**Mallory Sonalert Products, Inc.**

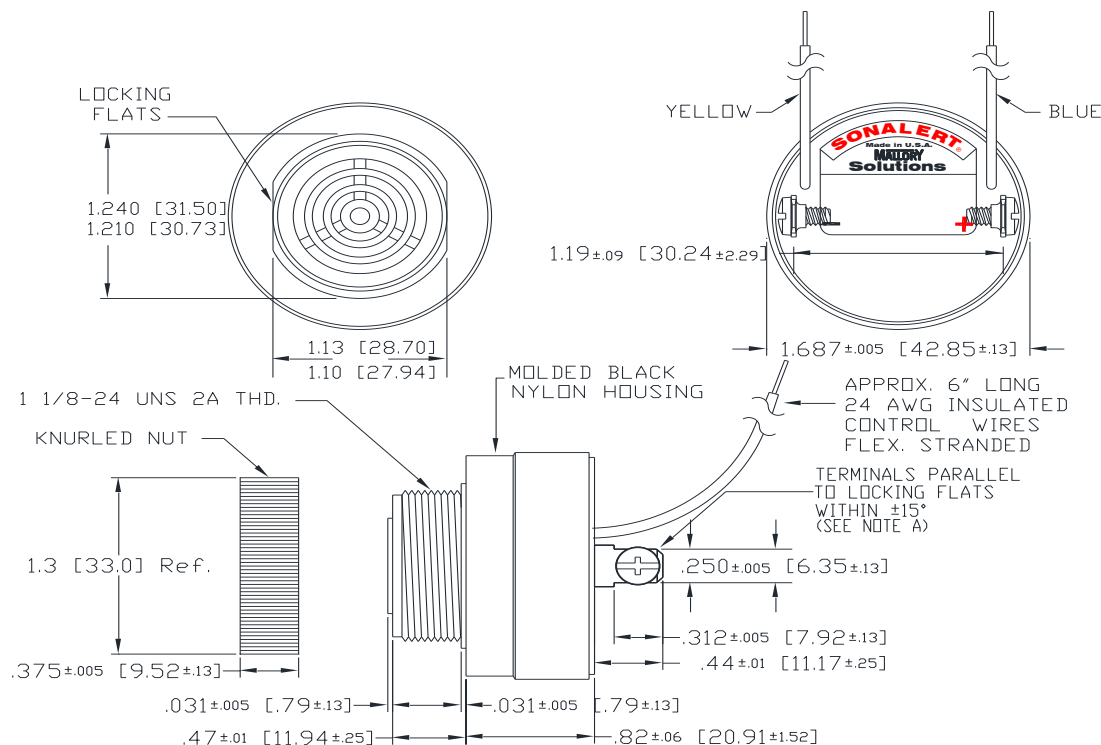
Part #:

SCE048XD3DB3S**Sales Outline Drawing**

Revision:

A**Specifications:**

| | | | | |
|------------------------|--|-----------------------------|-------------------------------|------------------------------|
| Sound Level Category: | Extra Loud | Loud | Extra Loud | Loud |
| Mode of Operation: | Continuous | Continuous | Slow Pulse | Slow Pulse |
| Pulse Rate (PPS): | N/A | N/A | 1 | 1 |
| Loudness @ 2 FT: | 95 to 105 dB(A) Typ. | 85 to 95 dB(A) Typ. | 95 to 105 dB(A) Typ. | 85 to 95 dB(A) Typ. |
| Frequency: | 2900 ± 500 Hz | 2900 ± 500 Hz | 2900 ± 500 Hz | 2900 ± 500 Hz |
| Connection: | TERMINALS ONLY | TERMINALS; BLUE WIRE TO (-) | TERMINALS; YELLOW WIRE TO (-) | TERMINALS; BOTH WIRES TO (-) |
| Voltage Rating: | 28 to 48 VDC | | | |
| Current Draw: | 40mA MAX | | | |
| Housing Material: | 6/6 Nylon, Color: Black | | | |
| Storage Temperature: | -40° to +85° C | | | |
| Operating Temperature: | -40° to +85° C | | | |
| Panel Mounting: | Recommended hole size is 1.25"(31.75mm). Thread front will fit standard 30mm(1.181") hole. | | | |
| Knurled Nut: | Used to attach part to panel. The max recommended torque is 10 in-lbs. | | | |
| Weight (Typical): | 1.6 oz (45g) | | | |
| NEMA 3R,4X, & 12: | Approved with use of ACC03. | | | |
| cUL Recognition: | cUL Recognized | | | |
| Options: | Please contact factory. | | | |

Dimensions: Inches (mm)**ROHS Compliant**

NOTE A: TERMINALS-.032 BRASS TIN PLATED, TAPPED FOR #6-32 SCREW. TWO #6-32 NICKEL PLATED BRASS SCREWS INCLUDED. WILL ACCEPT 1/4" QUICK CONNECT.

NOTE B: MOUNTING- REMOVE BLACK PLASTIC NUT AND INSERT THREADED FRONT THROUGH 1.25" HOLE PUNCHED IN PANEL, IF ORIENTATION IS NEEDED, NOTE LOCKING FLATS ON DRAWING. SCREW NUT BACK ON. DO NOT OVERTIGHTEN.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Mallory Sonalert:](#)

[SCE048XD3DB3S](#)