

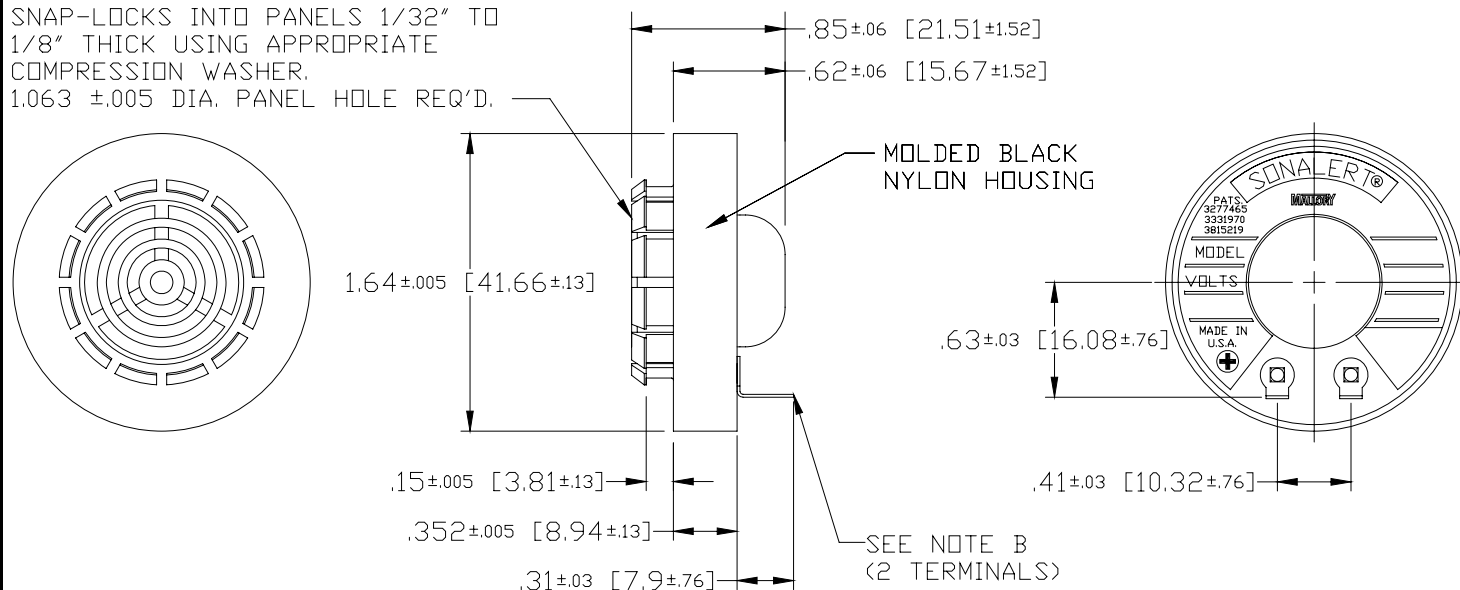
**Specifications:**

|                         |                                   |
|-------------------------|-----------------------------------|
| Sound level Category    | Soft Sound Level                  |
| Mode of Operation       | Continuous                        |
| Mounting                | Panel (see note A)                |
| Voltage Rating          | 4 - 28 Vdc                        |
| Frequency               | 2900 Hz $\pm$ 500 Hz              |
| Loudness (Min. Voltage) | 52 dB(A) min. @ 2 FT and 4 Vdc    |
| Loudness (Max Voltage)  | 68 dB(A) min. @ 2FT and 28 Vdc    |
| Current Draw            | 0.5 mA Max @ 4 Vdc                |
| Current Draw            | 3 mA Max @ 28 Vdc                 |
| Storage Temperature     | -40°C to +85°C                    |
| Operating Temperature   | -30°C to +65°C                    |
| Weight (Typical)        | 0.5 oz (17 g)                     |
| Housing                 | 6/6 Nylon, Color Black            |
| Options                 | For other options contact factory |

**Dimensions:** Inches (mm)

**NOTE A:**

MOUNTING - THIS PORTION  
SNAP-LOCKS INTO PANELS 1/32" TO  
1/8" THICK USING APPROPRIATE  
COMPRESSION WASHER.  
1.063  $\pm$ .005 DIA. PANEL HOLE REQ'D.


**NOTE B:**

TERMINALS - .016 BRASS, HOT TIN FINISH WITH  
.076 WIRE HOLE. TERMINAL WILL ACCEPT  
STANDARD 1/8" QUICK CONNECT

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Mallory Sonalert:](#)

[SNP428F](#)