

**Mallory Sonalert Products, Inc.**

Part #:

**SNP428R****Sales Outline Drawing**




Revision:

**B****Specifications:**

Sound Level Category	Medium
Mode of Operation	Continuous
Voltage Rating	4 to 28 VDC
Frequency	2900 $\pm$ 500 Hz
Loudness @ 2 FT	69 to 83 Typ.
Current Draw	3-18 mA
Housing Material	6/6 Nylon, Color: Black
Storage Temperature	-40° to +85° C
Operating Temperature	-30° to +65° C
Panel Mounting	Recommended hole size is 1.25"(31.75mm). Thread front will fit standard 30mm(1.181") hole.
Weight (Typical)	0.5 oz (17g)
Options	Please contact factory.

**Dimensions:** Inches (mm)**cUL Recognized****ROHS Compliant**

NOTE A:  
MOUNTING - THIS PORTION  
SNAP-LOCKS INTO PANELS 1/32" TO  
1/8" THICK USING APPROPRIATE  
COMPRESSION WASHER.  
1.063  $\pm$  .005 DIA. PANEL HOLE REQ'D.

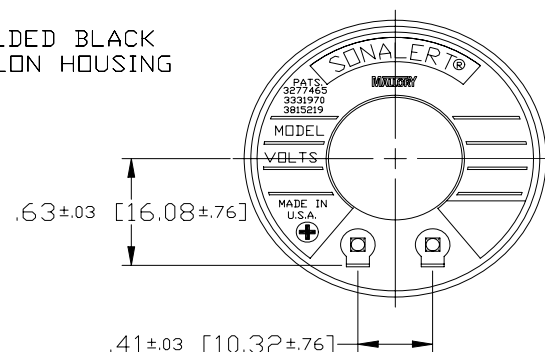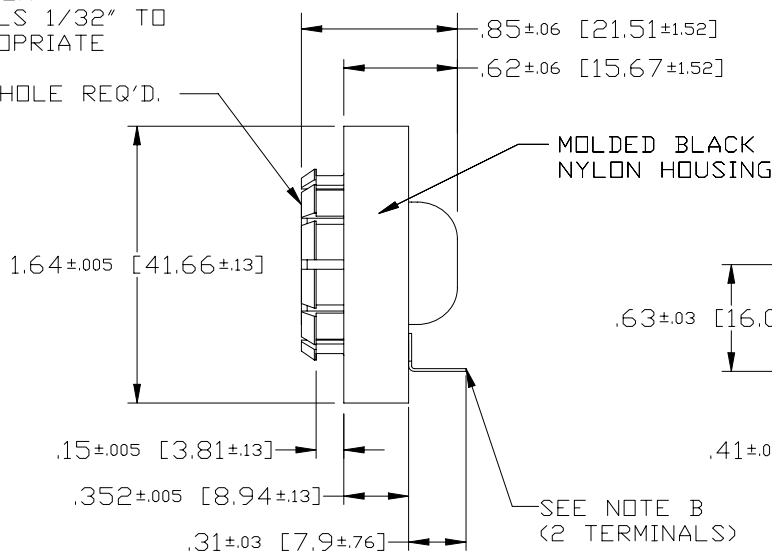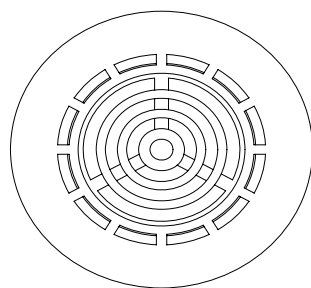

NOTE B:  
TERMINALS - .016 BRASS, HOT TIN FINISH WITH  
.076 WIRE HOLE. TERMINAL WILL ACCEPT  
STANDARD 1/8" QUICK CONNECT

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Mallory Sonalert:](#)

[SNP428R](#)