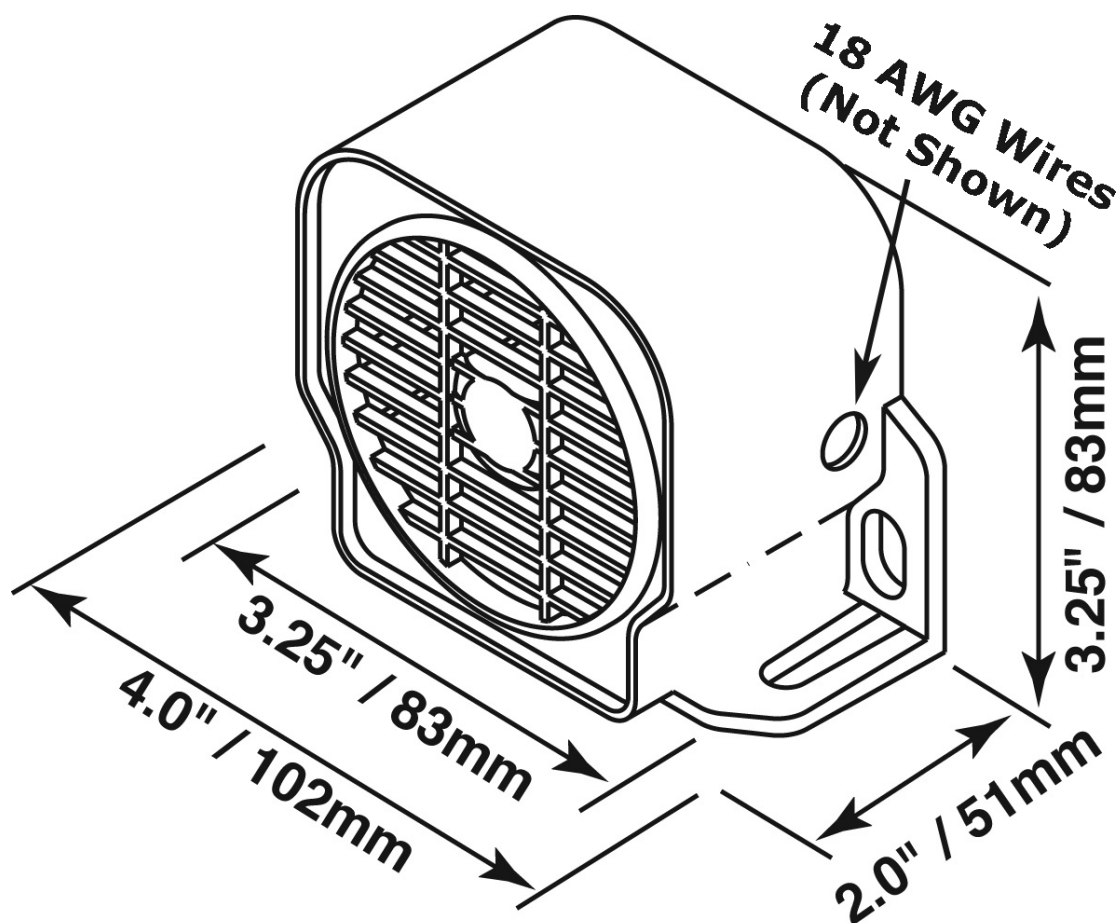


Specifications:

Voltage Rating	12 to 24 Vdc
Frequency	1250 Hz $\pm$ 20%
Loudness (dB(A) @ 4 ft)	107 $\pm$ 8
Current Draw (Amps Max)	1.0
Sound Pulse Rate (pps)	1 to 2
Operating Temperature	-40°C to +85°C
Termination	18 AWG, 10.5" Wires
Housing	ABS, Black UL94V-0/UL94V-1
Spike Protected	+100 / -400 Volts
Conforms to SAEJ994 (OCT 02) Standards	
Cross Reference	
ECCO	575
PRECO	270

Dimensions: Inches (mm)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Mallory Sonalert:](#)

[STA22702W](#)