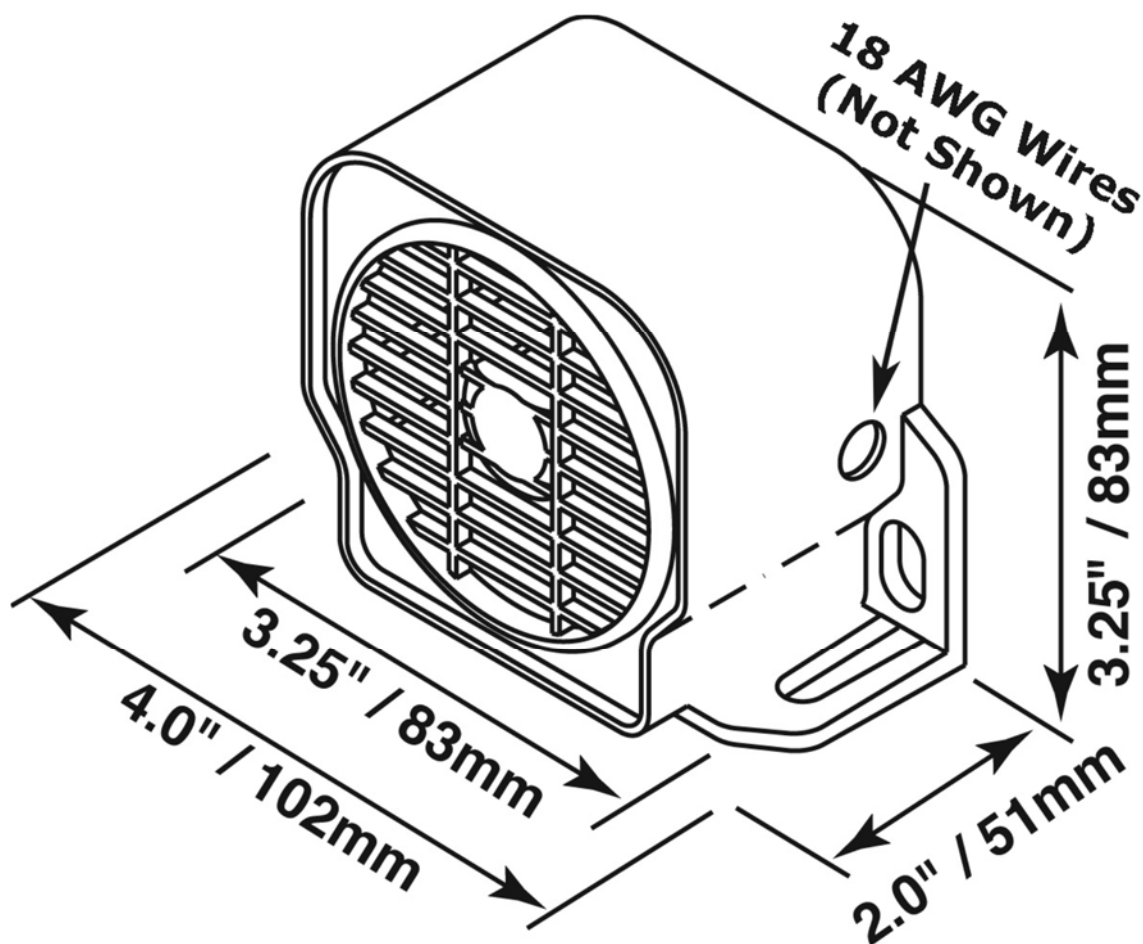


Specifications:

Voltage Rating (Vdc)	12 to 24
Frequency (Hz)	1250 $\pm$ 20%
Loudness (dB(A) @ 4ft)	107 $\pm$ 8
Current Draw (Amps max)	1.0
Sound Pulse Rate (pps)	1 to 2
Operating Temperature (°C)	-40 to +85
Termination	18 AWG, 1035" Wires
Housing	ABS, Black UL94V-0/UL94V-1
Spike Protected	+100 / -400 Volts
Conforms to SAEJ994 (OCT 02) Standards	
Cross Reference	
ECCO	575
PRECO	270
Weight (lbs.)	1.128

Dimensions: Inches (mm)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Mallory Sonalert:](#)

[STA22702W](#)