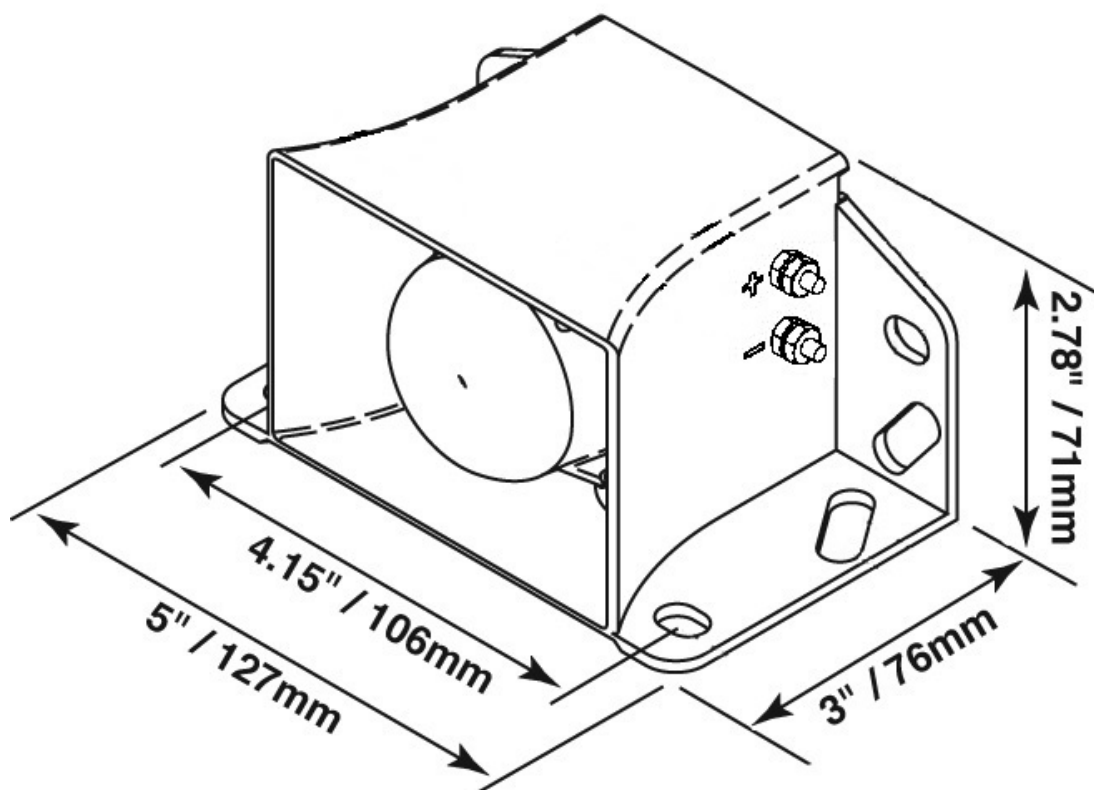


Specifications:

Voltage Rating	12 to 48 Vdc
Frequency	1600 Hz $\pm$ 20%
Loudness (dB(A) @ 4 ft)	82 to 102 (self adjusting)
Current Draw (Amps Max)	0.6
Sound Pulse Rate (pps)	1 to 2
Operating Temperature	-40°C to +85°C
Termination	8-32 UNC Studs
Housing	ABS, 10% Glass Filled, Black UL94V-0
Spike Protected	+100 / -400 Volts
Conforms to SAEJ994 (OCT 02) Standards	
Cross Reference	
ECCO	SA931
PRECO	1048

Dimensions: Inches (mm)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Mallory Sonalert:](#)

[STA32264A](#)