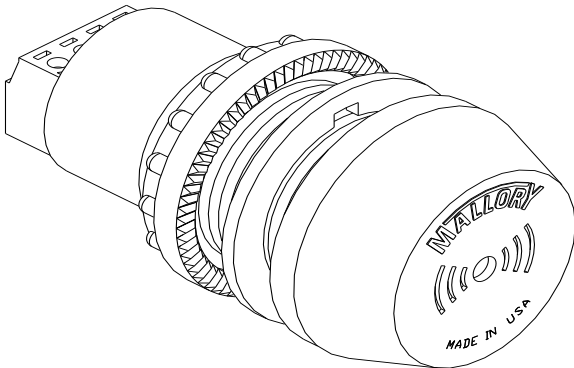
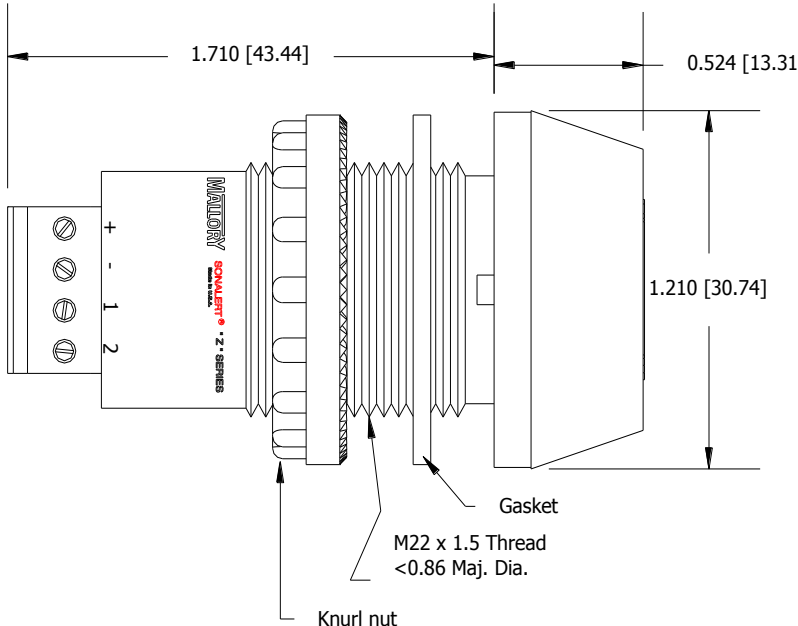


Mallory Sonalert Products, Inc.			Part #:		ZA028MDMT1		
Sales Outline Drawing			Revision:		F		
Specifications:							
Sound Level Category:		Medium		Medium		Medium	
Mode of Operation:		Continuous		Slow Pulse @ 1 PPS		Fast Pulse @ 10 PPS	
Loudness @ 2 FT:		75 to 85 dB(A) Typ.		75 to 85 dB(A) Typ.		75 to 85 dB(A) Typ.	
Frequency:		3900 ± 500 Hz		3900 ± 500 Hz		3900 ± 500 Hz	
Connection:		"+" to Positive, "-" to Ground		"+" to Positive, "-" and "1" to Ground		"+" to Positive, "-" and "2" to Ground	
Voltage Rating:		16 to 28 VDC					
Current Draw:		40mA MAX					
Housing Material:		6/6 Nylon, Color: Black					
Storage Temperature:		-40° to +80° C					
Operating Temperature		-30° to +65° C					
Panel Mounting:		Recommended hole size is 22.5 mm. Thread front will fit standard 22.5mm hole.					
Knurled Nut:		Used to attach part to panel. The max recommended torque is 10 in-lbs.					
Weight (Typical):		28 g					
NEMA 3R,4X, & 12:		Approved with use of included gasket.					
cUL Recognition		cUL Recognized					
Options:		Please contact factory.					
Dimensions:		Inches (mm)		cUL Recognized		ROHS Compliant	
				PATENT NUMBER		9576442	
							

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Mallory Sonalert:](#)

[ZA028MDMT1](#)