



**Mallory Sonalert Products, Inc.**

Part #: **ZA028SASR9**

## Sales Outline Drawing

Revision: **E**

### Specifications:

|                       |                                                                               |
|-----------------------|-------------------------------------------------------------------------------|
| Sound Level Category  | Soft                                                                          |
| Mode of Operation     | Siren Sweep 3.15 - 4 kHz @ 2 Sweeps per Sec.                                  |
| Voltage Rating        | 16 to 28 VAC/DC                                                               |
| Frequency             | 3900 ± 500 Hz                                                                 |
| Loudness @ 2 FT       | 65 to 75 dB(A) Typ.                                                           |
| Current Draw          | 40mA MAX                                                                      |
| Housing Material      | 6/6 Nylon, Color: Black                                                       |
| Storage Temperature   | -40° to +80° C                                                                |
| Operating Temperature | -30° to +65° C                                                                |
| Panel Mounting        | Recommended hole size is 22.5 mm. Thread front will fit standard 22.5mm hole. |
| Knurled Nut           | Used to attach part to panel. The max recommended torque is 10 in-lbs.        |
| Weight (Typical)      | 28 g                                                                          |
| NEMA 3R, 4X, & 12     | Approved with use of included gasket.                                         |
| cUL Recognition       | cUL Recognized                                                                |
| Options               | Please contact factory.                                                       |



### Dimensions: Inches (mm)

### cUL Recognized

### ROHS Compliant

PATENT NUMBER

9576442

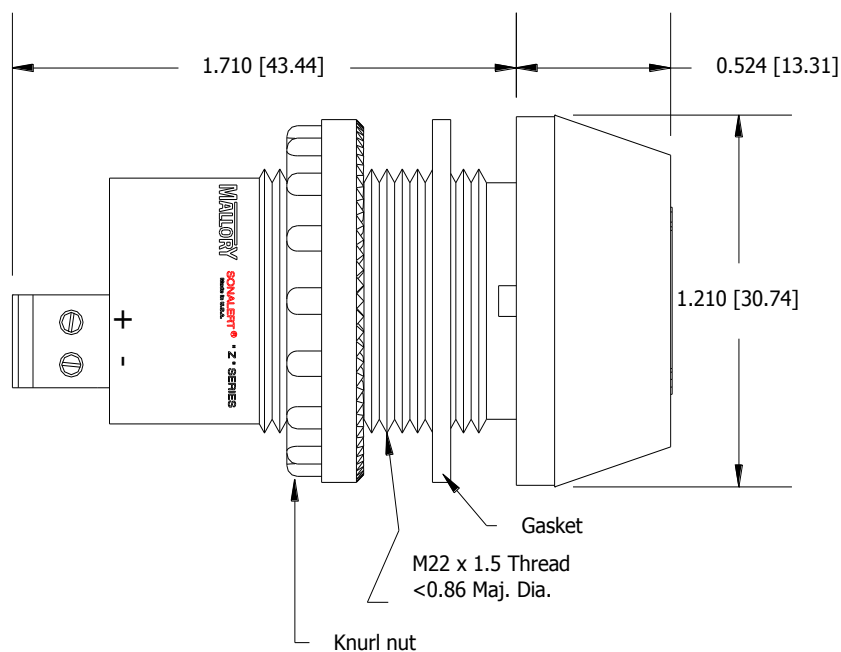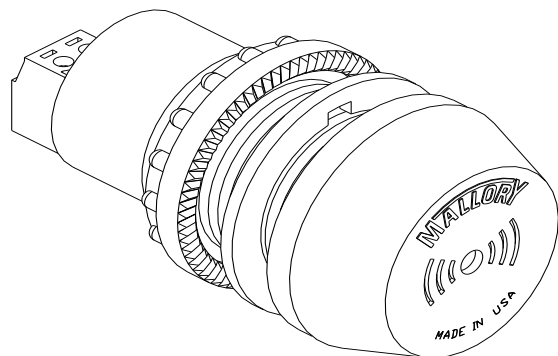

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Mallory Sonalert:](#)

[ZA028SASR9](#)