



**Mallory Sonalert Products, Inc.**Part #: **ZA120SASU2****Sales Outline Drawing**Revision: **F****Specifications:**

| | |
|-----------------------|---|
| Sound Level Category | Soft |
| Mode of Operation | Fast Speed Up @ 0.5 -8 PPS in 30 Seconds |
| Voltage Rating | 48 to 120 VAC |
| Frequency | 3900 \pm 500 Hz |
| Loudness @ 2 FT | 65 to 75 dB(A) Typ. |
| Current Draw | 40mA MAX |
| Housing Material | 6/6 Nylon, Color: Black |
| Storage Temperature | -40° to +80° C |
| Operating Temperature | -30° to +65° C |
| Panel Mounting | Recommended hole size is 22.5 mm. Thread front will fit standard 22.5mm hole. |
| Knurled Nut | Used to attach part to panel. The max recommended torque is 10 in-lbs. |
| Weight (Typical) | 28 g |
| NEMA 3R, 4X, & 12 | Approved with use of included gasket. |
| Note | Supply voltage shall employ Transient Voltage Surge Suppression. |
| Options | Please contact factory. |

Dimensions: Inches (mm)**cUL Recognized****ROHS Compliant**

PATENT NUMBER

9576442

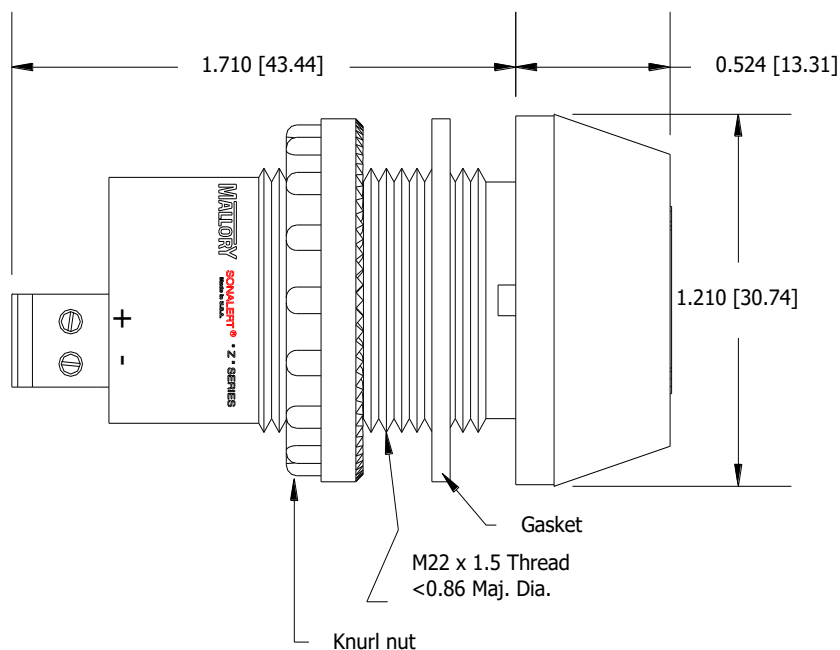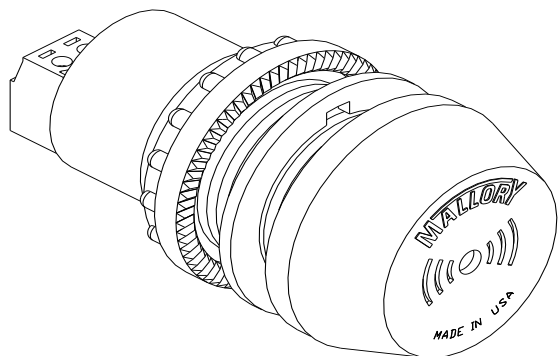

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Mallory Sonalert:](#)

[ZA120SASU2](#)