

**Mallory Sonalert Products, Inc.**

Part #:

ZT028LACTB**Sales Outline Drawing**

Revision:



E**Specifications:**

| | |
|-----------------------|---|
| Sound Level Category | Loud |
| Mode of Operation | Continuous |
| Lens Color | Opaque White |
| LED Color | BLUE |
| LED Mode of Operation | Continuous |
| Voltage Rating | 20 to 28 VAC/DC |
| Frequency | 3900 \pm 500 Hz |
| Loudness @ 2 FT | 85 to 95 dB(A) Typ. |
| Current Draw | 40mA MAX |
| Housing Material | 6/6 Nylon, Color: Black |
| Front Cap Material | 6/6 Nylon, Color: Opaque White |
| Storage Temperature | -40° to +80° C |
| Operating Temperature | -30° to +65° C |
| Panel Mounting | Recommended hole size is 22.5 mm. Thread front will fit standard 22.5mm hole. |
| Knurled Nut | Used to attach part to panel. The max recommended torque is 10 in-lbs. |
| Weight (Typical) | 28 g |
| NEMA 3R, 4X, & 12 | Approved with use of included gasket. |
| Options | Please contact factory. |

Dimensions: Inches (mm)**cUL Recognized****ROHS Compliant**

PATENT NUMBER

9165440

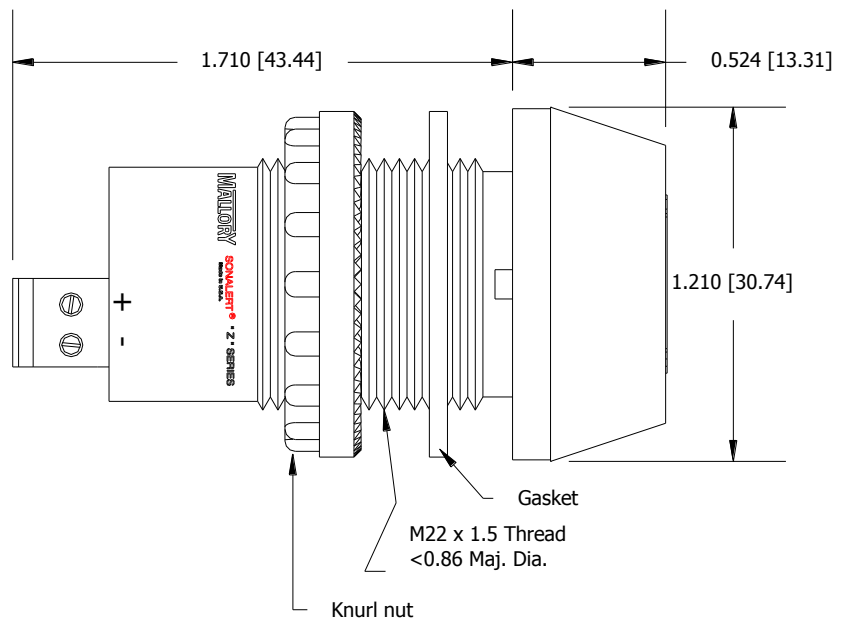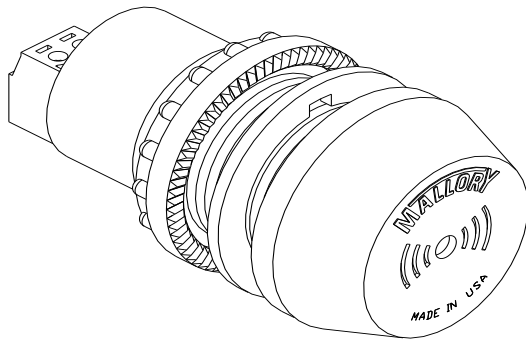

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Mallory Sonalert:](#)

[ZT028LACTB](#)