

**Mallory Sonalert Products, Inc.**

Part #:

ZT028LAIC2G**Sales Outline Drawing**

Revision:

E**Specifications:****INDIVIDUAL CONTROL OF LIGHT AND SOUND**



| | | |
|-----------------------|---|---------------------|
| Function | LIGHT | SOUND |
| Sound Level Category | N/A | Loud |
| Mode of Operation | Continuous | Fast Pulse @ 10 PPS |
| Lens Color | Opaque White | N/A |
| LED Color | GREEN | N/A |
| Rated Voltage | 24 VAC/DC | 24 VAC/DC |
| Voltage Range | 20 to 28 VAC/DC | 20 to 28 VAC/DC |
| Power Connection | L~ to ~VAC/DC | S~ to ~VAC/DC |
| Current Draw | 25mA MAX | 25mA MAX |
| Frequency | N/A | 3900 ± 500 Hz |
| Loudness @ 2 FT | N/A | 85 to 95 dB(A) Typ. |
| Housing Material | 6/6 Nylon, Color: Black | |
| Front Cap Material | 6/6 Nylon, Color: Opaque White | |
| Storage Temperature | -40° to +80° C | |
| Operating Temperature | -30° to +65° C | |
| Panel Mounting | Recommended hole size is 22.5 mm. Thread front will fit standard 22.5mm hole. | |
| Knurled Nut | Used to attach part to panel. The max recommended torque is 10 in-lbs. | |
| Weight (Typical) | 28 g | |
| NEMA 3R, 4X, & 12 | Approved with use of included gasket. | |
| Options | Please contact factory. | |

Dimensions: Inches (mm)**cUL Recognized****ROHS Compliant**

PATENT NUMBER

9165440

9576442

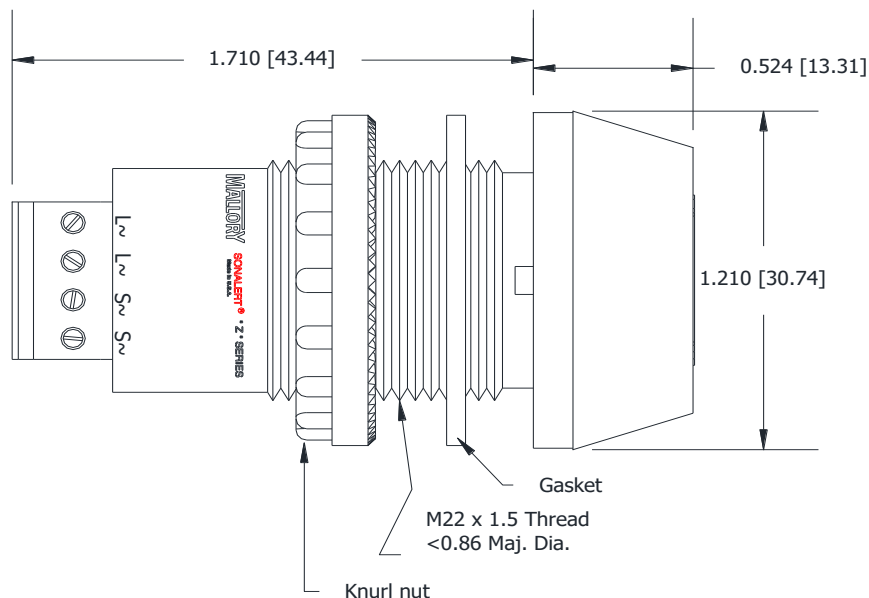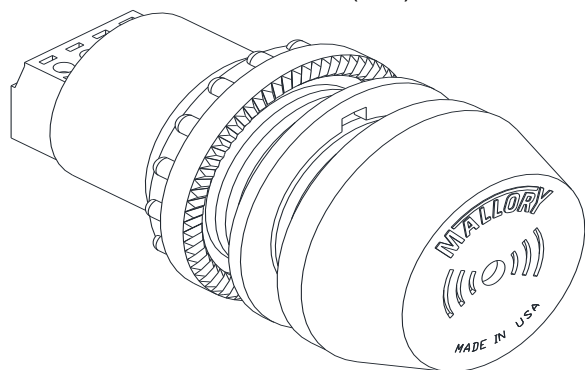

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Mallory Sonalert:](#)

[ZT028LAIC2G](#)