



**Mallory Sonalet Products, Inc.**

Part #:

**ZT028LDCM1R**

## Sales Outline Drawing

Revision:

**C**

### Specifications:

Sound Level Category	Loud
Mode of Operation	Chime Sound and Light @ 3 Seconds Repeating.
Lens Color	Opaque White
LED Color	RED
LED Mode of Operation	FADE @ 3 SEC
Voltage Rating	20 to 28 VDC
Frequency	3900 ± 500 Hz
Loudness @ 2 FT	85 to 95 dB(A) Typ.
Current Draw	40mA MAX
Housing Material	6/6 Nylon, Color: Black
Front Cap Material	6/6 Nylon, Color: Opaque White
Storage Temperature	-40° to +80° C
Operating Temperature	-30° to +65° C
Panel Mounting	Recommended hole size is 22.5 mm. Thread front will fit standard 22.5mm hole.
Knurled Nut	Used to attach part to panel. The max recommended torque is 10 in-lbs.
Weight (Typical)	28 g
NEMA 3R,4X, & 12	Approved with use of included gasket.
Options	Please contact factory.

**Dimensions:** Inches (mm)



**cUL Recognized**

PATENT NUMBER

**ROHS Compliant**

9165440

9576442

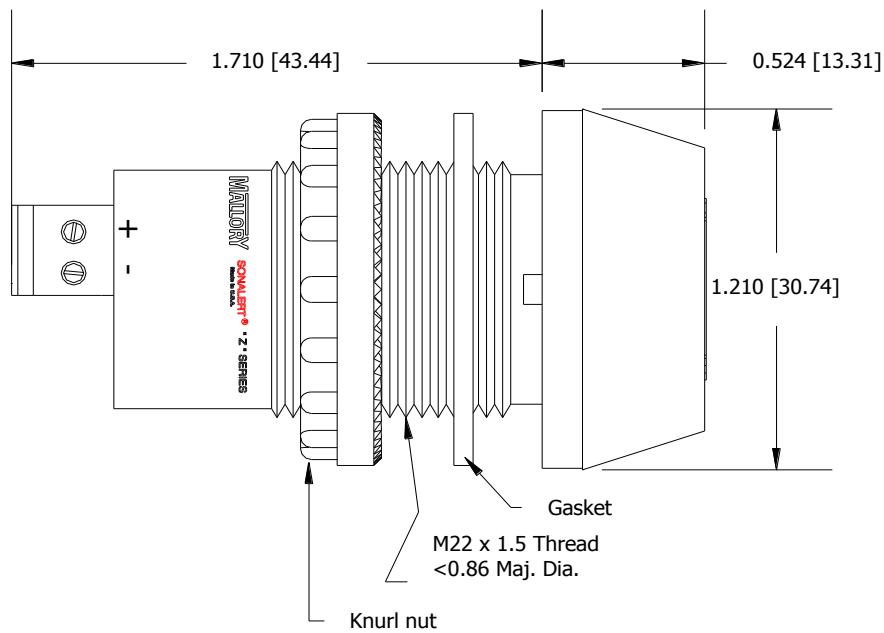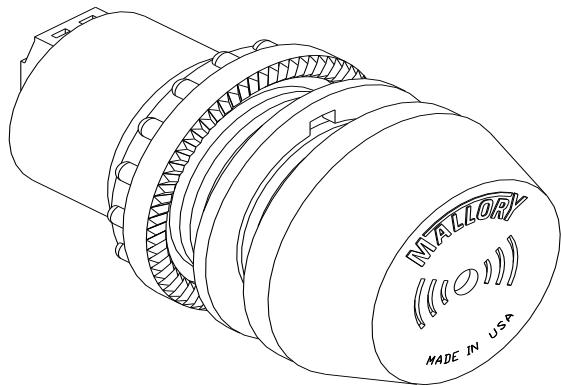

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Mallory Sonalert:](#)

[ZT028LDCM1R](#)