

**Mallory Sonalert Products, Inc.**Part #: **ZT120LADP3R****Sales Outline Drawing**Revision: **C****Specifications:**



Sound Level Category	Loud
Mode of Operation	Slow Double Pulse Sound and Light @ 0.5 PPS
Lens Color	Opaque White
LED Color	RED
LED Mode of Operation	FLASH 0.5PPS
Voltage Rating	90 to 120 VAC
Frequency	3900 \pm 500 Hz
Loudness @ 2 FT	85 to 95 dB(A) Typ.
Current Draw	40mA MAX
Housing Material	6/6 Nylon, Color: Black
Front Cap Material	6/6 Nylon, Color: Opaque White
Storage Temperature	-40° to +80° C
Operating Temperature	-30° to +65° C
Panel Mounting	Recommended hole size is 22.5 mm. Thread front will fit standard 22.5mm hole.
Knurled Nut	Used to attach part to panel. The max recommended torque is 10 in-lbs.
Weight (Typical)	28 g
NEMA 3R, 4X, & 12	Approved with use of included gasket.
Options	Please contact factory.

Dimensions: Inches (mm)**cUL Recognized****ROHS Compliant**

PATENT NUMBER

9165440

9576442

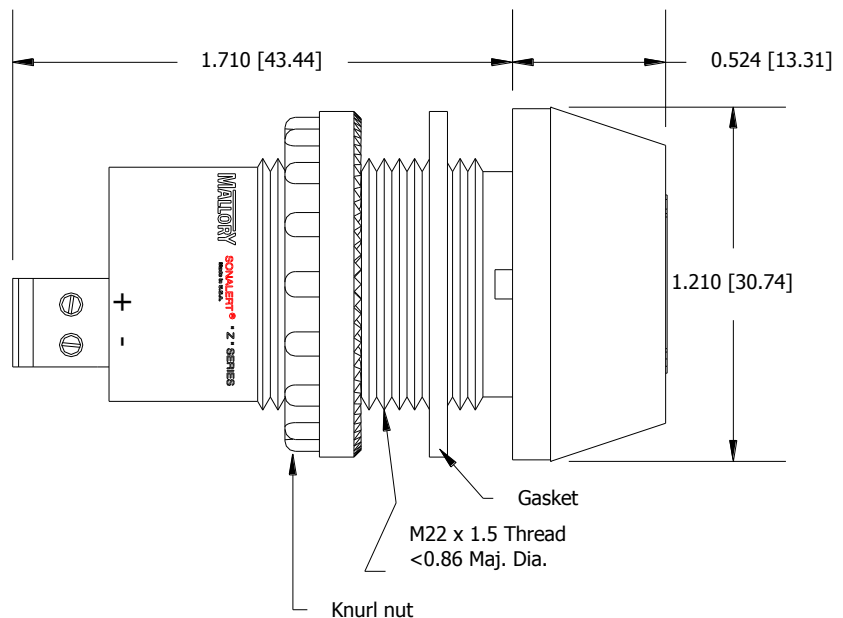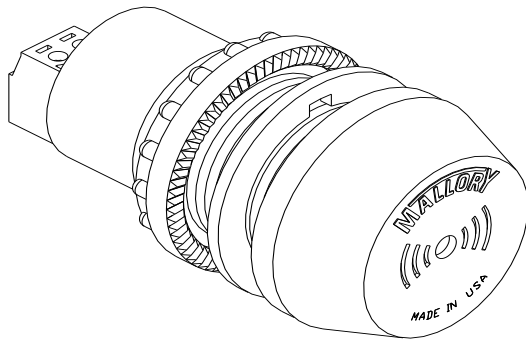

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Mallory Sonalert:](#)

[ZT120LACM1R](#) [ZT120LADP3R](#)