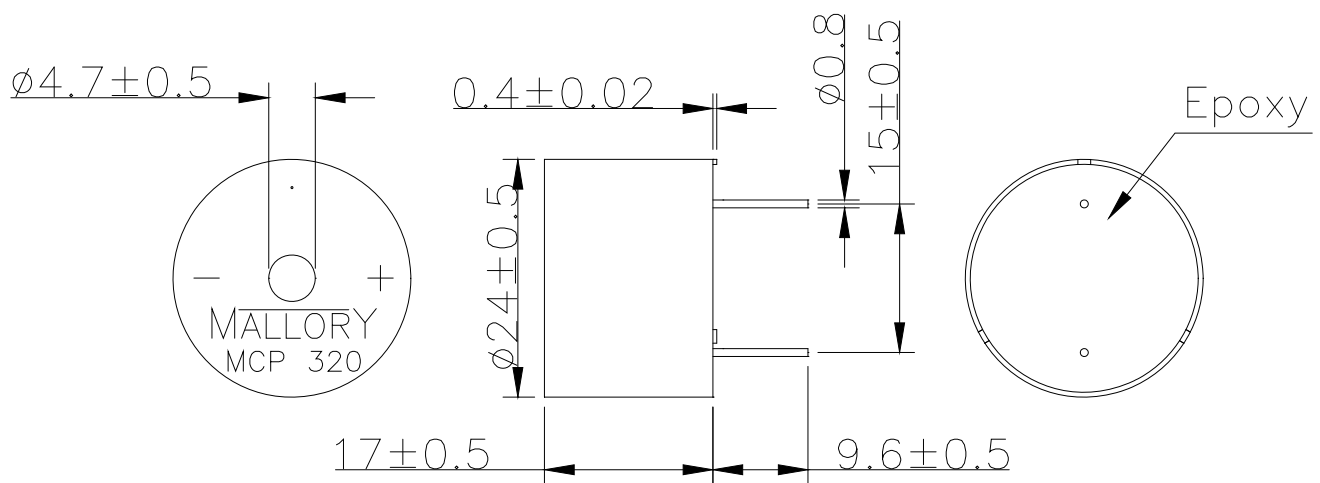


**OBSOLETE- See P/N MCP320Q****Specifications.**

Resonant Frequency (Hz)	3150 ±500
Operating Voltage (Vdc)	3 ~ 20
Rated Voltage (Vdc)	12
Current Consumption Max. (mA)	20 at Rated Voltage
Sound Pressure Level Min. (dB)	55 at 2 Feet at 3 Vdc 74 at 2 feet at 20 VDC
Tone/Pulse Rate (Hz)	Constant
Operating Temperature (°C)	-20 ~ +85
Storage Temperature (°C)	-30 ~ +130
Housing	PC UL-94V2 UL94HB plastic resin (Color: Black)
Leading Pin	Tin Plated Brass
Weight (Grams)	10
Options	For other options contact factory

**Dimensions:(units:mm)**

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Mallory Sonalert:](#)

[MCP320](#)