


2 Conductor Sub-Miniature Jack 2.5 ϕ - 4

161-068SP-EX



2 Conductor Sub-Miniature Mono Jack 2.5 ϕ - 4

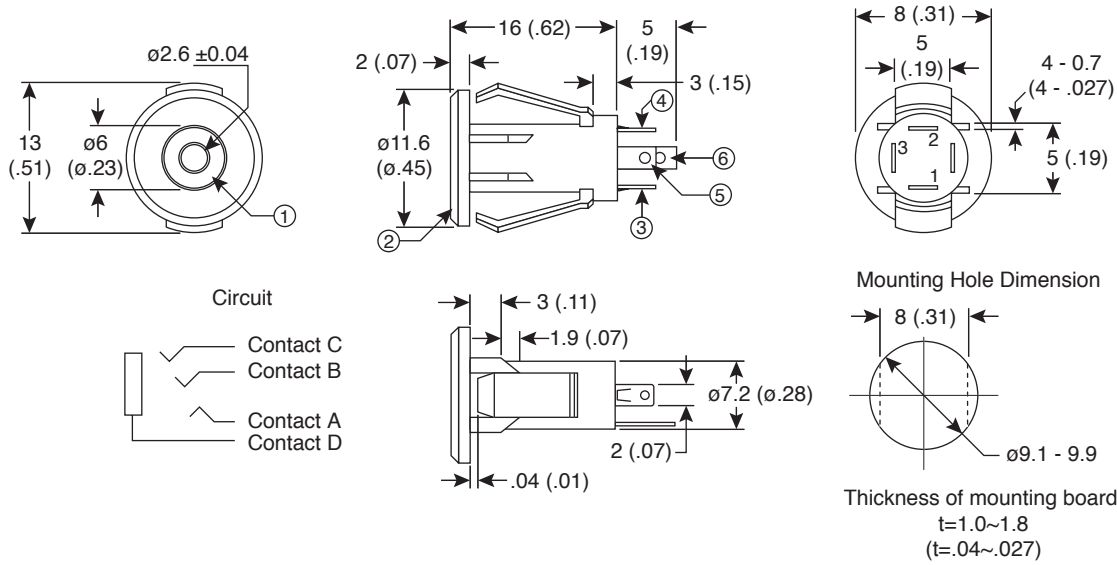

Part	Material	Finish
Contact D	BSR $t=0.3$	Ni
Contact C	FAB-EH $t=0.25$	Ni
Contact B	FAB-EH $t=0.25$	Ni
Contact A	FAB-EH $t=0.25$	Ni
Body	PA 66	
Metal	BSBM	Au

Dimensions: mm (In.)

SPECIFICATIONS	
Dielectric strength	500VAC for one minute
Contact Resistance:	50m Ω max.
Insulation Resistance:	100M Ω min. @ 500VDC
RoHS Compliant by Exemption	

Date Last Revised: 12-8-05

Available from Mouser Electronics
 1-800-346-6873
 www.mouser.com

KC-300956

161-068SP-EX

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Kobiconn:](#)

[161-068SP-EX](#)