



**E480232**

## Features

- AEC-Q101 Qualified
- For Surface Mount Applications in Order to Optimize Board Space
- Halogen Free
- Low Profile Package
- Unidirectional and Bidirectional Available, for Bidirectional Devices add 'C' Suffix to The pn#, i.e. SMAJP4KE12CAHE3
- Fast Response Time: Typical Less Than 1.0ps From 0 Volts to  $V_{BR}$  Minimum
- Moisture Sensitivity Level 1
- Epoxy Meets UL 94 V-0 Flammability Rating

## Mechanical Data

- Polarity: Color Band Denotes Positive end (cathode) Except Bidirectional
- Maximum Soldering Temperature: 260°C for 10 Seconds
- Manufacturing Code Added for Better Tracking
- CASE: JEDEC DO214AC
- Terminals: Plated Axial leads, Solderable Per MIL-STD-750, Methode 2026

## Maximum Ratings

 
 
- Operating Junction Temperature Range: -55°C to +175°C
- Storage Temperature Range: -55°C to +175°C
- Typical Thermal Resistance: 100°C/W Junction to Ambient

|                                                          |          |               |        |
|----------------------------------------------------------|----------|---------------|--------|
| Peak Pulse Power Surge Current with a 10/1000µs Waveform | $I_{PP}$ | See the Table | Note 1 |
| Peak Pulse Power Dissipation                             | $P_{PP}$ | 400W          | Note 1 |

Note:


1. Non-repetitive current pulse, per Fig.3 and derated above  $T_A=25^\circ\text{C}$  per Fig.4.
2. Mounted on 5.0mm<sup>2</sup> copper pads to each terminal.

Pin Configuration:




**400 Watt TVS**  
**12 to 100 Volts**

## SMA (DO-214AC) LEAD FRAME

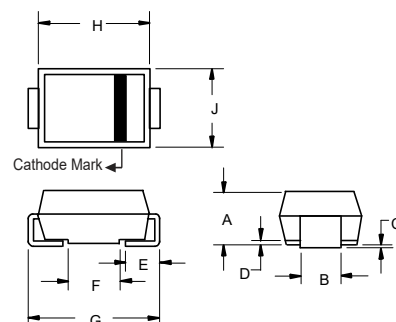

| DIM | INCHES |       | MM    |       | NOTE |
|-----|--------|-------|-------|-------|------|
|     | MIN    | MAX   | MIN   | MAX   |      |
| A   | 0.079  | 0.096 | 2.00  | 2.44  |      |
| B   | 0.050  | 0.064 | 1.27  | 1.63  |      |
| C   | 0.002  | 0.008 | 0.051 | 0.203 |      |
| D   | ---    | 0.020 | ---   | 0.51  |      |
| E   | 0.030  | 0.060 | 0.76  | 1.52  |      |
| F   | 0.065  | 0.091 | 1.65  | 2.32  |      |
| G   | 0.189  | 0.220 | 4.80  | 5.59  |      |
| H   | 0.157  | 0.181 | 4.00  | 4.60  |      |
| J   | 0.090  | 0.115 | 2.25  | 2.92  |      |

## SUGGESTED SOLDER PAD LAYOUT

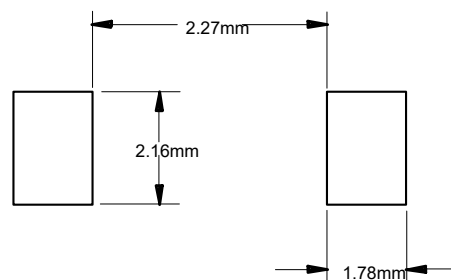

## Electrical Characteristics @ 25°C Unless Otherwise Specified

| MCC<br>PART NUMBER | REVERSE<br>STAND-OFF<br>VOLTAGE<br>$V_{WM}$ | BREAKDOWN VOLTAGE<br>$V_{(BR)} @ I_T$<br>(VOLTS) |        |            | MAXIMUM<br>CLAMPING<br>VOLTAGE @ $I_{PP}$ | PEAK<br>PULSE<br>CURRENT<br>$I_{PP}$ | MAXIMUM<br>REVERSE<br>LEAKAGE<br>@ $V_{WM}$<br>$I_D$ | MARKING CODE |
|--------------------|---------------------------------------------|--------------------------------------------------|--------|------------|-------------------------------------------|--------------------------------------|------------------------------------------------------|--------------|
|                    | (VOLTS)                                     | MIN                                              | MAX    | $I_T$ (mA) | (VOLTS)                                   | (AMPS)                               | $\mu A$                                              |              |
| SMAJP4KE12AHE3     | 10.20                                       | 11.40                                            | 12.60  | 1          | 16.7                                      | 24.6                                 | 5                                                    | 12A          |
| SMAJP4KE13AHE3     | 11.10                                       | 12.40                                            | 13.70  | 1          | 18.2                                      | 22.5                                 | 1                                                    | 13A          |
| SMAJP4KE15AHE3     | 12.80                                       | 14.30                                            | 15.80  | 1          | 21.2                                      | 19.3                                 | 1                                                    | 15A          |
| SMAJP4KE16AHE3     | 13.60                                       | 15.20                                            | 16.80  | 1          | 22.5                                      | 18.2                                 | 1                                                    | 16A          |
| SMAJP4KE18AHE3     | 15.30                                       | 17.10                                            | 18.90  | 1          | 25.5                                      | 16.1                                 | 1                                                    | 18A          |
| SMAJP4KE20AHE3     | 17.10                                       | 19.00                                            | 21.00  | 1          | 27.7                                      | 14.8                                 | 1                                                    | 20A          |
| SMAJP4KE22AHE3     | 18.80                                       | 20.90                                            | 23.10  | 1          | 30.6                                      | 13.4                                 | 1                                                    | 22A          |
| SMAJP4KE24AHE3     | 20.50                                       | 22.80                                            | 25.20  | 1          | 33.2                                      | 12.3                                 | 1                                                    | 24A          |
| SMAJP4KE27AHE3     | 23.10                                       | 25.70                                            | 28.40  | 1          | 37.5                                      | 10.9                                 | 1                                                    | 27A          |
| SMAJP4KE30AHE3     | 25.60                                       | 28.50                                            | 31.50  | 1          | 41.4                                      | 9.9                                  | 1                                                    | 30A          |
| SMAJP4KE33AHE3     | 28.20                                       | 31.40                                            | 34.70  | 1          | 45.7                                      | 9.0                                  | 1                                                    | 33A          |
| SMAJP4KE36AHE3     | 30.80                                       | 34.20                                            | 37.80  | 1          | 49.9                                      | 8.2                                  | 1                                                    | 36A          |
| SMAJP4KE39AHE3     | 33.30                                       | 37.10                                            | 41.00  | 1          | 53.9                                      | 7.6                                  | 1                                                    | 39A          |
| SMAJP4KE43AHE3     | 36.80                                       | 40.90                                            | 45.20  | 1          | 59.3                                      | 6.9                                  | 1                                                    | 43A          |
| SMAJP4KE47AHE3     | 40.20                                       | 44.70                                            | 49.40  | 1          | 64.8                                      | 6.3                                  | 1                                                    | 47A          |
| SMAJP4KE51AHE3     | 43.60                                       | 48.50                                            | 53.60  | 1          | 70.1                                      | 5.8                                  | 1                                                    | 51A          |
| SMAJP4KE56AHE3     | 47.80                                       | 53.20                                            | 58.80  | 1          | 77.0                                      | 5.3                                  | 1                                                    | 56A          |
| SMAJP4KE62AHE3     | 53.00                                       | 58.90                                            | 65.10  | 1          | 85.0                                      | 4.8                                  | 1                                                    | 62A          |
| SMAJP4KE68AHE3     | 58.10                                       | 64.60                                            | 71.40  | 1          | 92.0                                      | 4.5                                  | 1                                                    | 68A          |
| SMAJP4KE75AHE3     | 64.10                                       | 71.30                                            | 78.80  | 1          | 103.0                                     | 4.0                                  | 1                                                    | 75A          |
| SMAJP4KE82AHE3     | 70.10                                       | 77.90                                            | 86.10  | 1          | 113.0                                     | 3.6                                  | 1                                                    | 82A          |
| SMAJP4KE91AHE3     | 77.80                                       | 86.50                                            | 95.50  | 1          | 125.0                                     | 3.3                                  | 1                                                    | 91A          |
| SMAJP4KE100AHE3    | 85.50                                       | 95.00                                            | 105.00 | 1          | 137.0                                     | 3.0                                  | 1                                                    | 100A         |
| SMAJP4KE12CAHE3    | 10.20                                       | 11.40                                            | 12.60  | 1          | 16.7                                      | 24.6                                 | 5                                                    | 12C          |
| SMAJP4KE13CAHE3    | 11.10                                       | 12.40                                            | 13.70  | 1          | 18.2                                      | 22.5                                 | 1                                                    | 13C          |
| SMAJP4KE15CAHE3    | 12.80                                       | 14.30                                            | 15.80  | 1          | 21.2                                      | 19.3                                 | 1                                                    | 15C          |
| SMAJP4KE16CAHE3    | 13.60                                       | 15.20                                            | 16.80  | 1          | 22.5                                      | 18.2                                 | 1                                                    | 16C          |
| SMAJP4KE18CAHE3    | 15.30                                       | 17.10                                            | 18.90  | 1          | 25.5                                      | 16.1                                 | 1                                                    | 18C          |
| SMAJP4KE20CAHE3    | 17.10                                       | 19.00                                            | 21.00  | 1          | 27.7                                      | 14.8                                 | 1                                                    | 20C          |
| SMAJP4KE22CAHE3    | 18.80                                       | 20.90                                            | 23.10  | 1          | 30.6                                      | 13.4                                 | 1                                                    | 22C          |
| SMAJP4KE24CAHE3    | 20.50                                       | 22.80                                            | 25.20  | 1          | 33.2                                      | 12.3                                 | 1                                                    | 24C          |
| SMAJP4KE27CAHE3    | 23.10                                       | 25.70                                            | 28.40  | 1          | 37.5                                      | 10.9                                 | 1                                                    | 27C          |
| SMAJP4KE30CAHE3    | 25.60                                       | 28.50                                            | 31.50  | 1          | 41.4                                      | 9.9                                  | 1                                                    | 30C          |
| SMAJP4KE33CAHE3    | 28.20                                       | 31.40                                            | 34.70  | 1          | 45.7                                      | 9.0                                  | 1                                                    | 33C          |
| SMAJP4KE36CAHE3    | 30.80                                       | 34.20                                            | 37.80  | 1          | 49.9                                      | 8.2                                  | 1                                                    | 36C          |
| SMAJP4KE39CAHE3    | 33.30                                       | 37.10                                            | 41.00  | 1          | 53.9                                      | 7.6                                  | 1                                                    | 39C          |
| SMAJP4KE43CAHE3    | 36.80                                       | 40.90                                            | 45.20  | 1          | 59.3                                      | 6.9                                  | 1                                                    | 43C          |
| SMAJP4KE47CAHE3    | 40.20                                       | 44.70                                            | 49.40  | 1          | 64.8                                      | 6.3                                  | 1                                                    | 47C          |
| SMAJP4KE51CAHE3    | 43.60                                       | 48.50                                            | 53.60  | 1          | 70.1                                      | 5.8                                  | 1                                                    | 51C          |
| SMAJP4KE56CAHE3    | 47.80                                       | 53.20                                            | 58.80  | 1          | 77.0                                      | 5.3                                  | 1                                                    | 56C          |
| SMAJP4KE62CAHE3    | 53.00                                       | 58.90                                            | 65.10  | 1          | 85.0                                      | 4.8                                  | 1                                                    | 62C          |
| SMAJP4KE68CAHE3    | 58.10                                       | 64.60                                            | 71.40  | 1          | 92.0                                      | 4.5                                  | 1                                                    | 68C          |
| SMAJP4KE75CAHE3    | 64.10                                       | 71.30                                            | 78.80  | 1          | 103.0                                     | 4.0                                  | 1                                                    | 75C          |
| SMAJP4KE82CAHE3    | 70.10                                       | 77.90                                            | 86.10  | 1          | 113.0                                     | 3.6                                  | 1                                                    | 82C          |
| SMAJP4KE91CAHE3    | 77.80                                       | 86.50                                            | 95.50  | 1          | 125.0                                     | 3.3                                  | 1                                                    | 91C          |
| SMAJP4KE100CAHE3   | 85.50                                       | 95.00                                            | 105.00 | 1          | 137.0                                     | 3.0                                  | 1                                                    | 100C         |

Note:

1. For Bi-directional type having  $V_{WM}$  of 10 volts and less, the  $I_R$  limit is double.
2. The available parts are "A" type only, the parts without A ( $V_{BR}$  is  $\pm 10\%$ ) is not available.

## Curve Characteristics

Fig. 1 - Peak Pulse Power Rating Curve

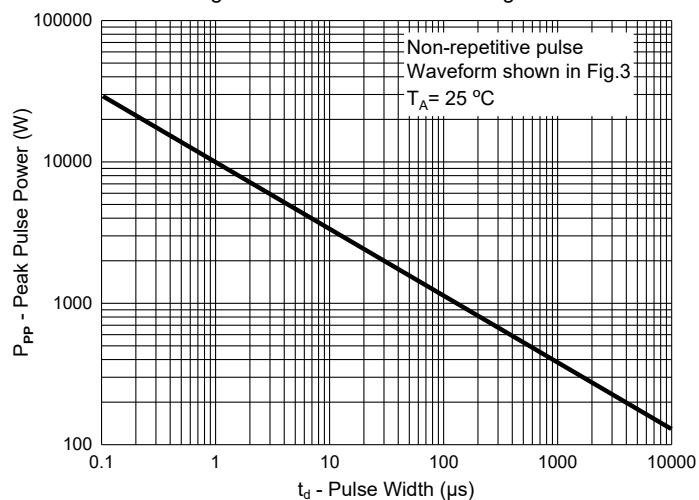


Fig. 2 - Typical Junction Capacitance

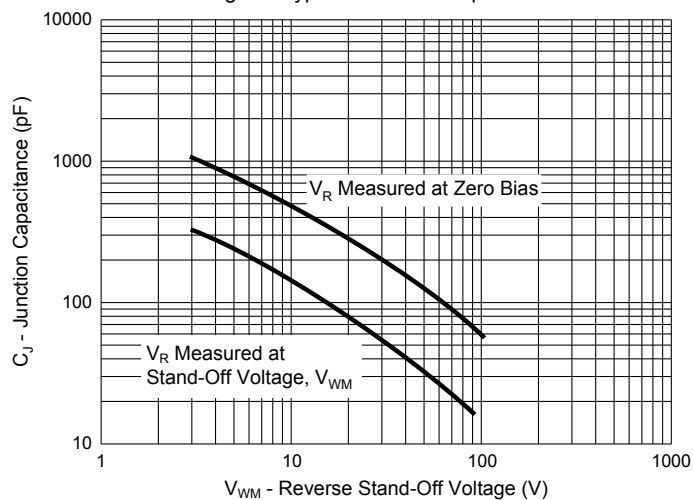


Fig. 3 - Pulse Waveform


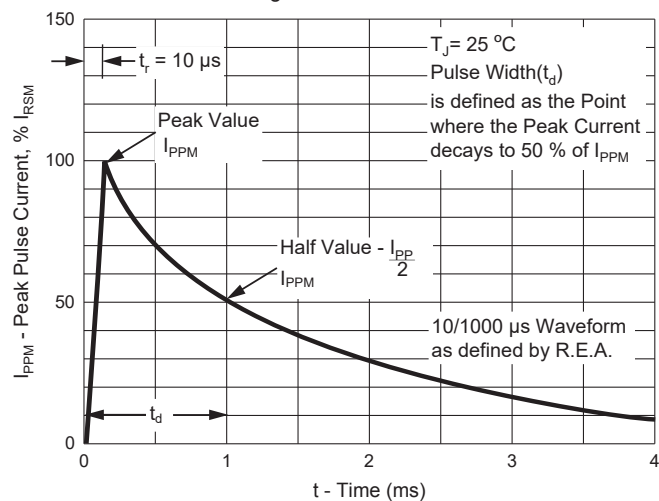


Fig. 4 - Pulse Derating Curve

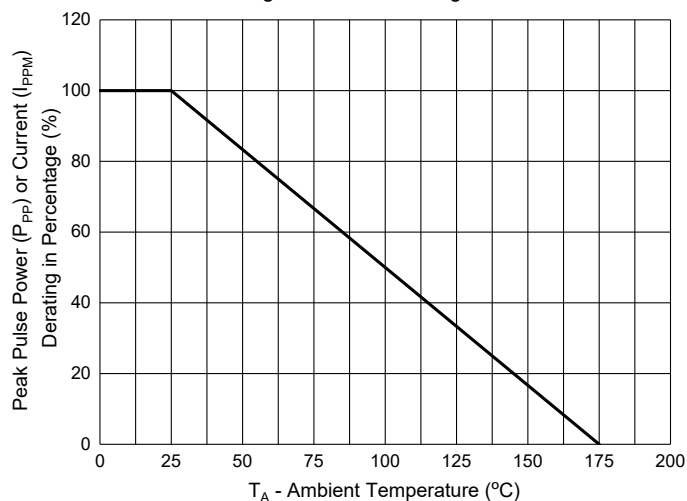

## Ordering Information

| Device         | Packing              |
|----------------|----------------------|
| Part Number-TP | Tape&Reel:5Kpcs/Reel |

Note : Adding "-HF" Suffix For Halogen Free, eg. Part Number-TP-HF

### \*\*\*IMPORTANT NOTICE\*\*\*

**Micro Commercial Components Corp.** reserves the right to make changes without further notice to any product herein to make corrections, modifications , enhancements , improvements , or other changes . **Micro Commercial Components Corp** . does not assume any liability arising out of the application or use of any product described herein; neither does it convey any license under its patent rights ,nor the rights of others . The user of products in such applications shall assume all risks of such use and will agree to hold **Micro Commercial Components Corp** . and all the companies whose products are represented on our website, harmless against all damages.

### \*\*\*LIFE SUPPORT\*\*\*

MCC's products are not authorized for use as critical components in life support devices or systems without the express written approval of Micro Commercial Components Corporation.

### \*\*\*CUSTOMER AWARENESS\*\*\*

Counterfeiting of semiconductor parts is a growing problem in the industry. Micro Commercial Components (MCC) is taking strong measures to protect ourselves and our customers from the proliferation of counterfeit parts. MCC strongly encourages customers to purchase MCC parts either directly from MCC or from Authorized MCC Distributors who are listed by country on our web page cited below. Products customers buy either from MCC directly or from Authorized MCC Distributors are genuine parts, have full traceability, meet MCC's quality standards for handling and storage. **MCC will not provide any warranty coverage or other assistance for parts bought from Unauthorized Sources.** MCC is committed to combat this global problem and encourage our customers to do their part in stopping this practice by buying direct or from authorized distributors.

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

## Micro Commercial Components (MCC):

|                                           |                                            |                                          |                                           |
|-------------------------------------------|--------------------------------------------|------------------------------------------|-------------------------------------------|
| <a href="#"><u>SMAJP4KE100AHE3-TP</u></a> | <a href="#"><u>SMAJP4KE100CAHE3-TP</u></a> | <a href="#"><u>SMAJP4KE12AHE3-TP</u></a> | <a href="#"><u>SMAJP4KE12CAHE3-TP</u></a> |
| <a href="#"><u>SMAJP4KE13AHE3-TP</u></a>  | <a href="#"><u>SMAJP4KE13CAHE3-TP</u></a>  | <a href="#"><u>SMAJP4KE82AHE3-TP</u></a> | <a href="#"><u>SMAJP4KE82CAHE3-TP</u></a> |
| <a href="#"><u>SMAJP4KE91AHE3-TP</u></a>  | <a href="#"><u>SMAJP4KE91CAHE3-TP</u></a>  | <a href="#"><u>SMAJP4KE62AHE3-TP</u></a> | <a href="#"><u>SMAJP4KE62CAHE3-TP</u></a> |
| <a href="#"><u>SMAJP4KE68AHE3-TP</u></a>  | <a href="#"><u>SMAJP4KE68CAHE3-TP</u></a>  | <a href="#"><u>SMAJP4KE75AHE3-TP</u></a> | <a href="#"><u>SMAJP4KE75CAHE3-TP</u></a> |
| <a href="#"><u>SMAJP4KE47AHE3-TP</u></a>  | <a href="#"><u>SMAJP4KE47CAHE3-TP</u></a>  | <a href="#"><u>SMAJP4KE51AHE3-TP</u></a> | <a href="#"><u>SMAJP4KE51CAHE3-TP</u></a> |
| <a href="#"><u>SMAJP4KE56AHE3-TP</u></a>  | <a href="#"><u>SMAJP4KE56CAHE3-TP</u></a>  | <a href="#"><u>SMAJP4KE36AHE3-TP</u></a> | <a href="#"><u>SMAJP4KE36CAHE3-TP</u></a> |
| <a href="#"><u>SMAJP4KE39AHE3-TP</u></a>  | <a href="#"><u>SMAJP4KE39CAHE3-TP</u></a>  | <a href="#"><u>SMAJP4KE43AHE3-TP</u></a> | <a href="#"><u>SMAJP4KE43CAHE3-TP</u></a> |
| <a href="#"><u>SMAJP4KE27AHE3-TP</u></a>  | <a href="#"><u>SMAJP4KE27CAHE3-TP</u></a>  | <a href="#"><u>SMAJP4KE30AHE3-TP</u></a> | <a href="#"><u>SMAJP4KE30CAHE3-TP</u></a> |
| <a href="#"><u>SMAJP4KE33AHE3-TP</u></a>  | <a href="#"><u>SMAJP4KE33CAHE3-TP</u></a>  | <a href="#"><u>SMAJP4KE20AHE3-TP</u></a> | <a href="#"><u>SMAJP4KE20CAHE3-TP</u></a> |
| <a href="#"><u>SMAJP4KE22AHE3-TP</u></a>  | <a href="#"><u>SMAJP4KE22CAHE3-TP</u></a>  | <a href="#"><u>SMAJP4KE24AHE3-TP</u></a> | <a href="#"><u>SMAJP4KE24CAHE3-TP</u></a> |
| <a href="#"><u>SMAJP4KE15AHE3-TP</u></a>  | <a href="#"><u>SMAJP4KE15CAHE3-TP</u></a>  | <a href="#"><u>SMAJP4KE16AHE3-TP</u></a> | <a href="#"><u>SMAJP4KE16CAHE3-TP</u></a> |
| <a href="#"><u>SMAJP4KE18AHE3-TP</u></a>  | <a href="#"><u>SMAJP4KE18CAHE3-TP</u></a>  |                                          |                                           |