

MT series

Sealed selector switches

Distinctive features - Specifications

U1603R2US



- ☐ Environmentally sealed selector switch (IP68)
- ☐ Multiple functions available
- ☐ Various contact materials that allow usage from dry circuit applications up to 4A


ELECTRICAL AND GENERAL SPECIFICATIONS

- Max. current/voltage rating with resistive load
 - Silver contacts (A) : 4A 30VDC
 - Gold plated silver contacts (AD) : 4A 30VDC (gold plating withstands up to 100mA 30VDC)
 - Gold plated brass contacts (CD) : 0,4VA 20VAC or DC
- Minimal load :
 - A contacts : 50mA 10VDC
 - AD and CD contacts : 10mA 50mV - 10μA 5V
- Initial contact resistance : 10mΩ max.
- Insulation resistance : 1.000 MΩ min. at 500VDC
- Dielectric strength : 1.000 Vrms 50Hz min. between terminals
1.500 Vrms 50Hz min. between terminals and frame
- Contact bounce : 2ms max.
- Electrical life at full load : 50,000 cycles
- Low level or mechanical life : 100,000 cycles
- Panel thickness : 11.5 mm (.452) max.
- Operating temperature : -40°C to +85°C


MATERIALS

- Actuator : 6/6 nylon
soft touch: thermoplastic elastomer over 6/6 nylon
- Bushing : brass, chrome plated
- Contacts
 - A: silver
 - AD: silver, gold plated
 - CD: brass, gold plated
- Terminal seal : epoxy

TERMINALS

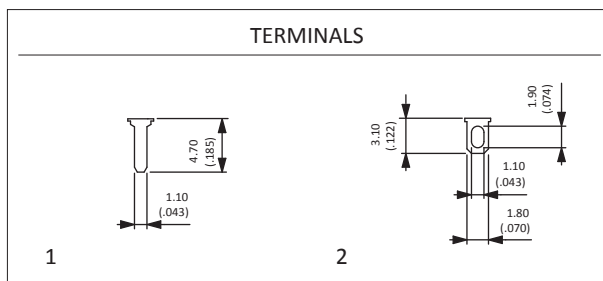

PANEL CUT-OUT

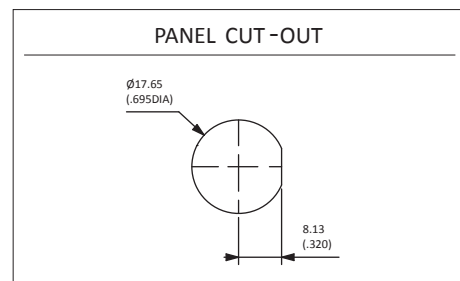

Dimensions: First dimensions are in mm while inches are shown as bracketed numbers.



Mounting accessories: Standard hardware supplied : 1 hex nut 20.64 mm (.813) across flats and 1 sealing gasket.



Packaging unit: 40 pieces per tray

Note: The company reserves the right to change specifications without notice.


MT series

Sealed selector switches


Distinctive features - Specifications

MT															
SERIES		Bushing finish				Electrical functions				Terminals		Contact materials		Actuators	
Blank	Bright chrome	6 ON - ON				1 Straight PC		A Silver		2 Rocker, black					
G	Matte black (std)	9 ON OFF ON				2 Solder lug		AD Gold plated silver		3 Winged, black					
		7 MOM OFF MOM						CD Gold plated brass		4 Paddle, black					
		8 ON OFF MOM								5 Winged, soft touch, black					
		2 ON - MOM								6 Paddle, soft touch, black					
										Other : on request.					


Sealed selector switch with rocker actuator

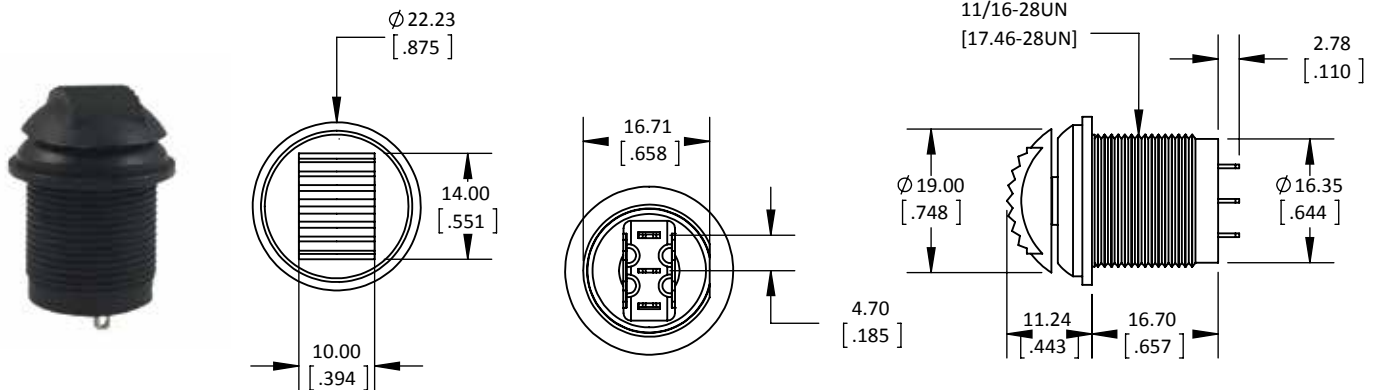

Sealed selector switch with winged actuator

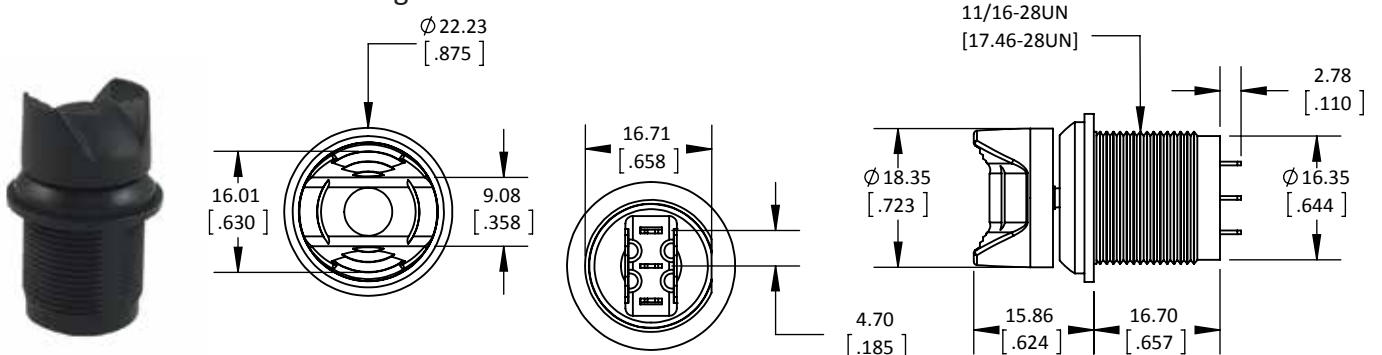

Sealed selector switch with paddle actuator

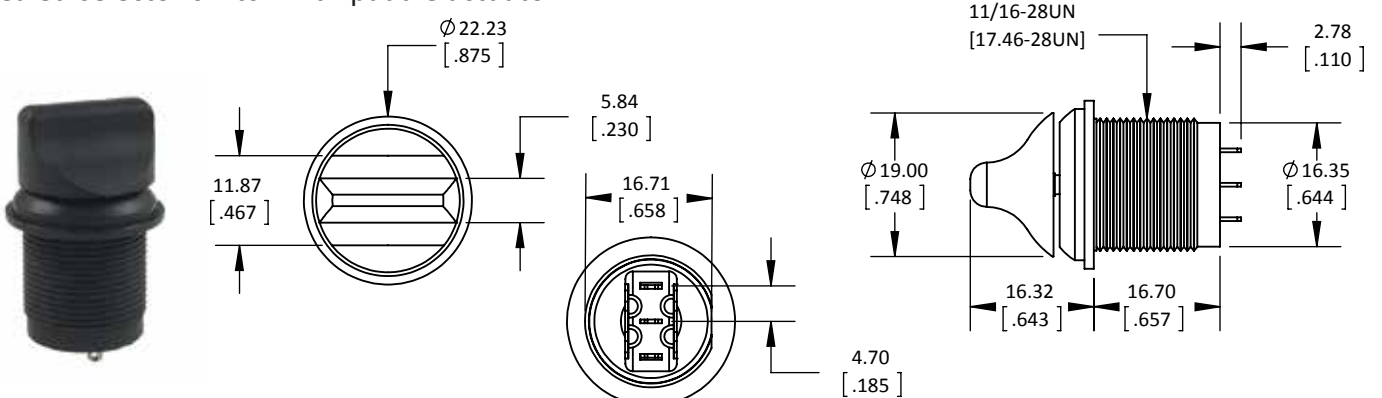

Note: The company reserves the right to change specifications without notice.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Apem:](#)

[MTG22AD2](#) [MTG62AD2](#) [MTG72AD2](#) [MTG82AD2](#) [MTG92AD2](#) [MTG82A2](#) [MTG72A2](#) [MTG72AD3](#) [MTG72AD4](#)
[MTG72A3](#) [MTG62A2](#) [MTG92A2](#) [MTG62A3](#) [MTG62A4](#) [MTG62AD3](#) [MTG62AD4](#) [MTG62AD5](#) [MTG62AD6](#)
[MTG62CD5](#) [MTG72A4](#) [MTG72A6](#) [MTG72AD5](#) [MTG72AD6](#) [MTG82AD3](#) [MTG82AD4](#) [MTG82AD5](#) [MTG82AD6](#)
[MTG92A3](#) [MTG92A4](#) [MTG92AD3](#) [MTG92AD4](#) [MTG92AD5](#) [MTG92AD6](#) [MTG72CD2](#)