 


9000 SERIES - MINIATURE MOMENTARY PUSHBUTTON SWITCHES

OPTION DRAWINGS & SPECIAL OPTIONS


CAPS Note: replace last '0' in p/n with color code. (order separately)




U900




U1140

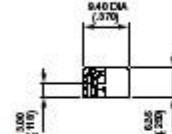


U1720

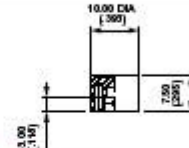


U480 Standard

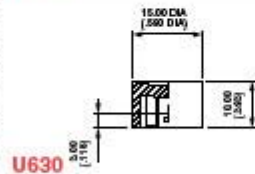

U630

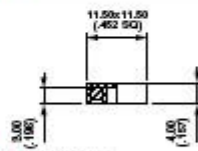

U2430 Square

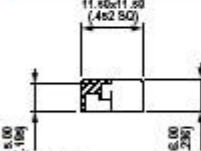


U2020 Square


Colors

1	blue
2	black
3	green
4	grey
5	yellow
6	red
7/1	white
9	orange

DRESS NUTS Chrome plated. Order separately.

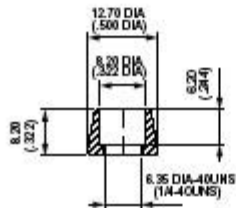

U1636 (for cap U1140)

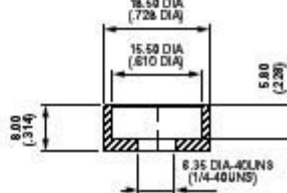

U825 (for cap U630)



U840 (for cap U480)

SPECIAL OPTIONS

F Tin plated terminals (for p.c. terminals only).

X601 Silver plated brass contacts
Contact ratings: 0.2A 250VAC, 0.4A 125VAC or 0.5A 30VDC
Electric life: 20,000 cycles minimum.
Minimum quantity: 5,000 pieces.

SPECIFICATIONS SUBJECT TO CHANGE WITHOUT NOTICE

C

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Apem:](#)

[U1727](#) [U907](#) [U1141](#) [U1143](#) [U1144](#) [U1145](#) [U1721](#) [U1722](#) [U1723](#) [U1726](#) [U1727/1](#) [U2022](#) [U2026](#) [U2432](#)
[U2436](#) [U632](#) [U825](#) [U840](#) [U902](#) [U906](#) [U486](#) [U4322](#) [U4316](#) [U482](#) [U1142](#) [U1146](#) [U1725](#) [U2027/1](#) [U1747](#) [U841](#)
[U2433](#) [U904](#) [U1147/1](#) [U2023](#) [U2024](#) [U2434](#) [U903](#) [U1729](#) [U2021](#) [U2029](#) [U907/1](#) [U1149](#) [U1724](#) [U2025](#)
[U2431](#) [U2439](#) [U2437/1](#) [U909](#) [U2435](#) [U905](#)