


N SERIES

PUSH-PULL SWITCHES

Panel cut-out Ø12

- Latching double pole changeover
- Ø24mm diameter operating button
- Selection of button colours
- Solder lug terminals

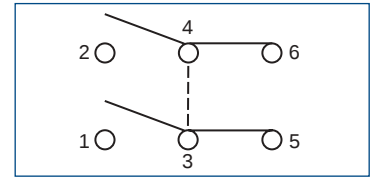


General Specifications

Panel cut-out	: 12mm dia.
Actuator diameter	: 24mm
Travel	: 2.3mm
Operating temperature	: -20°C – +70°C
Panel thickness	: 8mm max.
Switch terminals	: Solder lug

Electrical Specifications

Electrical function	: Double pole changeover
Maximum rating	: 2A, 250V AC
Contact resistance	: 10 milliOhms max
Electrical life	: 10,000 cycles at full load

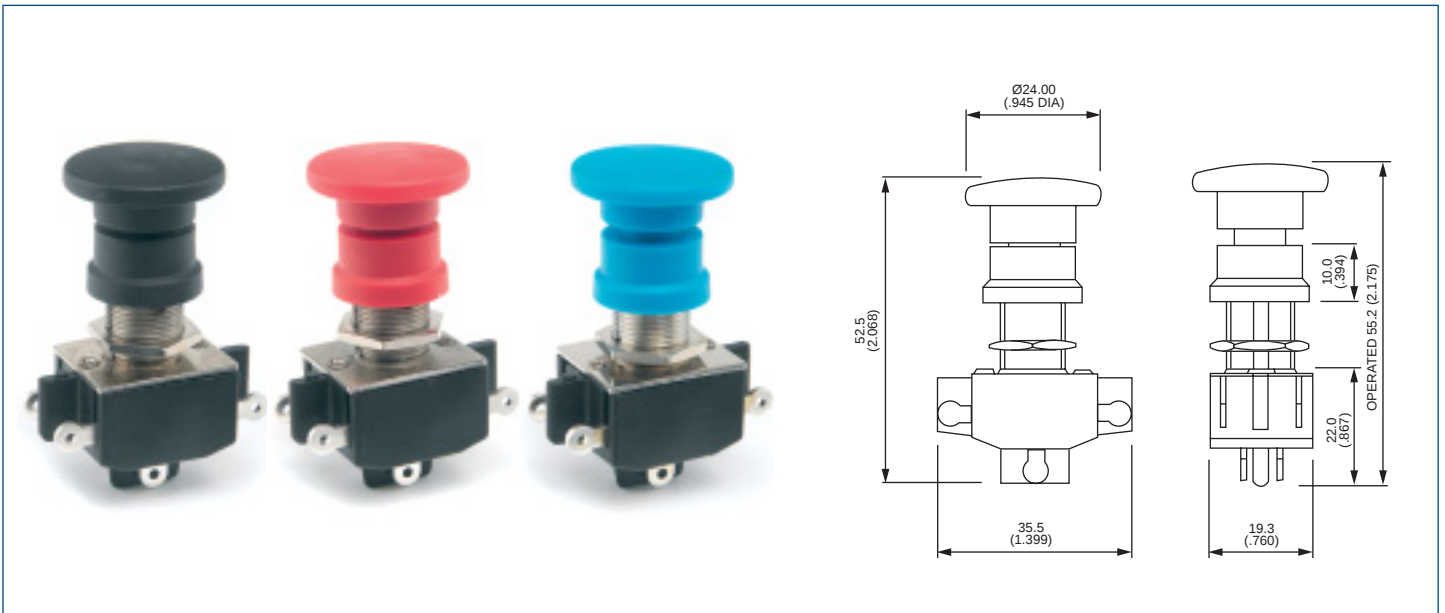

Description	Part No
Black plunger	N46A
Red plunger	N46B
Yellow plunger	N46D
Green plunger	N46E
Blue plunger	N46F

Options available

- 40mm head version
- Metal head version
- Custom printing on plunger please contact APEM components

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Apem:](#)

[N46A](#)