

8000 series

Momentary or alternate action pushbutton switches

Distinctive features and specifications

UG1410A



❑ Bushing Ø 6,35 (1/4) and Ø 11,9 (15/32)

❑ UL approved

ELECTRICAL SPECIFICATIONS

- Max. current/voltage rating with resistive load :
 - silver contacts : 4A 30VDC
 - gold plated contacts : 0,4VA max. 20VAC or DC
- Initial contact resistance : 10 mΩ max.
- Insulation resistance : 1.000 MΩ min. at 500VDC
- Dielectric strength :
 - 1.000 Vrms 50 Hz min. between terminals
 - 2.000 Vrms 50 Hz min. between terminals and frame
- Electrical life : 30.000 cycles at full load

MATERIALS

- Case : diallylphthalate (DAP)
- Actuator : brass, nickel plated
- Bushing : brass, nickel plated
- Housing : stainless steel
- Contacts
 - A** : silver
 - AD** : silver, gold plated
 - CD** : brass, gold plated
- Terminal seal : epoxy

GENERAL SPECIFICATIONS

- Torque : 1,25 Nm (.922 Ft.lb) max. applied to nut
- Total travel : 2,70 mm (.106)
- Operating temperature :
 - 40°C to +85°C

AGENCY APPROVAL



3A 250VAC, 6A 125VAC

Availability : consult factory for details of approved models.


Marking : to order switches marked UL, complete appropriate box of ordering format.

The company reserves the right to change specifications without notice.

8000 series

Momentary or alternate action pushbutton switches

Overview

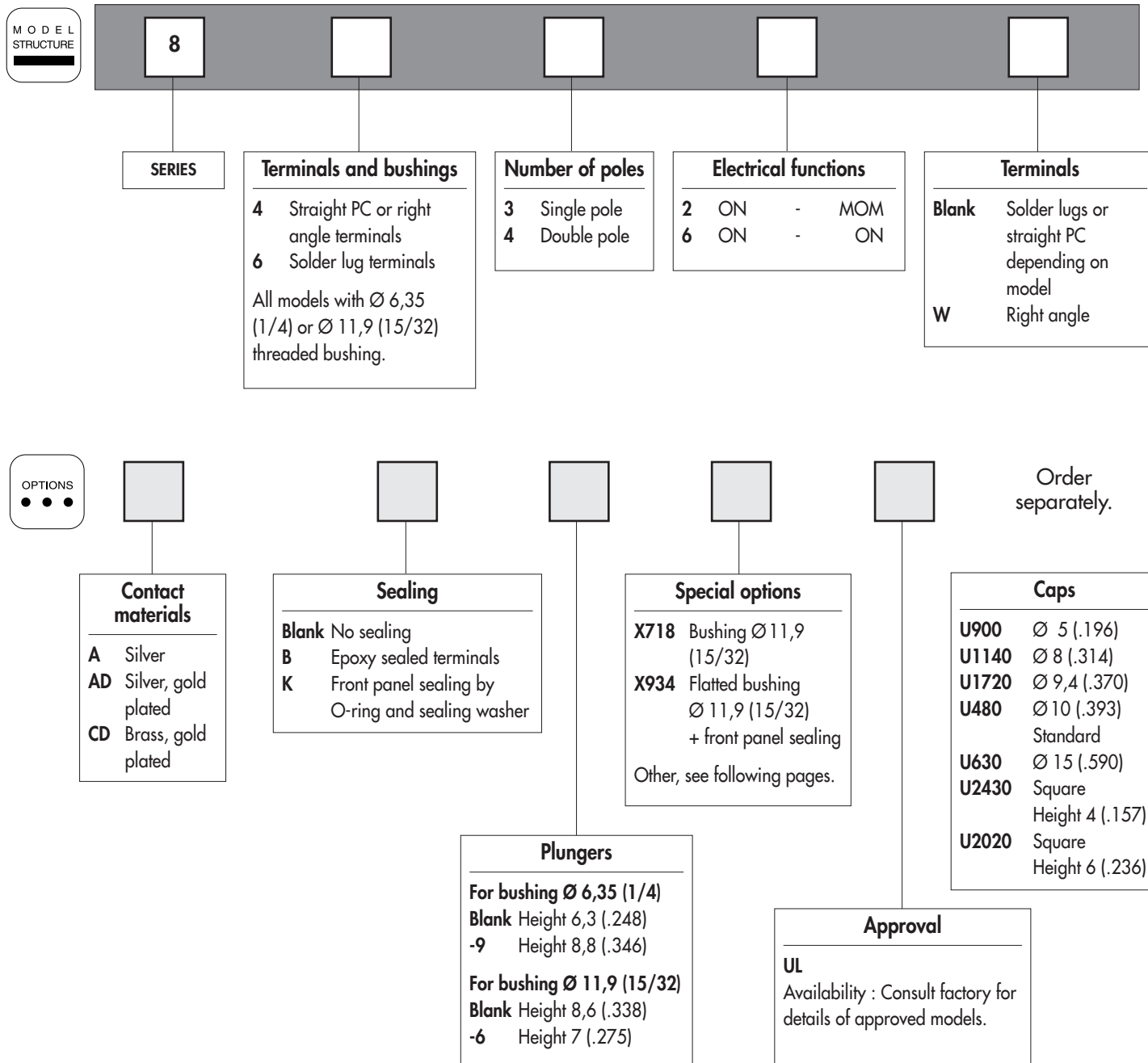

ABOUT THIS SERIES

On the following pages, you will find successively :

- model structure of switches
- options in the same order as in above chart

Dimensions : first dimensions are in mm while inches are shown as bracketed numbers.



Sealing boots are available to protect the switches against dust and water. They are presented in section H.



Mounting accessories : standard hardware supplied with all models : 2 hex nuts 8 mm (.314) across flats, 1 locking ring and 1 lockwasher.

Standard and special hardware available are presented in section I.




Packaging unit : 50 pieces, except 8000W (25 pieces).




8000 series

Momentary or alternate action pushbutton switches

PANEL CUT-OUT

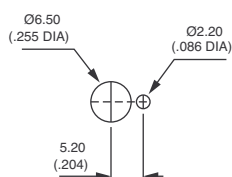

Standard

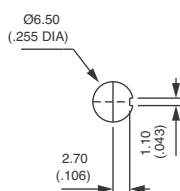

With K sealing option

CONTACT MATERIALS



A	Silver
AD	Silver, gold plated
CD	Brass, gold plated

SEALING




Blank No sealing

B Epoxy sealed terminals

K Front panel sealing by one O-ring and sealing washer. Protects the switch against water and dust. Panel seal withstands 1 bar pressure.

KB Combined sealings

Sealing boot : see section H.

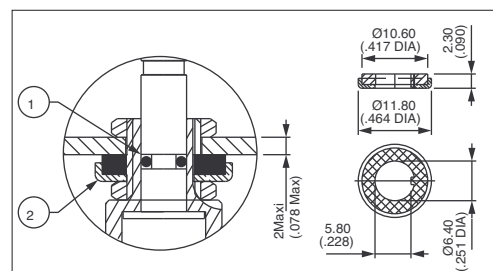

- ① O-ring
- ② Sealing washer

 
8000 series

Momentary or alternate action pushbutton switches

OPTIONS




PLUNGERS




For Ø 6,35 (1/4) bushing

Dash compulsory before plunger code.

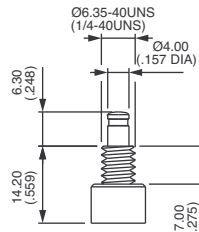


Blank

Standard

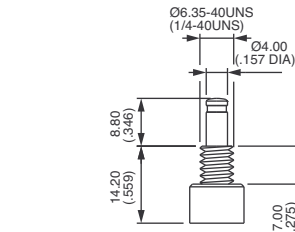


-9

For Ø 11,9 (15/32) bushing (X718 models)

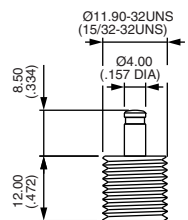


Blank

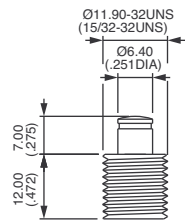

-6

 
SPECIAL OPTIONS



X601 Silver plated brass contacts

Current/voltage rating for an electrical life of 20.000 cycles : 0,5A 30VDC.
Minimum quantity : 5.000 pieces per model and shipment.


X718 Bushing Ø 11,9 (15/32)
For all basic models (solder lug straight PC or right angle terminals)
Available with plungers 13 and 6.
K sealing option available.

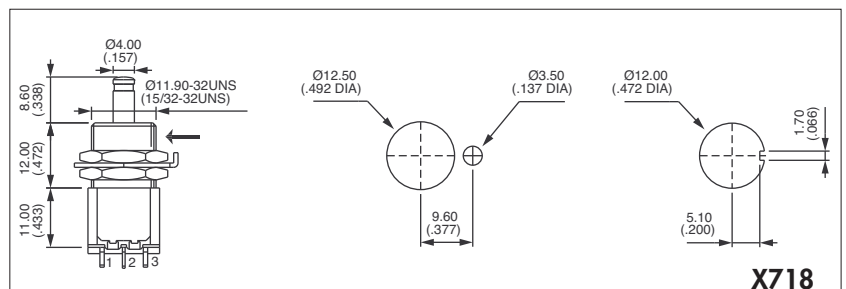

X718

X748 Snap-in mounting. Consult factory
Panel cut-out 15 x 12,5 (.59 x .492)

X934 Flatted bushing Ø 11,9 (15/32) + sealing by two O-rings
(for plunger -6 only). Epoxy sealed terminals.

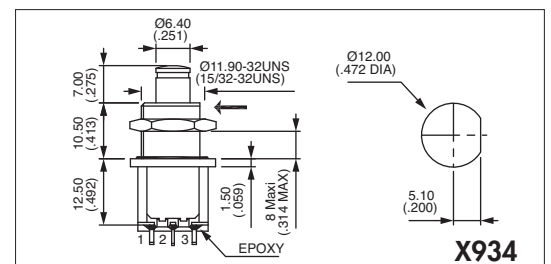


X934



8000 series

Momentary or alternate action pushbutton switches

 APPROVAL



UL






Availability : consult factory for details of approved models.

Marking : to order switches marked UL, complete above box with "UL".




CAPS

Order separately.

The caps below are for Ø 4 mm plungers (standard and -9), except U2600.

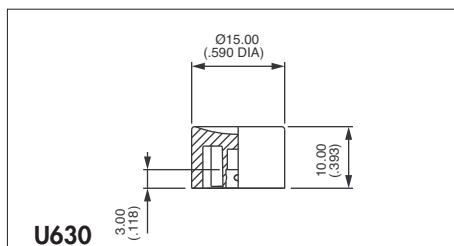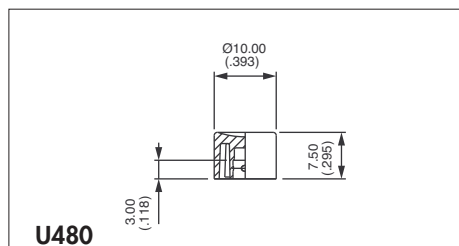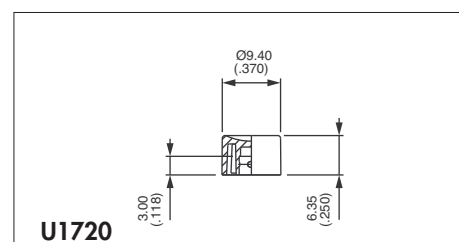
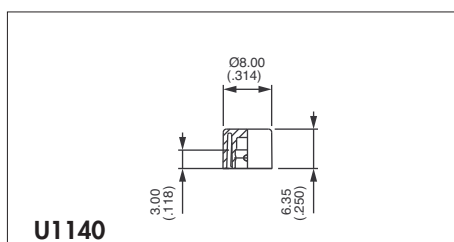
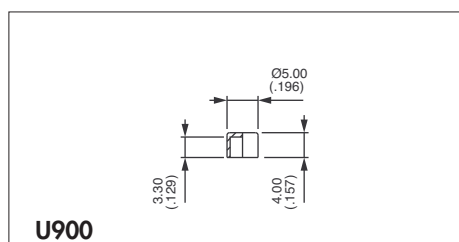


Cap colours	
Replace last "0" by number	
1	blue
1/4	dark blue
2	black
3	green
4	grey
5	yellow
6	red
7	ivory
7/1	white
9	orange

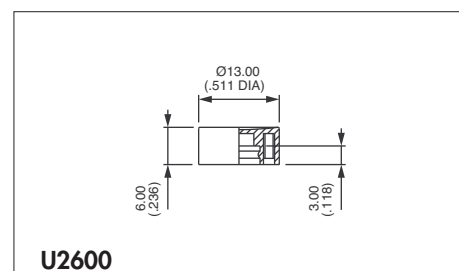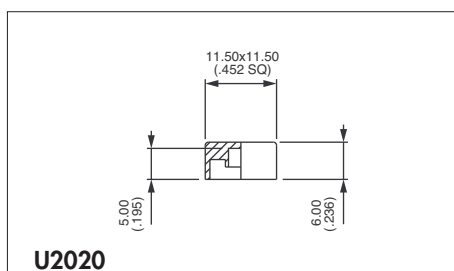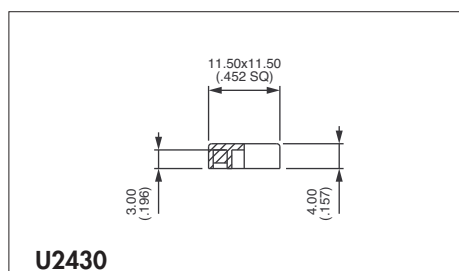

DRESS NUTS

Chrome plated. Order separately.

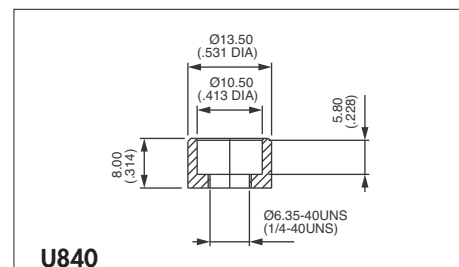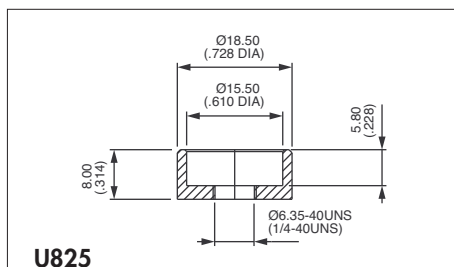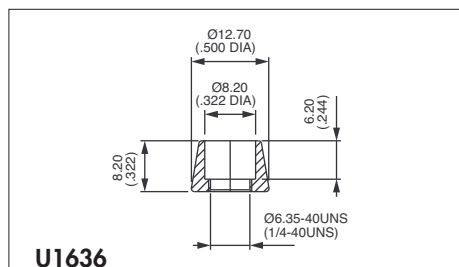

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Apem:](#)

[8636ADKB](#)