

9400-9600 series

Momentary pushbutton switches



DISTINCTIVE FEATURES

Two case lengths

Three electrical functions

Sealing options

Model X1146 with Ø 16 (.630) bushing



ELECTRICAL SPECIFICATIONS

- Max. current/voltage rating with resistive load :
 - silver contact (A) : 1 A 30 VDC
 - gold plated contacts (CD) : 100 mA 30 VDC
- Initial contact resistance : 50 mΩ max.
- Insulation resistance : 1,000 MΩ min. at 500 VDC
- Dielectric strength :
 - 1,000 Vrms 50 Hz min. between terminals
 - 1,500 Vrms 50 Hz min. between terminals and frame
- Electrical life : 250,000 cycles



GENERAL SPECIFICATIONS

- Total travel :

9600-9400-9400Y		9600N-9400N
Functions 3 and 5	Function 2	Function 3
1.3 mm	2 mm	0.9 mm

- Torque : 1.25 Nm (.922 Ft.lb) max. applied to nut
- Operating temperature : -30 °C to +65 °C (-22 °F to +149 °F)



MATERIALS

- Case : thermoplastic UL94-V0
- Actuator : polyamide, glass filled
- Bushing : brass, nickel plated
- Contacts :
 - A : silver
 - CD : brass, gold plated
- Terminal seal : epoxy

APEM products may be recycled at end-of-life for the re-claiming of valuable metal components.

The company reserves the right to change specifications without notice.




9400-9600 series


Momentary pushbutton switches




PANEL CUT-OUT

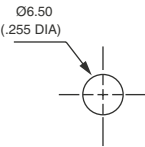


TERMINALS

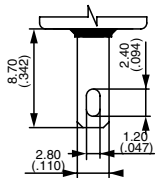

9600Z1

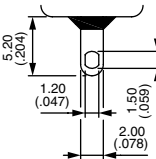


9600

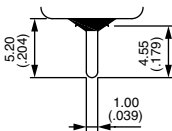


9400



 ELECTRICAL FUNCTIONS



Function 2 (NC)

 

Function 3 (NO)





Function 5 (combined)

9400-9600 series

Momentary pushbutton switches




BUILD YOUR PART NUMBER

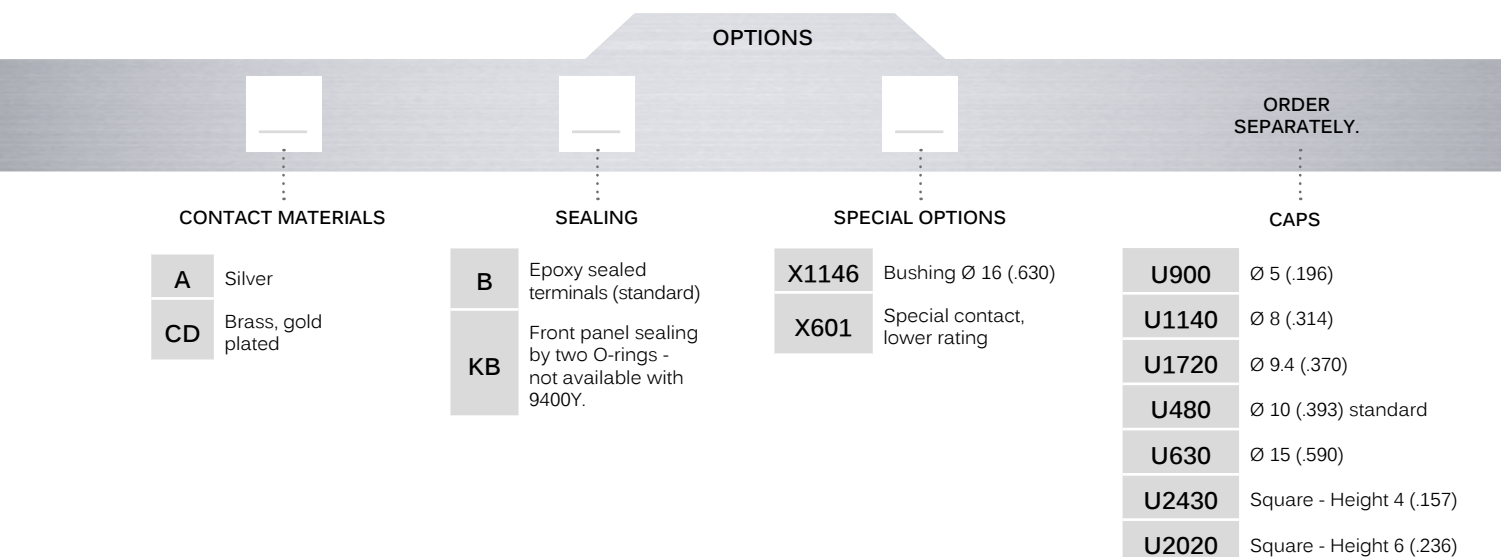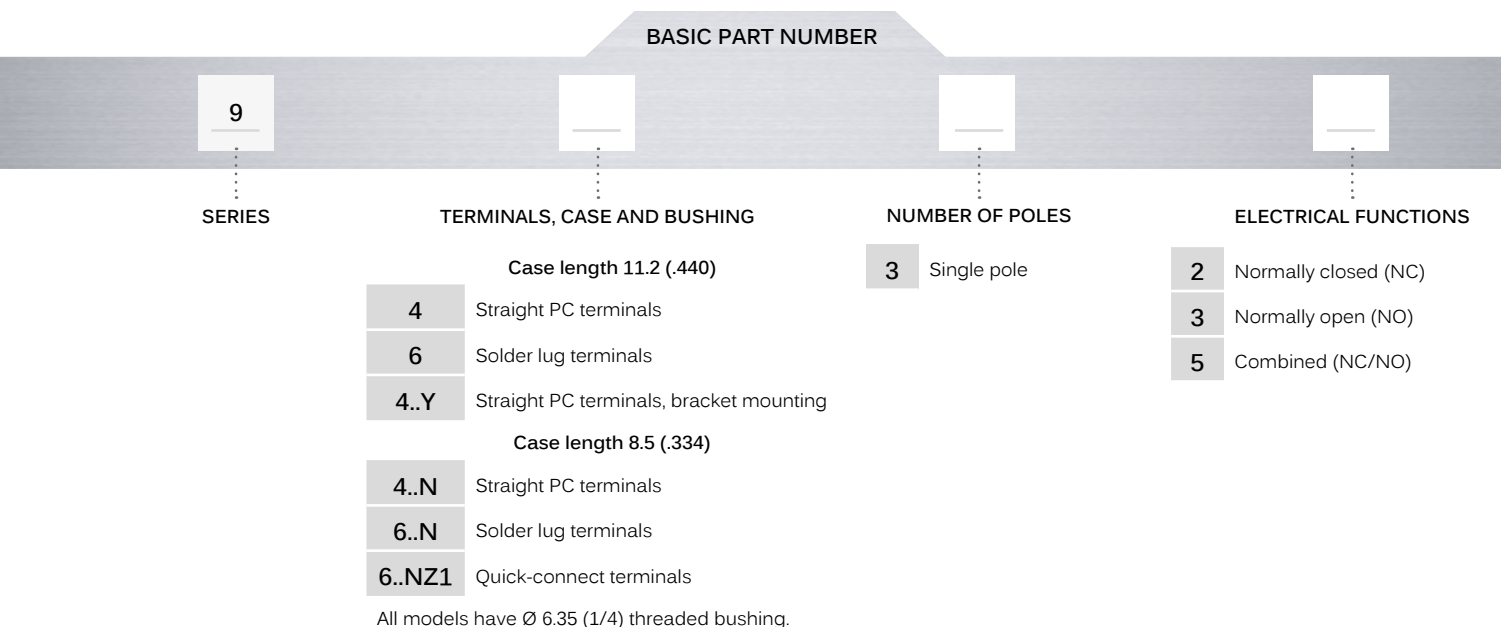


ABOUT THIS SERIES

On the following pages, you will find successively basic part numbers of switches and options in the same order as in above chart.


- Notice** : please note that not all combinations of above numbers are available. Refer to the following pages for further information.
- Sealing boots** are available to protect the switches against dust and water. See "Sealing Boots" section of website.
- Mounting accessories** : standard hardware supplied with all models : 2 hex nuts 8 mm (.314) across flats and 1 lockwasher. Standard and special hardware available is presented in the "Hardware" section of website.

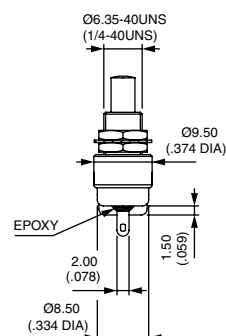

Momentary pushbutton switches

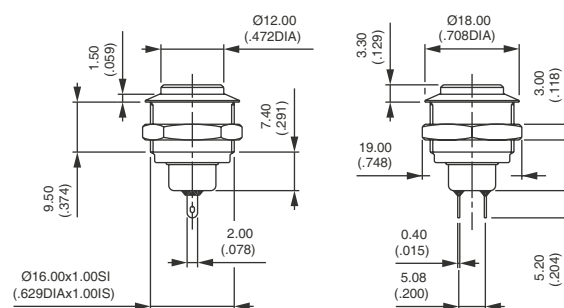

O-rings

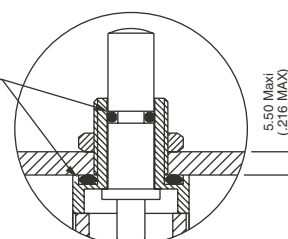

5

9400-9600 series

Momentary pushbutton switches

SPECIAL OPTIONS




- X601** Silver plated brass contacts
Current/voltage rating for an electrical life of 20,000 cycles : 0.5 A 30 VDC.
Minimum quantity : 5,000 pieces per model and shipment.
- X1146** Model with dia. 16 (.630) bushing and metal plunger
See previous page.

CAPS

Order separately.


For cap colors,
replace last "0" by number :

- | | |
|-----|-----------|
| 1 | Blue |
| 1/4 | Dark blue |
| 2 | Black |
| 3 | Green |
| 4 | Grey |
| 5 | Yellow |
| 6 | Red |
| 7 | Ivory |
| 7/1 | White |
| 9 | Orange |

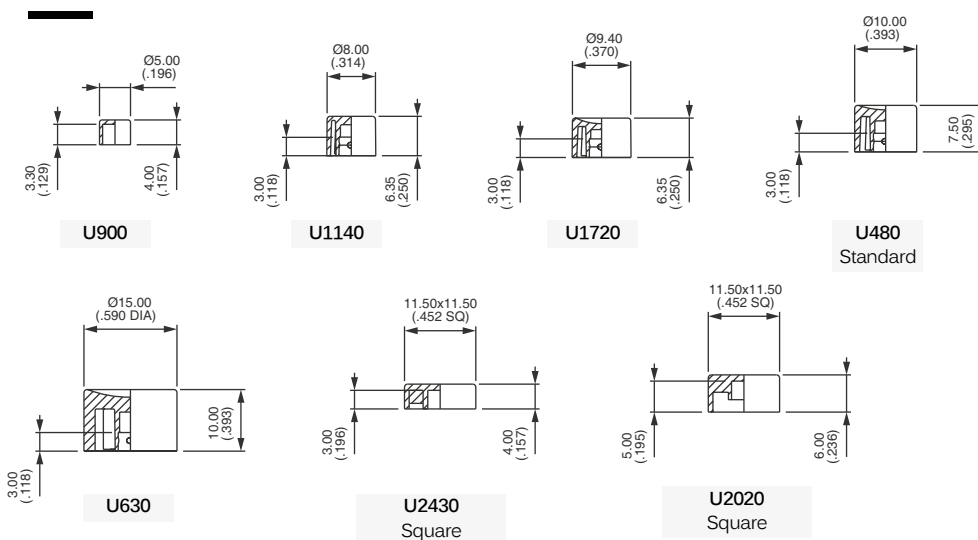

DRESS NUTS

Order separately. Chrome plated.

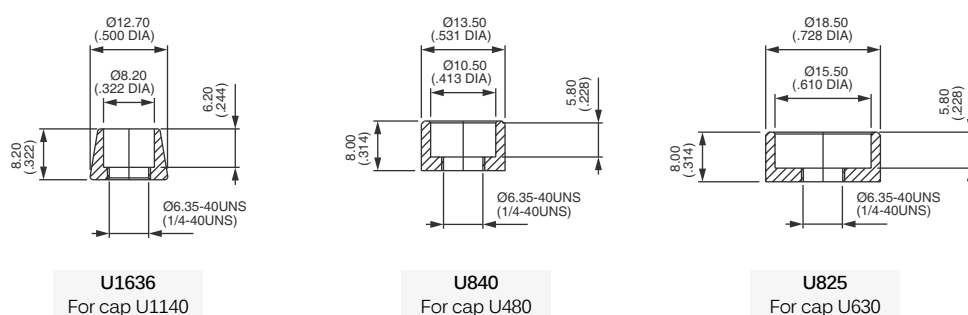

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Apem:](#)

[9432AB](#) [9432CDB](#) [9432YCDB](#) [9433AX1146](#) [9433CDB](#) [9433NCDB](#) [9435CDB](#) [9435YCDB](#) [9633ADX1146](#)
[9633AX1146](#) [9635AB](#) [9433AB](#) [9433AB+U907](#) [9433CD](#) [9433YA](#) [9632AB3](#) [9632CDB](#) [9633NAB3](#) [9633NAKB](#)
[9633NCDK](#) [9435AB](#)