


# XMAS Tree Type Clip


561-XT1250250, 561-XT1880250, 561-XT2500250, 561-XTS1250308,  
 561-XTS1870442, 561-XTS2500394, 561-XTS2500561, 561-XTS2500787,  
 561-XTS2501250, 561-XTS2812020, 561-XTS3170660

**Date Last Revised: 5/19/09**


### Prong Style

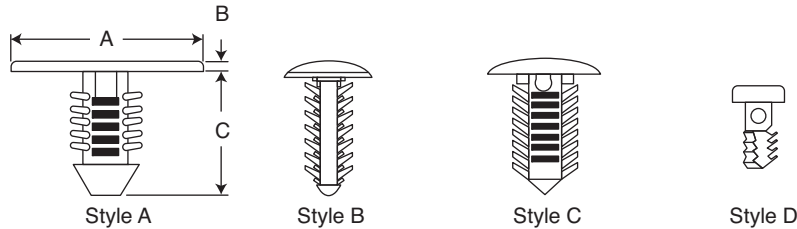

### Point Style

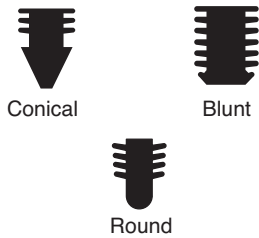

### Head Style

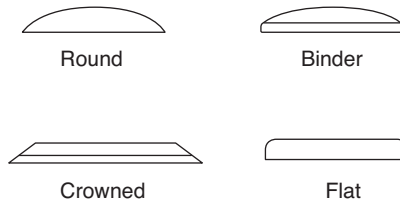

**Installation** - As clip is pushed into place the ribs deflect and then spring back after they pass through hole. Works effectively in prepared or blind holes.

### Dimensions: in. (mm)

SPECIFICATIONS	
<b>Material:</b>	Black Nylon 6/6
Can be used in blind hole applications	
Fast, easy installation with secure holding	

Mouser Stock No.	Hole Size	Panel Thickness	Head Style	Head Dia	Head Height	Prong Style	Prong Length	Point Style
561-XT1250250	.125	.062/.250	Round	.344"	.062	B	.321	Conical
561-XT1880250	.188	.062/.250	Round	.500"	.078	B	.348	Conical
561-XT2500500	.250	.062/.500	Round	.700"	.100	C	.630	Conical
561-XTS1250308	.120/.130	.135/.250	Flat	1/4"	.080	D	.308	Mod. Blunt
561-XTS1870442	.182/.192	.035/.210	Flat	7/16"	.075	A	.437	Conical
561-XTS2500394	.240/.260	.075/.185	Flat	39/64"	.120	C	.388	Round
561-XTS2500561	.250	.07/.400	Round	.70"	.100	C	.542	Conical
561-XTS2500787	.250	.125/.687	Flat	1/2"	.067	B	.787	Blunt
561-XTS2501250	.250	.050/.875	Crowned	3/4"	.110	A	1.250	Conical
561-XTS2812020	.281	.810/1.580	Crowned	19/32"	.050	A	1.935	Conical
561-XTS3170660	.320	.120/.500	Binder	1/2"	.050	A	.655	Blunt

**Available from Mouser Electronics**  
**1-800-346-6873 / www.mouser.com**

EPD-200511

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

## Eagle Plastic Devices:

[561-XT2500500](#) [561-XTS2501250](#) [561-XTS2500561](#) [561-XTS1250308](#) [561-XTS1870442](#) [561-XT1250250](#) [561-XT1880250](#) [561-XTS2812020](#) [561-XTS2500394](#) [561-XTS3170660](#) [561-XTS2500787](#) [561-XT2500500](#)