

APEX[®]



U-GUARD[™]
NON-MARRING COVERED TOOLS



PROTECT YOUR WORK.[™]

apexuguard.com

PROVEN DESIGN in 10+ Years of Assembly Manufacturing

The APEX Industrial Fastening line **enhances durability, extends life and improves tool fit**, while also making tools easier to identify on the jobsite. Pulling from our 85 years in assembly manufacturing, APEX is committed to providing high quality fastening solutions with durable dependability.



NON-MARRING

Non-Marring Cover protects from scratching or damages; Thin Wall maximizes access

SAFETY

Free Spinning Sleeve for enhances control & safety



DURABILITY

Full Body Design for greater strength & durability

Get the job done right the first time.

The APEX® u-GUARD™ series of non-marring covered tools gives you protection and control on the jobsite. These patented tools allow the user to grab directly onto the drive tool while it spins freely inside the covers, increasing fastening control and significantly reducing contact from the rotating tool.

**REQUEST A
FREE SAMPLE AT**
www.apexuguard.com

SEE BACK FOR \$500 REBATE

APEX u-GUARD™

NON-MARRING COVERED TOOLS

Covered Impact Power Bit
Broca cubiertas con reducción de vibración

#2+
NO.

NON-MARRING
Non-Marring Cover protects from scratching or damages; Thin Wall maximizes access
Cubierta antirrayones protege de arañazos o daños; Pared delgada maximiza el acceso

SAFETY
Free Spinning Sleeve for enhanced control & safety
Diseño de libre giro para mejorar el control y la seguridad

2X MORE DURABLE

50% BETTER GRIP

PROTECT YOUR WORK.™

INDUSTRIAL PERFORMANCE SINCE 1933™

SUPERIOR DURABILITY

The APEX® 30-piece fastening set with u-GUARD™ is built for the most demanding jobsites. The stack and store alphaCASE™ features a tongue and groove design with thick sidewall construction. The 30-piece set includes APEX's patented non-marring covered tools which protect final finishes from damage, and the core APEX S2 steel product with optimized tip geometry for fit to the fastener.

AUGSET-30 | 30 Piece u-GUARD™ Fastening Set

SUPERIOR DURABILITY
to withstand the toughest jobs



PIVOTING INSERT RAILS
refillable for ease of use



STACKABLE
for convenient storage



FULL LENGTH METAL HINGE
for improved case life



ATTACHMENT POINTS
for versatility on the job

 
EXTERIOR LABELS
for visibility and marking

Screwdriving bit tips include Square, Phillips®, Torx®, Slotted, Quick Release Bit Holder, Power Bit Holder, and Magnetic Nutsetters. Bits are secured in pivoting insert rails inside the case, allowing easy access to bits and case configurability.





u-GUARD™ NON-MARRING COVERED TOOLS



Covered Bit Holders

SKU #	DRIVE END	DRIVE SIZE	LENGTH
AUGBQ2A-1	BIT HOLDER	1/4"	2-1/4"
AUGBH3-1	BIT HOLDER	1/4"	3"



Covered Impact Power Bits

SKU #	DRIVE END	DRIVE SIZE	LENGTH
AUGB3BPH2-1	PHILLIPS	PH2	3"
AUMB3BPH2-1	PHILLIPS	PH2	3"
AUGB3BSQ2-1	SQUARE	SQ2	3"
AUMB3BSQ2-1	SQUARE	SQ2	3"
AUGB3BTX25-1	TORX	T25	3"
AUMB3BTX25-1	TORX	T25	3"




Covered Magnetic Nutsetters

SKU #	DRIVE END	DRIVE SIZE	LENGTH
AUGN2B16-1	HEX NUTSETTER	1/4"	2-9/16"
AUGN2B20-1	HEX NUTSETTER	5/16"	2-9/16"
AUGN2B24-1	HEX NUTSETTER	3/8"	2-9/16"
AUGN2B28-1	HEX NUTSETTER	7/16"	2-9/16"
AUGN2B32-1	HEX NUTSETTER	1/2"	2-9/16"
AUGN2BSET-3	HEX NUTSETTER	1/4", 5/16", 3/8"	2-9/16"

DESIGN PROVEN in
10+ YEARS
of **ASSEMBLY
MANUFACTURING**

REQUEST A FREE SAMPLE AT
www.apexuguard.com

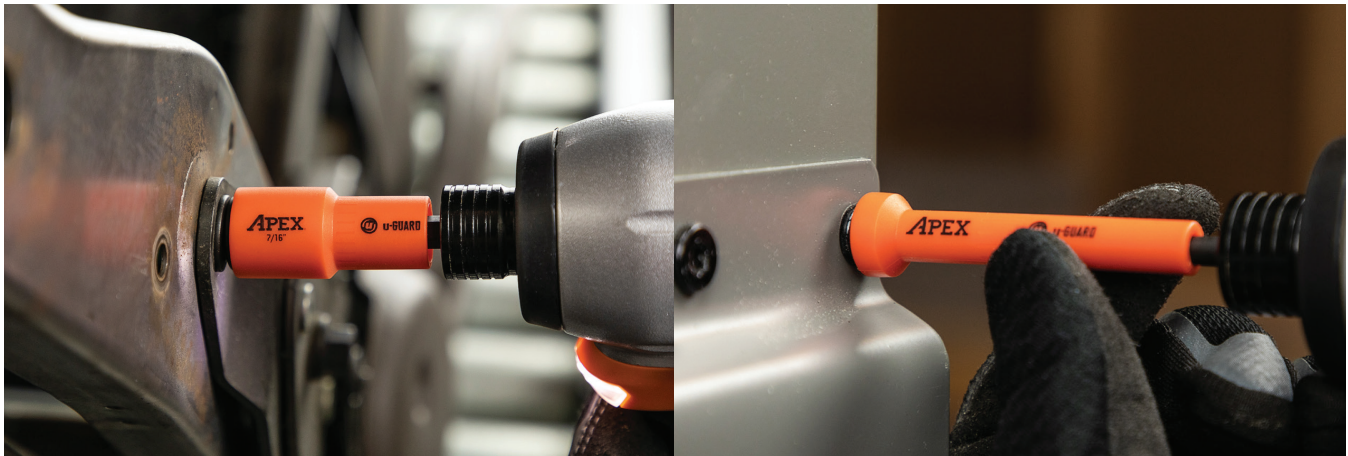

ADDITIONAL SETS



AUGSET-38 | 38 Piece u-GUARD™ Fastening Set



AMSET-38 | 38 Piece Fastening Set

DURABLE DEPENDABILITY

2X MORE DURABLE™

50% BETTER GRIP™

* Grip measured on Phillips bit only

DURABILITY

Full Body Design for greater strength & durability

BEST FIT

Optimized Tip Geometry for exact fastener fitment. Helps to eliminate cam-out and promotes fastener retention.

LIFE

Modified S2 Steel & proprietary heat treat process maximizes bit life.

IDENTIFICATION

Laser Marking for long-lasting, quick and easy size identification.



COMPATIBLE WITH
u-GUARD™
NON-MARRING COVERED TOOLS





1" PHILLIPS® Insert Bits

SKU #	DRIVE SIZE	PK SIZE	PKG TYPE
AMB1PH1-2	PH1	2	SKIN CARD
AMB1PH1-50	PH1	50	BULK
AMB1PH2-2	PH2	2	SKIN CARD
AMB1PH2-10	PH2	10	SKIN CARD
AMB1PH2-15	PH2	15	TIC TAC CASE
AMB1PH2-30	PH2	30	TIC TAC CASE
AMB1PH2-50	PH2	50	BULK
AMB1PH3-2	PH3	2	SKIN CARD
AMB1PH3-50	PH3	50	BULK
AMB1PH4-25	PH4	25	BULK



1" PHILLIPS® RECESSED Insert Bits

SKU #	DRIVE SIZE	PK SIZE	PKG TYPE
AMB1PT1-50	PH1	50	BULK
AMB1PT2-50	PH2	50	BULK
AMB1PT2-2	PH2	2	SKIN CARD



1" TORX® Insert Bits

SKU #	DRIVE SIZE	PK SIZE	PKG TYPE
AMB1TX10-25	T10	25	BULK
AMB1TX15-2	T15	2	SKIN CARD
AMB1TX15-25	T15	25	BULK
AMB1TX20-2	T20	2	SKIN CARD
AMB1TX20-25	T20	25	BULK
AMB1TX25-2	T25	2	SKIN CARD
AMB1TX25-10	T25	10	SKIN CARD
AMB1TX25-15	T25	15	TIC TAC CASE
AMB1TX25-30	T25	30	TIC TAC CASE
AMB1TX25-50	T25	50	BULK
AMB1TX27-50	T27	50	BULK
AMB1TX30-50	T30	50	BULK
AMB1TX40-25	T40	25	BULK



1" SLOTTED Insert Bits

SKU #	DRIVE SIZE	PK SIZE	PKG TYPE
AMB1SL1-25	1-2	25	BULK
AMB1SL2-25	2-3	25	BULK
AMB1SL3-25	3-4	25	BULK
AMB1SL4-25	4-5	25	BULK
AMB1SL6-25	6-8	25	BULK
AMB1SL8-2	8-10	2	SKIN CARD
AMB1SL8-25	8-10	25	BULK



1" TORX® SECURITY Insert Bits

SKU #	DRIVE SIZE	PK SIZE	PKG TYPE
AMB1TR10-25	TR10	25	BULK
AMB1TR15-25	TR15	25	BULK
AMB1TR20-25	TR20	25	BULK
AMB1TR25-25	TR25	25	BULK
AMB1TR27-25	TR27	25	BULK
AMB1TR30-25	TR30	25	BULK
AMB1TR40-25	TR40	25	BULK
1" TORX® SECURITY INSERT BIT SET			
AMB1TRSET-7	TR10, TR15, TR20, TR25, TR27, TR30, TR40	7	SKIN CARD



1" POZI® Insert Bits

SKU #	DRIVE SIZE	PK SIZE	PKG TYPE
AMB1PZ1-25	PZ1	25	BULK
AMB1PZ2-25	PZ2	25	BULK
AMB1PZ3-25	PZ3	25	BULK



1" SQUARE Insert Bits

SKU #	DRIVE SIZE	PK SIZE	PKG TYPE
AMB1SQ1-2	SQ1	2	SKIN CARD
AMB1SQ1-50	SQ1	50	BULK
AMB1SQ2-2	SQ2	2	SKIN CARD
AMB1SQ2-10	SQ2	10	SKIN CARD
AMB1SQ2-50	SQ2	50	BULK
AMB1SQ3-50	SQ3	50	BULK



1" SAE Hex Insert Bits

SKU #	DRIVE SIZE	PK SIZE	PKG TYPE
AMB1HX5-25	5/64"	25	BULK
AMB1HX6-25	3/32"	25	BULK
AMB1HX7-25	7/64"	25	BULK
AMB1HX8-25	1/8"	25	BULK
AMB1HX9-25	9/64"	25	BULK
AMB1HX10-25	5/32"	25	BULK
AMB1HX12-25	3/16"	25	BULK
AMB1HX14-25	7/32"	25	BULK
AMB1HX16-25	1/4"	25	BULK
1" SAE HEX INSERT BIT SET			
AMB1HXSET-9	5/64", 3/32", 7/64", 1/8", 9/64", 5/32", 3/16", 7/32", 1/4"	9	SKIN CARD



1" SAE SECURITY Hex Insert Bits

SKU #	DRIVE SIZE	PK SIZE	PKG TYPE
AMB1HXR8-25	1/8"	25	BULK
AMB1HXR12-25	3/16"	25	BULK
AMB1HXR6-25	3/32"	25	BULK
AMB1HXR10-25	5/32"	25	BULK
AMB1HXR5-25	5/64"	25	BULK
AMB1HXR7-25	7/64"	25	BULK
AMB1HXR9-25	9/64"	25	BULK
1" HEX SECURITY INSERT BIT SET			
AMB1HXRSET-7	5/64", 3/32", 7/64", 1/8", 9/64", 5/32", 3/16"	7	SKIN CARD



1" METRIC Hex Insert Bits

SKU #	DRIVE SIZE	PK SIZE	PKG TYPE
AMB1HM2-25	2mm	25	BULK
AMB1HM25-25	2.5mm	25	BULK
AMB1HM3-25	3mm	25	BULK
AMB1HM4-25	4mm	25	BULK
AMB1HM5-25	5mm	25	BULK
AMB1HM6-25	6mm	25	BULK
1" METRIC HEX INSERT BIT SET			
AMB1HMSET-6	2mm, 2.5mm, 3mm, 4mm, 5mm, 6mm	6	SKIN CARD



2" PHILLIPS® Power Bits

SKU #	DRIVE SIZE	PK SIZE	PKG TYPE
AMB2PH1-50	PH1	50	BULK
AMB2PH2-1	PH2	1	SKIN CARD
AMB2PH2-5	PH2	5	SKIN CARD
AMB2PH2-15	PH2	15	SKIN CARD
AMB2PH2-50	PH2	50	BULK
AMB2PH3-50	PH3	50	BULK



2" SLOTTED Power Bits

SKU #	DRIVE SIZE	PK SIZE	PKG TYPE
AMB2SL4-25	4-5	25	BULK
AMB2SL6-25	6-8	25	BULK
AMB2SL8-1	8-10	1	SKIN CARD
AMB2SL8-25	8-10	25	BULK



COMPATIBLE WITH

U-GUARD™
NON-MARRING COVERED TOOLS



2" SQUARE Power Bits

SKU #	DRIVE SIZE	PK SIZE	PKG TYPE
AMB2SQ1-50	SQ1	50	BULK
AMB2SQ2-1	SQ2	1	SKIN CARD
AMB2SQ2-5	SQ2	5	SKIN CARD
AMB2SQ2-50	SQ2	50	BULK
AMB2SQ3-50	SQ3	50	BULK



2" TORX® Power Bits

SKU #	DRIVE SIZE	PK SIZE	PKG TYPE
AMB2TX15-2	T15	2	SKIN CARD
AMB2TX15-25	T15	25	BULK
AMB2TX20-2	T20	2	SKIN CARD
AMB2TX20-25	T20	25	BULK
AMB2TX25-2	T25	2	SKIN CARD
AMB2TX25-5	T25	5	SKIN CARD
AMB2TX25-50	T25	50	BULK
AMB2TX27-50	T27	50	BULK
AMB2TX30-2	T30	2	SKIN CARD
AMB2TX30-50	T30	50	BULK
AMB2TX40-2	T40	2	SKIN CARD
AMB2TX40-50	T40	50	BULK



2-3/4" PHILLIPS® Power Bits

SKU #	BIT TYPE	DRIVE SIZE	PK SIZE	PKG TYPE
AMB2CPH1-25	PHILLIPS	PH1	25	BULK
AMB2CPH2-25	PHILLIPS	PH2	25	BULK
AMB2CPH3-25	PHILLIPS	PH3	25	BULK



3-1/2" PHILLIPS® Power Bits

SKU #	BIT TYPE	DRIVE SIZE	PK SIZE	PKG TYPE
AMB3BPH1-25	PHILLIPS	PH1	25	BULK
AMB3BPH2-1	PHILLIPS	PH2	1	SKIN CARD
AMB3BPH2-25	PHILLIPS	PH2	25	BULK
AMB3BPH3-25	PHILLIPS	PH3	25	BULK



3-1/2" SQUARE Power Bits

SKU #	BIT TYPE	DRIVE SIZE	PK SIZE	PKG TYPE
AMB3BSQ1-25	SQUARE	SQ1	25	BULK
AMB3BSQ2-1	SQUARE	SQ2	1	SKIN CARD
AMB3BSQ2-25	SQUARE	SQ2	25	BULK
AMB3BSQ3-25	SQUARE	SQ3	25	BULK



3-1/2" TORX® Power Bits

SKU #	BIT TYPE	DRIVE SIZE	PK SIZE	PKG TYPE
AMB3BTX25-25	TORX	T25	25	BULK
AMB3BTX25-1	TORX	T25	1	SKIN CARD



6" PHILLIPS® Power Bits

SKU #	BIT TYPE	DRIVE SIZE	PK SIZE	PKG TYPE
AMB6PH1-25	PHILLIPS	PH1	25	BULK
AMB6PH2-1	PHILLIPS	PH2	1	SKIN CARD
AMB6PH2-25	PHILLIPS	PH2	25	BULK
AMB6PH3-25	PHILLIPS	PH3	25	BULK



6" TORX® Power Bits

SKU #	BIT TYPE	DRIVE SIZE	PK SIZE	PKG TYPE
AMB6TX25-1	TORX	T25	1	SKIN CARD
AMB6TX25-25	TORX	T25	25	BULK



6" SQUARE Power Bits

SKU #	BIT TYPE	DRIVE SIZE	PK SIZE	PKG TYPE
AMB6SQ1-25	SQUARE	SQ1	25	BULK
AMB6SQ2-25	SQUARE	SQ2	25	BULK
AMB6SQ3-25	SQUARE	SQ3	25	BULK



1/4" Hex Shank Socket Adaptors

SKU #	DRIVE SIZE	PK SIZE	PKG TYPE
AMAD216-1	1/4" SQ	1	SKIN CARD
AMAD224-1	3/8" SQ	1	SKIN CARD
AMAD232-1	1/2" SQ	1	SKIN CARD



1/4" Square Drive Sockets

SKU #	HEX SIZE	PK SIZE	PKG TYPE
AMSA216-1	1/4"	1	HANG TAG
AMSA220-1	5/16"	1	HANG TAG
AMSA224-1	3/8"	1	HANG TAG



3/8" Square Drive Sockets

SKU #	HEX SIZE	PK SIZE	PKG TYPE
AMSB220-1	5/16"	1	HANG TAG
AMSB224-1	3/8"	1	HANG TAG
AMSB228-1	7/16"	1	HANG TAG
AMSB232-1	1/2"	1	HANG TAG
AMSB236-1	9/16"	1	HANG TAG
AMSB240-1	5/8"	1	HANG TAG
AMSB244-1	11/16"	1	HANG TAG
AMSB248-1	3/4"	1	HANG TAG

3/8" SQUARE DRIVE SOCKET SET			
AMSB2SET-9	1/2", 11/16", 3/4", 3/8", 5/16", 5/8", 7/16", 9/16", 1/4" hex to 3/8" socket adaptor	9	SOCKET RAIL



1/2" Square Drive Sockets

SKU #	HEX SIZE	PK SIZE	PKG TYPE
AMSC328-1	7/16"	1	HANG TAG
AMSC332-1	1/2"	1	HANG TAG
AMSC336-1	9/16"	1	HANG TAG
AMSC340-1	5/8"	1	HANG TAG
AMSC344-1	11/16"	1	HANG TAG
AMSC348-1	3/4"	1	HANG TAG
AMSC352-1	13/16"	1	HANG TAG
AMSC356-1	7/8"	1	HANG TAG

1/2" SQUARE DRIVE SOCKET SET			
AMSC3SET-9	1/2", 11/16", 13/16", 3/4", 5/8", 7/16", 7/8", 9/16", 1/4" hex to 1/2" socket adaptor	9	SOCKET RAIL





1/4" Hex Shank Magnetic Nut Setters

SKU #	HEX SIZE	PK SIZE	PKG TYPE
1-7/8" NUT SETTERS			
AMN1C16-1	1/4"	1	SKIN CARD
AMN1C16-25	1/4"	25	BULK
AMN1C20-1	5/16"	1	SKIN CARD
AMN1C20-25	5/16"	25	BULK
AMN1C24-1	3/8"	1	SKIN CARD
AMN1C24-25	3/8"	25	BULK
AMN1C28-1	7/16"	1	SKIN CARD
AMN1C28-25	7/16"	25	BULK
AMN1C32-1	1/2"	1	SKIN CARD
AMN1C32-25	1/2"	25	BULK
1-7/8" NUT SETTER SETS			
AMN1CSET-3	1/4", 5/16", 3/8"	3	SKIN CARD
AMN1CSET-5	1/4", 5/16", 3/8", 7/16", 1/2"	5	SKIN CARD
2-9/16" NUT SETTERS			
AMN2B16-1	1/4"	1	SKIN CARD
AMN2B16-25	1/4"	25	BULK
AMN2B20-1	5/16"	1	SKIN CARD
AMN2B20-25	5/16"	25	BULK
AMN2B24-1	3/8"	1	SKIN CARD
AMN2B24-25	3/8"	25	BULK
AMN2B28-1	7/16"	1	SKIN CARD
AMN2B28-25	7/16"	25	BULK
AMN2B32-1	1/2"	1	SKIN CARD
AMN2B32-25	1/2"	25	BULK
6" NUT SETTERS			
AMN616-25	1/4"	25	BULK
AMN620-25	5/16"	25	BULK
AMN624-25	3/8"	25	BULK



1/4" Hex Shank Magnetic Bit Holders, Extension Bit Holders, Quick Release Bit Holder & Drive Guides

SKU #	LENGTH	DESCRIPTION	DRIVE SIZE	PK SIZE	PKG TYPE
AMBH2-25	2"	MAGNETIC BIT HOLDER	1/4"	25	BULK
AMBQ2A-1	2-1/4"	QUICK RELEASE BIT HOLDER	1/4"	1	SKIN CARD
AMBQ2A-25	2-1/4"	QUICK RELEASE BIT HOLDER	1/4"	25	BULK
AMBH3-1	3"	MAGNETIC BIT HOLDER	1/4"	1	SKIN CARD
AMBH3-25	3"	MAGNETIC BIT HOLDER	1/4"	25	BULK
AMDG3-1	3"	IMPACT DRIVE GUIDE	1/4"	1	SKIN CARD
AMDG3-25	3"	IMPACT DRIVE GUIDE	1/4"	25	BULK
AMBH6-1	6"	EXTENSION BIT HOLDER	1/4"	1	SKIN CARD
AMBH6-25	6"	EXTENSION BIT HOLDER	1/4"	25	BULK
AMBH12-1	12"	EXTENSION BIT HOLDER	1/4"	1	SKIN CARD
AMBH12-25	12"	EXTENSION BIT HOLDER	1/4"	25	BULK

REQUEST A
FREE SAMPLE AT
www.apexuguard.com

SEE BACK FOR \$500 REBATE ON YOUR NEXT APEX TOOL PURCHASE

APEX PROMO-UGPH12 PROMOTIONAL PACK NOT FOR RESALE

APEX

u-GUARD™

NON-MARRING COVERED TOOLS

Covered Impact Power Bit

Broca cubiertas con reducción de vibración

NON-MARRING

Non-Marring Cover protects from scratching or damages; Thin Wall maximizes access.

Cubierta antirrayones protege de arañazos o daños; Pared delgada maximiza el acceso

SAFETY

Free Spinning Sleeve for enhanced control & safety.

Diseño de libre giro para mejorar el control y la seguridad

DURABILITY

Full Body Design for greater strength & durability.

Diseño de cuerpo entero para la mayor resistencia y durabilidad

#2

NO.

+

2X MORE DURABLE™

50% BETTER GRIP™

PROTECT YOUR WORK.™

INDUSTRIAL PERFORMANCE SINCE 1933™

FOR PARA



Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Apex Tool Group:

[AMAD216-1](#) [AMAD224-1](#) [AMAD232-1](#) [AMB1HM2-25](#) [AMB1HM25-25](#) [AMB1HM3-25](#) [AMSC348-1](#) [AMSC352-1](#)
[AMSC356-1](#) [AMSC3SET-9](#) [AMSB2SET-9](#) [AMSC328-1](#) [AMSC332-1](#) [AMSC336-1](#) [AMSC340-1](#) [AMSC344-1](#)
[AMSB228-1](#) [AMSB232-1](#) [AMSB236-1](#) [AMSB240-1](#) [AMSB244-1](#) [AMSB248-1](#) [AMN624-25](#) [AMSA216-1](#) [AMSA220-1](#)
[AMSA224-1](#) [AMSB220-1](#) [AMSB224-1](#) [AMN2B28-1](#) [AMN2B28-25](#) [AMN2B32-1](#) [AMN2B32-25](#) [AMN616-25](#)
[AMN620-25](#) [AMN2B16-1](#) [AMN2B16-25](#) [AMN2B20-1](#) [AMN2B20-25](#) [AMN2B24-1](#) [AMN2B24-25](#) [AMN1C28-1](#)
[AMN1C28-25](#) [AMN1C32-1](#) [AMN1C32-25](#) [AMN1CSET-3](#) [AMN1CSET-5](#) [AMN1C16-1](#) [AMN1C16-25](#) [AMN1C20-1](#)
[AMN1C20-25](#) [AMN1C24-1](#) [AMN1C24-25](#) [AMBH6-1](#) [AMBH6-25](#) [AMBQ2A-1](#) [AMBQ2A-25](#) [AMDG3-1](#) [AMDG3-25](#)
[AMB6TX25-25](#) [AMBH12-1](#) [AMBH12-25](#) [AMBH2-25](#) [AMBH3-1](#) [AMBH3-25](#) [AMB6PH2-25](#) [AMB6PH3-25](#) [AMB6SQ1-](#)
[25](#) [AMB6SQ2-25](#) [AMB6SQ3-25](#) [AMB6TX25-1](#) [AMB3BSQ2-25](#) [AMB3BSQ3-25](#) [AMB3BTX25-1](#) [AMB3BTX25-25](#)
[AMB6PH1-25](#) [AMB6PH2-1](#) [AMB3BPH1-25](#) [AMB3BPH2-1](#) [AMB3BPH2-25](#) [AMB3BPH3-25](#) [AMB3BSQ1-25](#)
[AMB3BSQ2-1](#) [AMB2TX25-50](#) [AMB2TX27-50](#) [AMB2TX30-2](#) [AMB2TX30-50](#) [AMB2TX40-2](#) [AMB2TX40-50](#)
[AMB2TX15-2](#) [AMB2TX15-25](#) [AMB2TX20-2](#) [AMB2TX20-25](#) [AMB2TX25-2](#) [AMB2TX25-5](#) [AMB2SL8-25](#) [AMB2SQ1-50](#)
[AMB2SQ2-1](#) [AMB2SQ2-5](#) [AMB2SQ2-50](#) [AMB2SQ3-50](#)