

WT1010HN

1-Channel Power Unit, 150 W
Product no.: WT1010HN



Benefits


- Digital Soldering Station WT 1H 120V, 60Hz (150W) with WP120 and WSR201
- WP 120 (120 W): All-rounder with Power-Response soldering tip, XT Tip family and XT soldering head
- OFF time, Prozess window, Lock function, Offset
- Compatible with a large selection of soldering pencils, pre-heat plates and solder baths
- 2-in-1 WSR Safety Rest, flips between sponge and brass wool
- Stackable Units, saving space on the workbench
- RS232 protocol for Automation and Control




For this purpose, we recommend:



Solder fume extractors

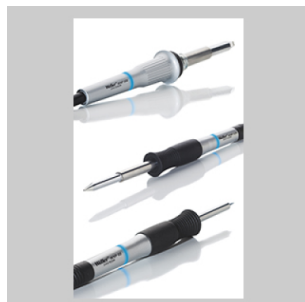

Soldering irons

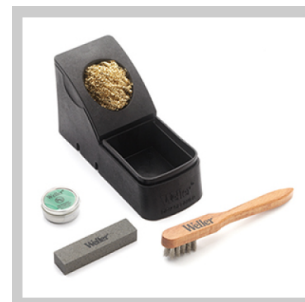

Cleaning




Pre-heating plates



Technical Data

Dimensions L x W x H (mm)	149 x 138 x 101
Dimensions L x W x H (inches)	5.87 x 5.43 x 3.98
Weight (approx.) in kg	3
Voltage	120 V
Power	150 W
Channels	1
Temperature range (depends on tool) °C	50 - 550
Temperature range (depends on tool) °F	150 - 950
Temperature accuracy °C	±9
Temperature accuracy °F	±17
Temperature stability °C	±2
Temperature stability °F	±4
Equipotential bonding socket	Via 3,5 mm pawl socket on front of device
Display	Backlit LCD
Air consumption l/min	---
Operating pressure in bar/psi	---
Capacity l/min	---
Vacuum	---

Owning the bench

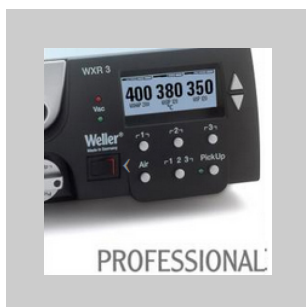

PROFESSIONAL



FILTRATION



EREM



XCELITE

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Apex Tool Group:](#)

[WT1010HN](#)