

# WE 1010, 120V

1-channel-soldering station with WEP 70 soldering iron and PH 70 safety rest  
Product no.: WE1010NA



## Benefits

- Power unit, 1 channel with soldering iron WEP 70 and safety rest PH 70
- › 70W solder iron with ergonomic handle and providing toolless tip change
- › ESD safe station, iron and heat-resistant silicon cable for safe handling
- › Using ET soldering tips
- › Standby mode and auto setback conserves energy, protects equipment
- › Password-protected to preserve settings
- › Replacement for 4ETH, 4ETK, 4ETO, 4ETS necessary. For WEP 70 4ETHL, 4ETKL, 4EKOL and 4ETSL must be used.


For this purpose, we recommend:



Solder fume extractors



Soldering irons

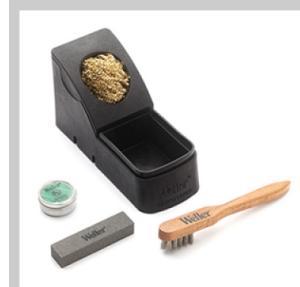

Cleaning



Pre-heating plates



## Technical Data

Dimensions L x W x H (mm)	150 x 120 x 98
Dimensions L x W x H (inches)	5.91 x 4.72 x 3.86
Weight (approx.) in kg	1.4
Voltage	120 V
Power	85 W
Channels	1
Temperature range (depends on tool) °C	100 - 450
Temperature range (depends on tool) °F	200 - 850
Temperature accuracy °C	Average tip temperature can be „offset“ to +/- 5°C at idle with no load
Temperature accuracy °F	Average tip temperature can be „offset“ to +/- 9°F at idle with no load
Temperature stability °C	± 6
Temperature stability °F	± 10
Equipotential bonding socket	---
Display	Digital LC Display
Air consumption l/min	---
Operating pressure in bar/psi	---
Capacity l/min	---
Vacuum	---

## Owning the bench



PROFESSIONAL



FILTRATION



EREM



XCELITE

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Apex Tool Group:](#)

[TC205](#) [T0058770714](#) [WE1010NA](#) [T0058770706](#) [T0058770715](#)