


LTE Rubber Antenna Specification


Main Technical Specifications

Frequency Range	800/900/1800/2100/2600Mhz
Gain	5DB
VSWR	≤3.0:1
Input Impedance	50ohm
Polarization Type	Vertical
Max Input power	20w
Max diameter	13mm
Min diameter	5.5mm
Antenna Length	210mm
Connector Type	SMA /FME etc.
Antenna Color	Black
Storage Temperature	-30°C to +75°C

Characteristic curve

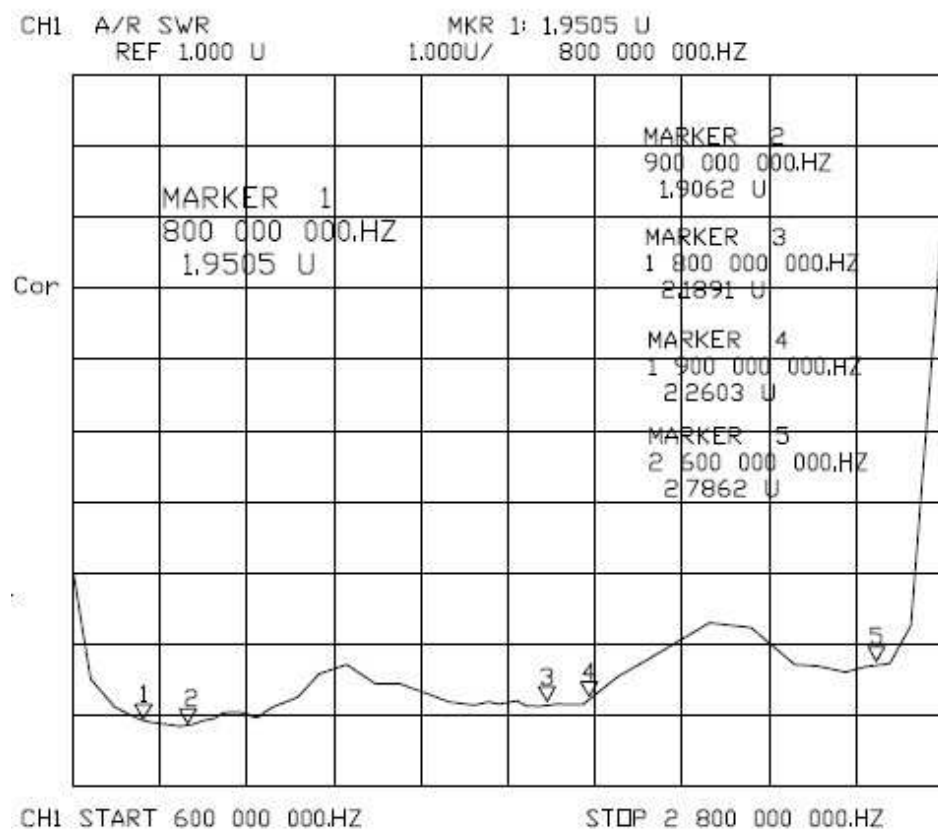

Size drawing

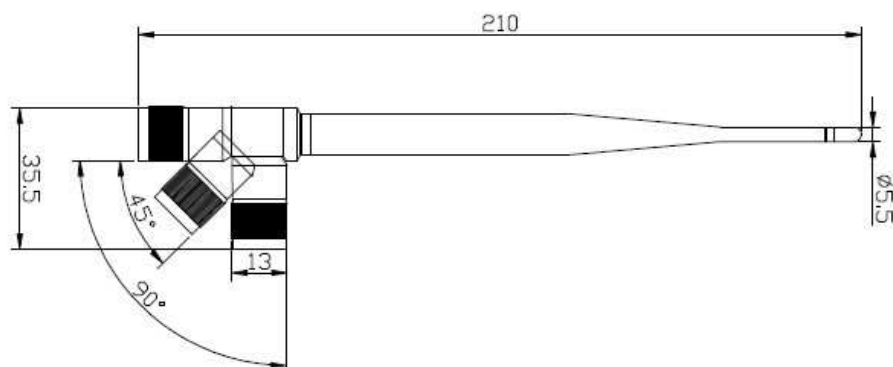

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Mikroe:

[MIKROE-3371](#)