


WIFI Rubber Antenna Specification




Main Technical Specifications

Frequency Range	2400-2500MHz
Gain	9DB
VSWR	$\leq 1.5:1$
Input Impedance	50ohm
Polarization Type	Vertical
Radiation	Omni
Max Input power	50w
Antenna Length	295mm
Connector Type	SMA/BNC etc.
Antenna Color	Black
Storage Temperature	-30°C to +75°C

Characteristic curve

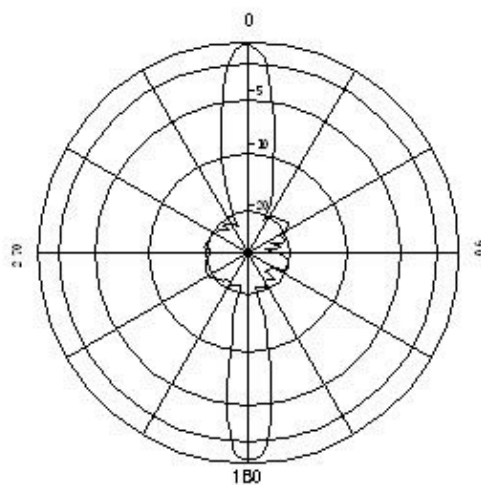

Vertical Pattern

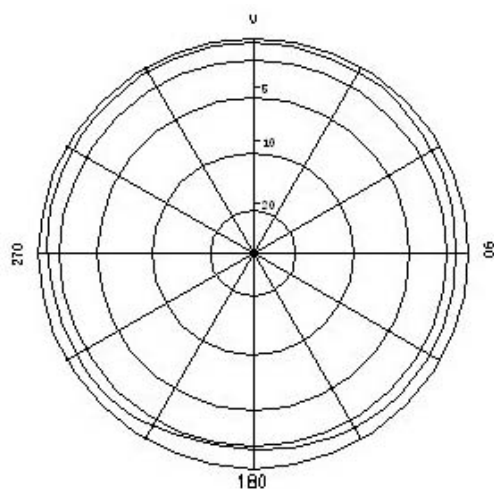

Horizontal Pattern

	FRE (MHz)	Max dBi	Min dBi
	2400	9.13	8.97
	2450	9.25	9.06
	2500	9.16	9.02

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Mikroe:

[MIKROE-3372](#)