


## 1005/1013/8898

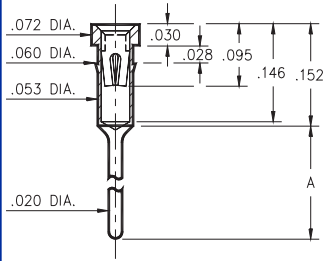


| Basic Part Number | Length A |
|-------------------|----------|
| 1005-0            | .138     |
| 1013-0            | .165     |
| 8898-0            | .214     |

NOTE: 8898 is not annealed & not suitable for auto-clinching

**XXXX-0-15-XX-3X-XX-04-0**

Press-fit in .057 mounting hole  
1/4 hard brass shell for auto-clinching

## 0145/0146

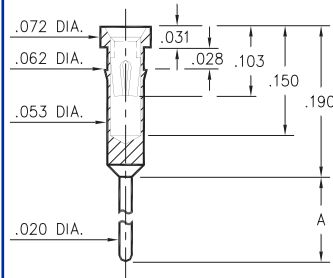


| Basic Part Number | Length A |
|-------------------|----------|
| 0145-0            | .300     |
| 0146-0            | .410     |

**014X-0-15-XX-30-XX-04-0**

Press-fit in .059 mounting hole


## 4378

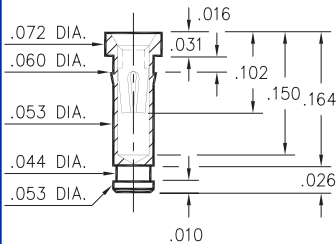

**4378-0-15-XX-30-XX-10-0**

Press-fit in .057 mounting hole


## 0556

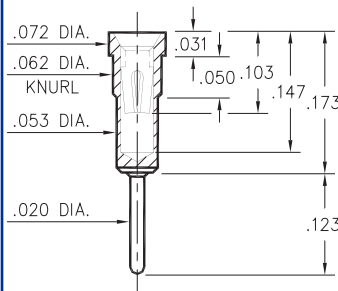

**0556-0-15-XX-30-XX-04-0**

Press-fit in .059 mounting hole


## 1103

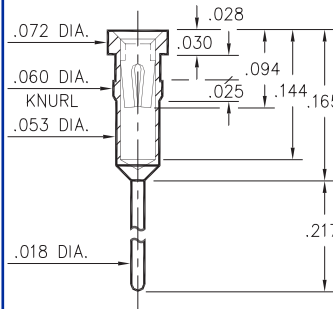

**1103-0-15-XX-30-XX-04-0**

Press-fit in .057 mounting hole


## 9234

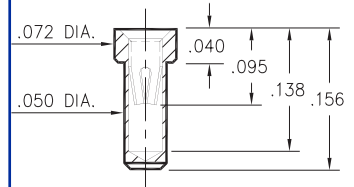

**9234-0-15-XX-30-XX-10-0**

Solder mount in .052 min. mounting hole

## 0136/37/38/39/41/48/52

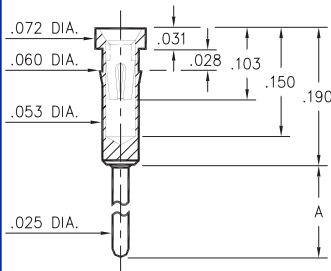


| Basic Part Number | Length A |
|-------------------|----------|
| 0136-0            | 1.215    |
| 0137-0            | .560     |
| 0138-0            | .210     |
| 0139-0            | .635     |
| 0141-0            | .700     |
| 0148-0            | .455     |
| 0152-0            | .410     |

**01XX-0-15-XX-30-XX-04-0**

Press-fit in .057 mounting hole


## 0447

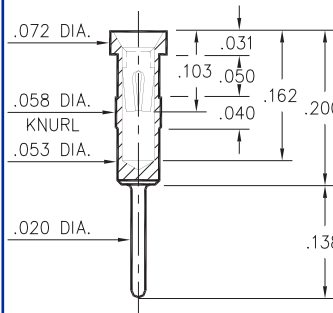

**0447-0-15-XX-30-XX-04-0**

Press-fit in .056 mounting hole

## 5660

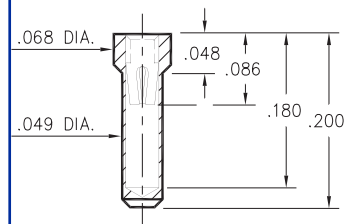

**5660-0-15-XX-30-XX-10-0**

Solder mount in .051 min. mounting hole

### SPECIFICATIONS

**SHELL MATERIAL:**  
Brass Alloy 360, 1/2 Hard

**CONTACT MATERIAL:**  
Beryllium Copper Alloy 172, HT

**DIMENSION IN INCHES**  
**TOLERANCES ON:**  
LENGTHS: ±.005  
DIAMETERS: ±.002  
ANGLES: ± 2°

**ORDER CODE: XXXX - X - 15 - XX - 3X - XX - XX - 0**

**BASIC PART #**

**SPECIFY SHELL FINISH:**

01 200μ" TIN/LEAD OVER NICKEL  
15 10μ" GOLD OVER NICKEL

**SPECIFY CONTACT FINISH:**

02 200μ" TIN/LEAD OVER NICKEL  
14 10μ" GOLD OVER NICKEL  
27 30μ" GOLD OVER NICKEL

**SELECT CONTACT**

#30 or #32 CONTACT (DATA ON PAGE 208)

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

## Mill-Max:

[1013-0-15-01-32-14-04-0](#) [1005-0-15-01-32-14-04-0](#) [1005-0-15-01-30-14-04-0](#) [0556-0-15-01-30-14-04-0](#) [0139-0-15-01-30-14-04-0](#) [0152-0-15-01-30-14-04-0](#) [0145-0-15-01-30-14-04-0](#) [0136-0-15-01-30-14-04-0](#) [0148-0-15-01-30-14-04-0](#) [0146-0-15-01-30-14-04-0](#) [0138-0-15-01-30-14-04-0](#) [0447-0-15-01-30-14-04-0](#) [0152-0-15-15-30-14-04-0](#) [0139-0-15-15-30-14-04-0](#) [0148-0-15-15-30-14-04-0](#) [8898-0-15-01-32-14-04-0](#) [8898-0-15-01-30-14-04-0](#) [5660-0-15-01-30-14-10-0](#) [9234-0-15-01-30-14-10-0](#)