



## 0444

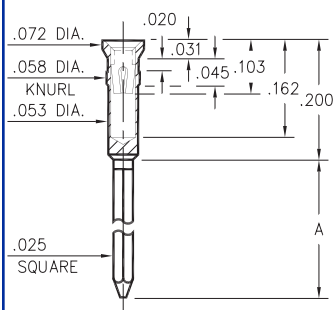

| Basic Part Number | # of Wraps | Length A |
|-------------------|------------|----------|
| 0444-1            | 1          | .260     |
| 0444-2            | 2          | .370     |
| 0444-3            | 3          | .505     |

**0444-X-17-XX-30-XX-02-0**  
Press-fit in .056 mounting hole


## 0445/0446

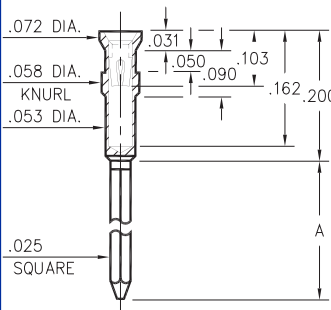

| Basic Part Number | # of Wraps | Length A |
|-------------------|------------|----------|
| 0446-2            | 2          | .370     |
| 0445-3            | 3          | .505     |

**044X-X-17-XX-30-XX-02-0**  
Press-fit in .056 mounting hole


## 2601⇒2603

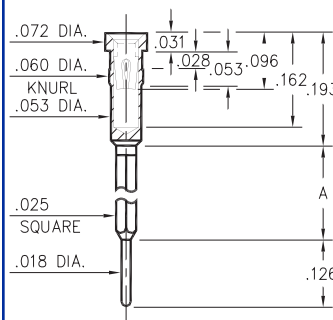

| Basic Part Number | # of Wraps | Length A |
|-------------------|------------|----------|
| 2601-0            | 1          | .232     |
| 2602-0            | 2          | .350     |
| 2603-0            | 3          | .468     |

**260X-X-17-XX-30-XX-02-0**  
Press-fit in .057 mounting hole

## 1047

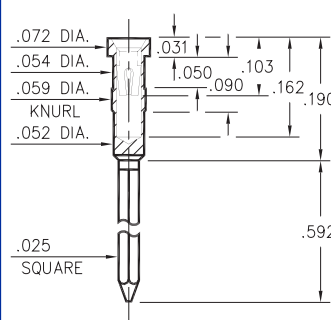

**1047-3-17-XX-30-XX-02-0**  
Press-fit in .056 mounting hole

### SPECIFICATIONS

**SHELL MATERIAL:**  
Brass Alloy 360, 1/2 Hard

**CONTACT MATERIAL:**  
Beryllium Copper Alloy 172, HT

**DIMENSION IN INCHES**  
**TOLERANCES ON:**  
LENGTHS: ±.005  
DIAMETERS: ±.002  
ANGLES: ± 2°

**ORDER CODE: XXXX - X - 17 - XX - 30 - XX - 02 - 0**

**BASIC PART #** \_\_\_\_\_

**SPECIFY SHELL FINISH:** \_\_\_\_\_

**01** 200μ" TIN/LEAD OVER NICKEL  
**15** 10μ" GOLD OVER NICKEL

**SPECIFY CONTACT FINISH:**

**02** 200μ" TIN/LEAD OVER NICKEL  
**14** 10μ" GOLD OVER NICKEL  
**27** 30μ" GOLD OVER NICKEL

**SELECT CONTACT**

**#30 CONTACT (DATA ON PAGE 208)**

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Mill-Max:

[2602-0-17-01-30-14-02-0](#) [2603-0-17-01-30-14-02-0](#) [0445-3-17-01-30-14-02-0](#) [0444-3-17-01-30-14-02-0](#) [0444-2-17-01-30-14-02-0](#) [0444-1-17-01-30-14-02-0](#) [2601-0-17-01-30-14-02-0](#) [1047-3-17-01-30-14-02-0](#)