



0385

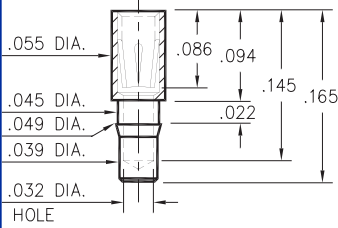


0385-0-15-XX-43-XX-10-0
Press-fit in .046 mounting hole

4001

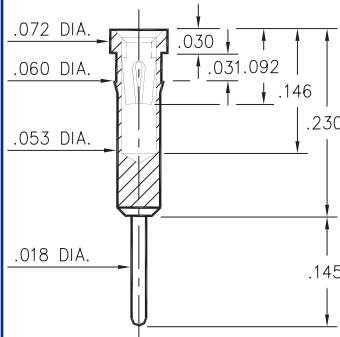


4001-0-15-XX-43-XX-04-0
Press-fit in .057 mounting hole

1782

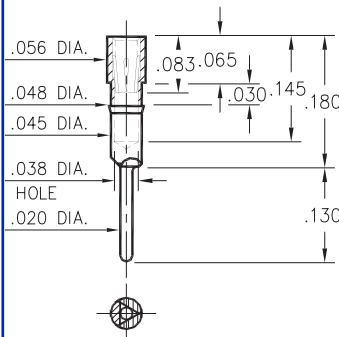


1782-0-15-XX-43-XX-04-0
Press-fit in .045 mounting hole

5960

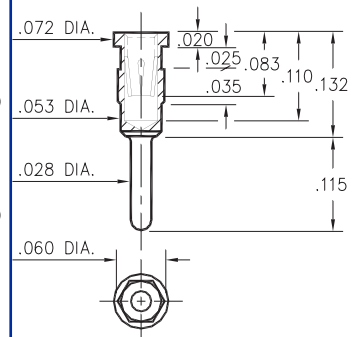

5960-0-15-XX-43-XX-04-0
Hex press-fit in .057 plated thru hole


1401/3185

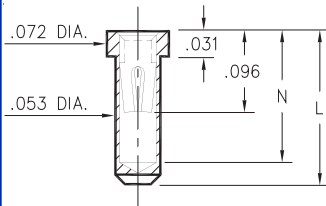

XXXX-0-15-XX-30-XX-10-0
Solder mount in .055 min. mounting hole


Basic Part Number	Depth N	Length L
1401-0	.145	.165
3185-0	.109	.130

4310

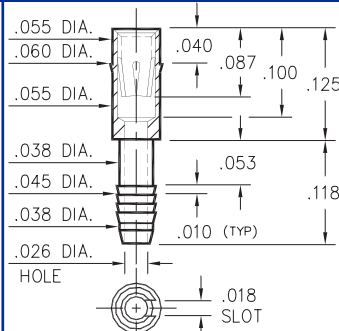


4310-0-31-XX-43-XX-04-0
Compliant press-fit in .040±.003 plated hole. For .090→.130 thick board.

1385

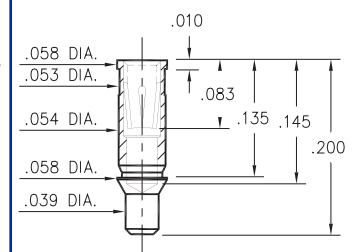


1385-0-15-XX-43-XX-10-0
Surface mount

3018

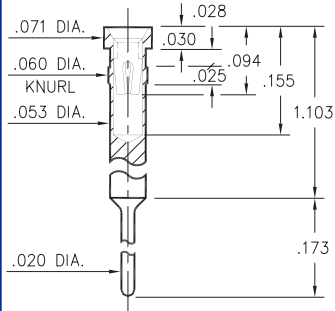


3018-0-15-XX-30-XX-04-0
Press-fit in .057 mounting hole

3907

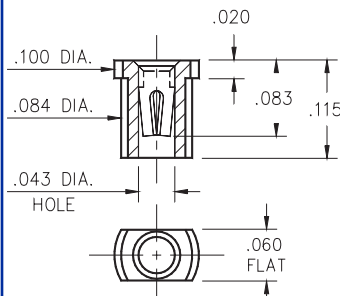


3907-0-18-XX-30-XX-10-0
Surface mount
Also available on 12mm wide carrier tape: 4,000 parts per 13" reel.
Order as: 3907-0-57-XX-30-XX-10-0

8852

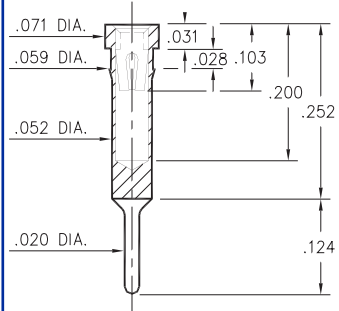

8852-0-15-XX-30-XX-04-0
Press-fit in .056 mounting hole

8363

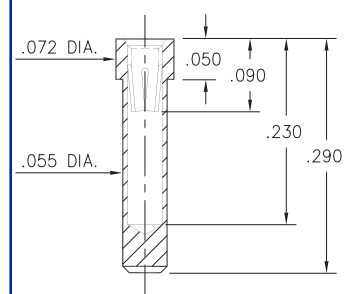

8363-0-15-XX-35-XX-10-0
Solder mount in .057 min. mounting hole

SPECIFICATIONS

SHELL MATERIAL:
Brass Alloy 360, 1/2 Hard

CONTACT MATERIAL:
Beryllium Copper Alloy 172, HT

DIMENSION IN INCHES
TOLERANCES ON:
LENGTHS: ±.005
DIAMETERS: ±.002
ANGLES: ± 2°

ORDER CODE: XXXX - X - XX - XX - XX - XX - 0

BASIC PART # →
SPECIFY SHELL FINISH: →
01 200μ" TIN/LEAD OVER NICKEL
15 10μ" GOLD OVER NICKEL

SPECIFY CONTACT FINISH: →
02 200μ" TIN/LEAD OVER NICKEL
14 10μ" GOLD OVER NICKEL
27 30μ" GOLD OVER NICKEL

SELECT CONTACT

#30, #35 or #43 CONTACT (DATA ON PAGES 208 & 209)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Mill-Max:

[3185-0-15-01-30-14-10-0](#) [3018-0-15-01-30-14-04-0](#) [1385-0-15-01-43-14-10-0](#) [1401-0-15-01-30-14-10-0](#) [1401-0-15-15-30-14-10-0](#) [8363-0-15-01-35-14-10-0](#)