



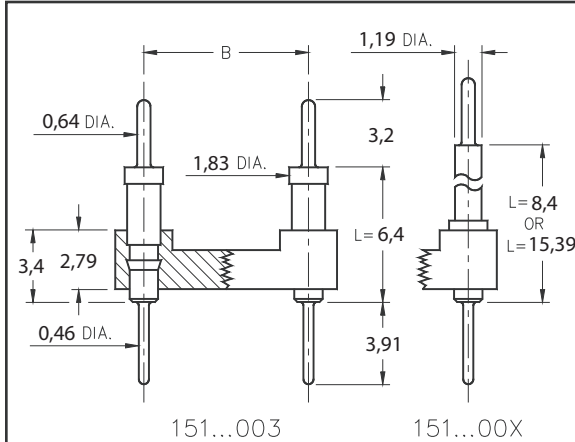

- Combine 0,64 dia. tails with pluggable 0,46 dia. solder tails.
- Series:
151...003 uses pin# 5503
151...004 uses pin# 5504
151...005 uses pin# 5505
For pin details see page 172.
- Pin material: Brass alloy 360 1/2 hard.

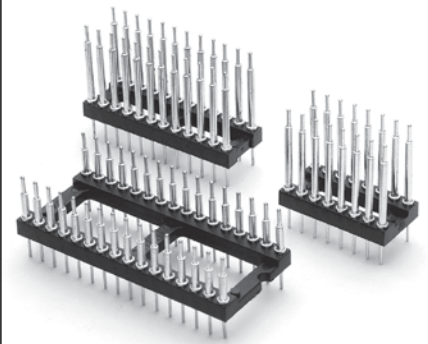

Total number of pins				Quantity per tube	Ordering Information <i>XX=Plating Code See Below</i> <i>For RoHS compliance, select plating code. For the gold option (XX=10) also change part number from 151-XX-XXX-00-00XQ00 to 151-10-XXX-00-00X100</i>			
	A	B	C		L = 6,4	L = 8,4	L = 15,39	
10	12,6	5,08	7,6	41	151-XX-210-00-003000	151-XX-210-00-004000	151-XX-210-00-005000	
4	5,0	7,62	10,1	102	151-XX-304-00-003000	151-XX-304-00-004000	151-XX-304-00-005000	
6	7,6	7,62	10,1	67	151-XX-306-00-003000	151-XX-306-00-004000	151-XX-306-00-005000	
8	10,1	7,62	10,1	50	151-XX-308-00-003000	151-XX-308-00-004000	151-XX-308-00-005000	
10	12,6	7,62	10,1	40	151-XX-310-00-003000	151-XX-310-00-004000	151-XX-310-00-005000	
14	17,7	7,62	10,1	28	151-XX-314-00-003000	151-XX-314-00-004000	151-XX-314-00-005000	
16	20,3	7,62	10,1	25	151-XX-316-00-003000	151-XX-316-00-004000	151-XX-316-00-005000	
18	22,8	7,62	10,1	22	151-XX-318-00-003000	151-XX-318-00-004000	151-XX-318-00-005000	
20	25,3	7,62	10,1	20	151-XX-320-00-003000	151-XX-320-00-004000	151-XX-320-00-005000	
22	27,8	7,62	10,1	18	151-XX-322-00-003000	151-XX-322-00-004000	151-XX-322-00-005000	
24	30,4	7,62	10,1	16	151-XX-324-00-003000	151-XX-324-00-004000	151-XX-324-00-005000	
28	35,5	7,62	10,1	14	151-XX-328-00-003000	151-XX-328-00-004000	151-XX-328-00-005000	
20	25,4	10,16	12,7	20	151-XX-420-00-003000	151-XX-420-00-004000	151-XX-420-00-005000	
22	27,8	10,16	12,7	18	151-XX-422-00-003000	151-XX-422-00-004000	151-XX-422-00-005000	
24	30,4	10,16	12,7	16	151-XX-424-00-003000	151-XX-424-00-004000	151-XX-424-00-005000	
28	35,5	10,16	12,7	14	151-XX-428-00-003000	151-XX-428-00-004000	151-XX-428-00-005000	
32	40,6	10,16	12,7	12	151-XX-432-00-003000	151-XX-432-00-004000	151-XX-432-00-005000	
24	30,5	15,24	17,7	16	151-XX-624-00-003000	151-XX-624-00-004000	151-XX-624-00-005000	
28	35,5	15,24	17,7	14	151-XX-628-00-003000	151-XX-628-00-004000	151-XX-628-00-005000	
32	40,6	15,24	17,7	12	151-XX-632-00-003000	151-XX-632-00-004000	151-XX-632-00-005000	
36	45,7	15,24	17,7	11	151-XX-636-00-003000	151-XX-636-00-004000	151-XX-636-00-005000	
40	50,8	15,24	17,7	10	151-XX-640-00-003000	151-XX-640-00-004000	151-XX-640-00-005000	
42	53,3	15,24	17,7	9	151-XX-642-00-003000	151-XX-642-00-004000	151-XX-642-00-005000	
48	60,9	15,24	17,7	8	151-XX-648-00-003000	151-XX-648-00-004000	151-XX-648-00-005000	
50	63,5	15,24	17,7	8	151-XX-650-00-003000	151-XX-650-00-004000	151-XX-650-00-005000	
52	66,0	15,24	17,7	7	151-XX-652-00-003000	151-XX-652-00-004000	151-XX-652-00-005000	
50	63,5	22,86	25,3	8	151-XX-950-00-003000	151-XX-950-00-004000	151-XX-950-00-005000	
52	66,0	22,86	25,3	7	151-XX-952-00-003000	151-XX-952-00-004000	151-XX-952-00-005000	
64	81,2	22,86	25,3	6	151-XX-964-00-003000	151-XX-964-00-004000	151-XX-964-00-005000	
SPECIFY PLATING CODE XX=					10	90	40	
Pin Plating					0,25µm Au	5,08µm Sn/Pb	5,08µm Sn	

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Mill-Max:

[151-90-314-00-005000](#)