

INTERCONNECTS

SERIES 321, 322, 323, 324 • 2,54 GRID WRAPOST • SINGLE ROW STRIPS

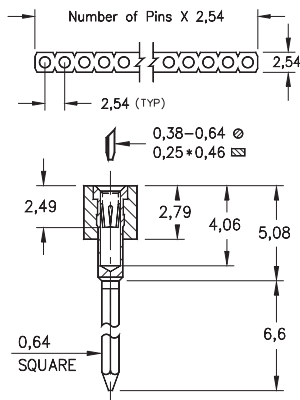


FIG. 1

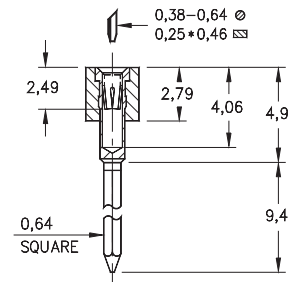


FIG. 2

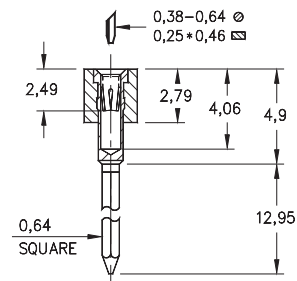


FIG. 3


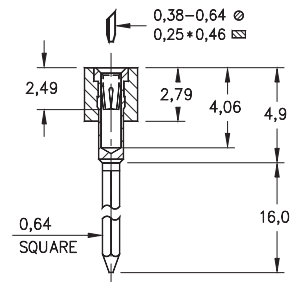


FIG. 4

- Wraposts available in 1 - 4 levels using MM pin numbers:

1-Level uses pin # 0040-1
2-Level uses pin # 0089-2
3-Level uses pin # 0088-3
4-Level uses pin # 0086-4
See page 198 for details

- Hi-Rel, 4-finger BeCu #30 contact is rated at 3 amps. See page 253 for details
- Insulators are high temperature thermoplastic, suitable for all soldering operations

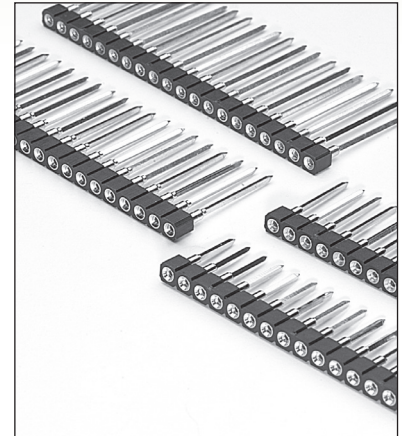

ORDERING INFORMATION

FIG. 1	Series 321...001	1 Level Wrapost
	321-13-1	-41-001000 Specify number of pins 01-64
FIG. 2	Series 322...001	2 Level Wrapost
	322-XX-1	-41-001000 Specify number of pins 01-64
FIG. 3	Series 323...001	3 Level Wrapost
	323-XX-1	-41-001000 Specify number of pins 01-64
FIG. 4	Series 324...002	4 Level Wrapost
	324-XX-1	-41-002000 Specify number of pins 01-64



XX=Plating Code
See Below

For
Electrical, Mechanical
& Environmental Data,
See page 264

SPECIFY PLATING CODE XX=	11	13	91	93	41	43	
Sleeve (Pin)	0,25µm Au	0,25µm Au	5,08µm Sn/Pb	5,08µm Sn/Pb	5,08µm Sn	5,08µm Sn	
Contact (Clip)	0,25µm Au	0,76µm Au	0,25µm Au	0,76µm Au	0,25µm Au	0,76µm Au	



Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Mill-Max:

[324-93-164-41-002000](#) [324-93-132-41-002000](#) [324-93-120-41-002000](#) [322-93-164-41-001000](#) [321-13-164-41-001000](#) [322-93-120-41-001000](#) [324-93-138-41-002000](#) [322-93-161-41-001000](#) [324-93-127-41-002000](#) [322-93-154-41-001000](#) [324-93-106-41-002000](#) [324-93-116-41-002000](#) [322-93-144-41-001000](#) [324-93-158-41-002000](#) [324-93-148-41-002000](#) [322-93-123-41-001000](#) [322-41-109-41-001000](#) [322-93-134-41-001000](#) [322-93-116-41-001000](#) [324-93-141-41-002000](#) [324-93-119-41-002000](#) [322-93-151-41-001000](#) [324-93-151-41-002000](#) [322-93-118-41-001000](#) [322-93-130-41-001000](#) [324-93-139-41-002000](#) [322-93-141-41-001000](#) [322-93-150-41-001000](#) [322-93-119-41-001000](#) [324-93-130-41-002000](#) [324-93-152-41-002000](#) [324-93-107-41-002000](#) [324-93-113-41-002000](#) [322-93-126-41-001000](#) [324-93-121-41-002000](#) [322-93-137-41-001000](#) [322-93-127-41-001000](#) [324-93-128-41-002000](#) [324-93-131-41-002000](#) [322-93-143-41-001000](#) [322-93-140-41-001000](#) [324-93-145-41-002000](#) [324-93-117-41-002000](#) [322-93-115-41-001000](#) [322-93-129-41-001000](#) [324-93-155-41-002000](#) [324-93-110-41-002000](#) [324-93-143-41-002000](#) [324-93-153-41-002000](#) [324-93-111-41-002000](#) [322-93-117-41-001000](#) [322-93-147-41-001000](#) [324-93-135-41-002000](#) [324-93-125-41-002000](#) [322-93-163-41-001000](#) [322-93-122-41-001000](#) [324-93-163-41-002000](#) [324-93-156-41-002000](#) [324-93-137-41-002000](#) [322-93-162-41-001000](#) [322-93-155-41-001000](#) [322-91-127-41-001000](#) [322-93-128-41-001000](#) [324-93-118-41-002000](#) [324-93-122-41-002000](#) [324-93-159-41-002000](#) [322-93-152-41-001000](#) [322-93-121-41-001000](#) [324-93-157-41-002000](#) [322-93-142-41-001000](#) [322-93-160-41-001000](#) [324-93-146-41-002000](#) [322-93-145-41-001000](#) [324-93-149-41-002000](#) [324-93-147-41-002000](#) [322-93-124-41-001000](#) [322-93-125-41-001000](#) [324-93-144-41-002000](#) [322-93-136-41-001000](#) [322-93-135-41-001000](#) [324-93-108-41-002000](#) [324-93-129-41-002000](#) [324-93-123-41-002000](#) [324-93-160-41-002000](#) [322-41-110-41-001000](#) [324-93-126-41-002000](#) [322-93-131-41-001000](#) [324-93-150-41-002000](#) [322-93-138-41-001000](#) [322-93-148-41-001000](#) [324-93-109-41-002000](#) [324-93-161-41-002000](#) [322-93-158-41-001000](#) [324-93-154-41-002000](#) [322-93-153-41-001000](#) [324-93-162-41-002000](#) [322-41-108-41-001000](#) [324-93-142-41-002000](#) [322-93-157-41-001000](#) [324-93-124-41-002000](#)