

INTERCONNECTS

SERIES 714...01X • 2,54 GRID ULTRA LOW PROFILE CARRIERS • SINGLE AND DOUBLE ROW STRIPS

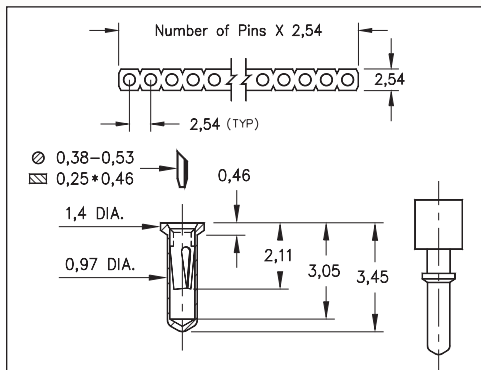


FIG. 1

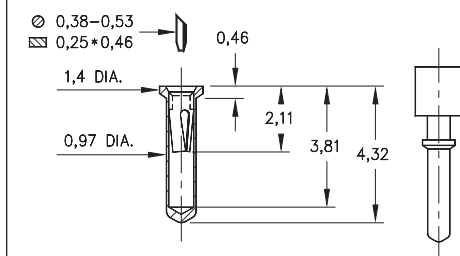


FIG. 2

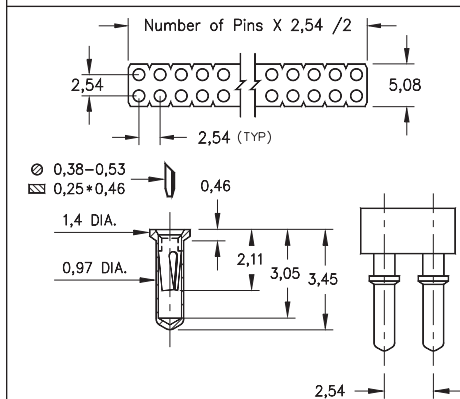


FIG. 3


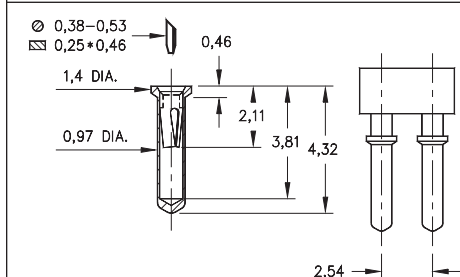


FIG. 4

- Ultra low profile receptacles sit 0,46 above the board
- Series 714 use MM #0552-1 and MM #0552-2 pin receptacles. See page 158 for details
- Hi-Rel, 3-finger BeCu #11 contact is rated at 3 amps. See page 251 for details
- Insulators are high temperature thermoplastic, suitable for all soldering operations

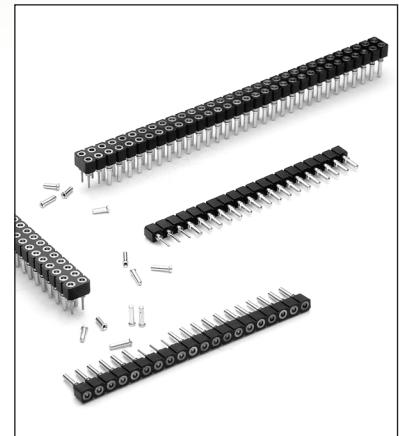

ORDERING INFORMATION

FIG. 1	Single Row (0,99 min. mounting hole)	
	714-XX-1	-31-012000
	Specify number of pins	01-64
FIG. 2	Single Row (0,99 min. mounting hole)	
	714-XX-1	-31-018000
	Specify number of pins	01-64
FIG. 3	Double Row (0,99 min. mounting hole)	
	714-XX-2	-31-012000
	Specify number of pins	04-64
FIG. 4	Double Row (0,99 min. mounting hole)	
	714-XX-2	-31-018000
	Specify number of pins	04-64
RoHS-2 2011/65/EU XX=Plating Code See Below For Electrical, Mechanical & Environmental Data, See page 264		
SPECIFY PLATING CODE XX=		
Sleeve (Pin)	91	93
Contact (Clip)	41	43
	5,08µm Sn/Pb	5,08µm Sn
	0,25µm Au	0,76µm Au
	0,25µm Au	0,76µm Au

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Mill-Max:

[714-93-264-31-018000](#) [714-93-264-31-012000](#) [714-93-132-31-018000](#) [714-93-132-31-012000](#) [714-93-120-31-018000](#) [714-93-120-31-012000](#) [714-93-107-31-012000](#) [714-93-164-31-018000](#) [714-93-164-31-012000](#) [714-93-103-31-018000](#) [714-43-264-31-018000](#) [714-43-264-31-012000](#) [714-43-164-31-018000](#) [714-43-164-31-012000](#) [714-43-132-31-018000](#) [714-43-132-31-012000](#) [714-43-120-31-018000](#) [714-43-120-31-012000](#) [714-43-214-31-018000](#) [714-43-206-31-018000](#) [714-43-146-31-018000](#) [714-43-234-31-018000](#) [714-43-101-31-018000](#) [714-43-208-31-018000](#) [714-41-102-31-012000](#) [714-41-108-31-012000](#) [714-41-124-31-018000](#) [714-41-116-31-012000](#) [714-43-106-31-018000](#) [714-43-109-31-012000](#) [714-43-111-31-012000](#) [714-43-104-31-018000](#) [714-43-114-31-018000](#) [714-43-125-31-018000](#) [714-43-109-31-018000](#) [714-43-110-31-018000](#) [714-91-120-31-012000](#) [714-91-240-31-012000](#) [714-91-230-31-012000](#) [714-91-236-31-012000](#) [714-93-115-31-012000](#) [714-93-123-31-018000](#) [714-93-204-31-018000](#) [714-93-220-31-012000](#)