


PIN RECEPTACLES

**FOR 0,38 - 0,51 DIAMETER PINS (#11 CONTACT)
AND 0,38 - 0,56 DIAMETER PINS (#21 CONTACT)
(SEE SPECIFIC CONTACT RANGE ON PAGE 251)**

0548

0548-0-15-XX-21-XX-10-0


Solder mount in 0,91 min. mounting hole

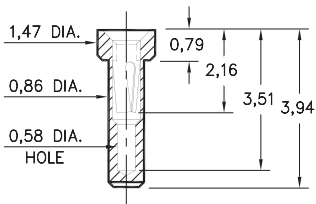

8975

8975-0-15-XX-21-XX-10-0


Solder mount in 0,91 min. mounting hole

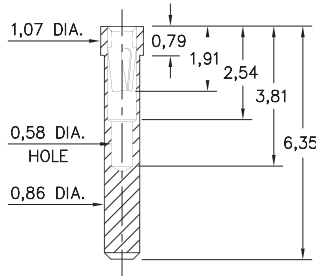

3016

3016-0-15-XX-21-XX-10-0


Solder mount in 0,91 min. mounting hole

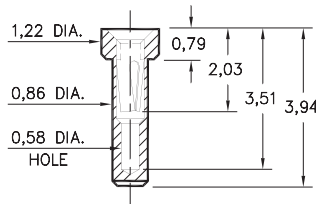

9548

9548-0-15-XX-21-XX-10-0


Solder mount in 0,91 min. mounting hole

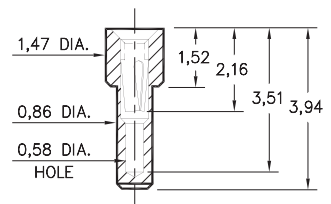

8637

8637-0-15-XX-21-XX-10-0


Solder mount in 0,94 min. mounting hole

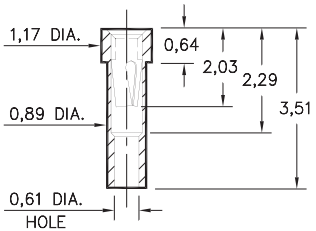

1407

1407-0-15-XX-11-XX-10-0


Solder mount in 1,02 min. mounting hole

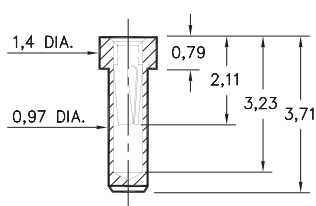

0553/8553

X553-X-15-XX-X1-XX-10-0

Hex press-fit in 1,04 plated through-hole

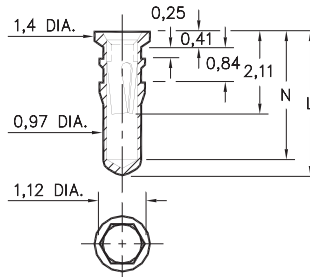


Basic Part Number	Length L	Depth N
0553-1	3,56	3,15
0553-2	4,32	3,91
0553-3	7,16	6,76
8553-0	6,22	5,82

0566

0566-X-15-XX-21-XX-10-0

Solder mount in 1,0 min. mounting hole

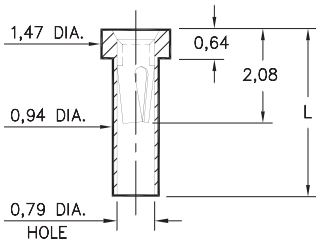


Basic Part Number	Length L
0566-1	2,11
0566-2	3,51

0442

0442-0-15-XX-11-XX-10-0


Solder mount in 1,02 min. mounting hole

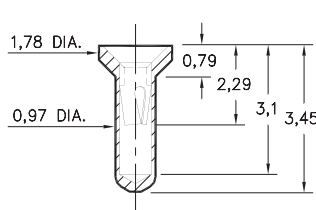

0554

0554-0-15-XX-21-XX-10-0

Solder mount in 1,02 min. mounting hole

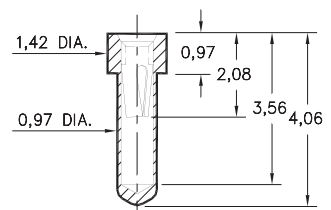

SPECIFICATIONS:

Shell Material: Brass Alloy 360, 1/2 Hard

Contact Material: Beryllium Copper Alloy 172, HT

Dimensions: Millimeters

Tolerances On: Lengths: $\pm 0,13$
Diameters: $\pm 0,051$
Angles: $\pm 2^\circ$

RoHS-2
2011/65/EU

ORDER CODE: XXXX - X - 15 - XX - XX - 10 - 0

BASIC PART #

SPECIFY SHELL FINISH:

- 01** 5,08 μ m TIN/LEAD OVER NICKEL
- ◆ **80** 5,08 μ m TIN OVER NICKEL (RoHS)
- ◆ **15** 0,25 μ m GOLD OVER NICKEL (RoHS)

SPECIFY CONTACT FINISH:

- 02** 2,54 μ m TIN/LEAD OVER NICKEL
- ◆ **84** 2,54 μ m TIN OVER NICKEL (RoHS)
- ◆ **27** 0,76 μ m GOLD OVER NICKEL (RoHS)

SELECT CONTACT:

#11 or #21 CONTACT (DATA ON PAGE 251)

(For alternate contact choices, see group A on page 248)



Mill-Max Mfg. Corp. • 190 Pine Hollow Road, P.O. Box 300, Oyster Bay, NY 11771 • 516-922-6000 • Fax: 516-922-9253 • www.mill-max.com

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Mill-Max:

[0566-2-15-80-21-84-10-0](#) [0553-3-15-80-21-27-10-0](#) [0553-3-15-80-11-84-10-0](#) [0553-3-15-80-11-27-10-0](#) [0553-2-15-80-21-84-10-0](#) [0553-2-15-80-21-27-10-0](#) [0553-2-15-80-11-27-10-0](#) [0553-1-15-80-21-84-10-0](#) [0442-0-15-80-11-27-10-0](#) [1407-0-15-15-11-27-10-0](#) [0553-2-15-01-21-27-10-0](#) [0553-3-15-01-21-02-10-0](#) [0553-2-15-01-21-02-10-0](#) [0553-1-15-01-21-02-10-0](#) [0442-0-15-01-11-27-10-0](#) [8553-0-15-80-11-84-10-0](#) [1407-0-15-80-11-27-10-0](#) [0442-0-15-15-11-27-10-0](#)