


PIN RECEPTACLES

FOR 0,81 - 1,17 DIAMETER PINS

0359

0359-0-15-XX-34-XX-10-0


Press-fit in 2,29 mounting hole

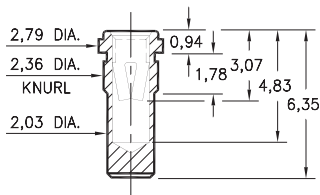

0358

0358-0-15-XX-34-XX-10-0


Press-fit in 2,29 mounting hole

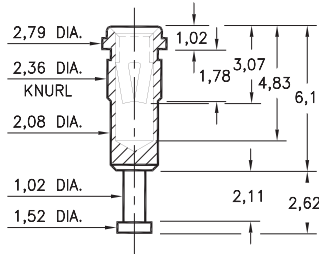

0360

0360-0-15-XX-34-XX-10-0


Press-fit in 2,29 mounting hole

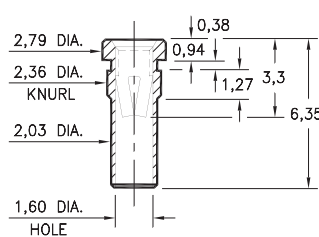

0343

0343-0-15-XX-34-XX-10-0


Press-fit in 2,29 mounting hole

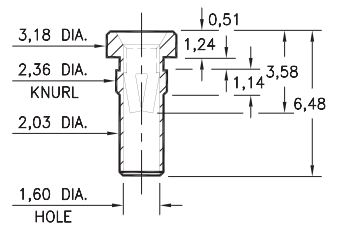

0356

0356-0-15-XX-34-XX-10-0


Solder mount in 2,59 min. mounting hole
Also available on 24mm wide carrier tape:
1,100 parts per 330mm reel
Order as: 0356-0-57-XX-34-XX-10-0

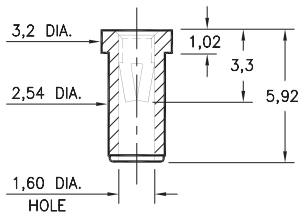

6659

6659-0-15-XX-34-XX-10-0


Solder mount in 2,59 min. mounting hole

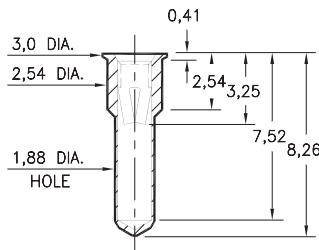

0347

0347-0-15-XX-34-XX-10-0


Solder mount in 3,05 min. mounting hole

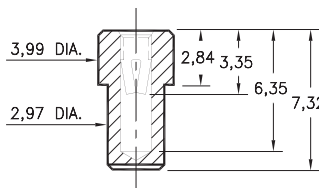

0329

0329-0-15-XX-34-XX-10-0


Solder mount in 1,91 min. mounting hole. "Knock out" bottom

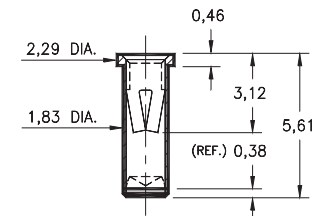

0814

0814-0-15-XX-34-XX-04-0


Solder mount in 2,08 min. mounting hole

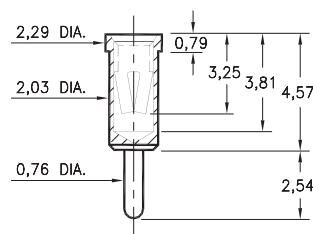

5059

5059-0-15-XX-34-XX-04-0


Press-fit in 2,29 mounting hole

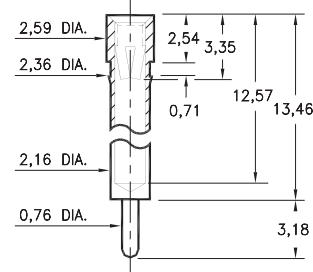

8360

8360-0-15-XX-34-XX-10-0


Press-fit in 2,21 mounting hole

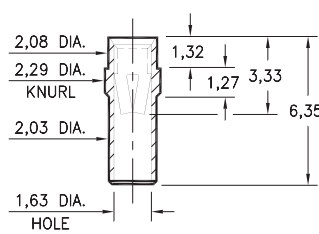

9359

9359-0-15-XX-34-XX-10-0

Press-fit in 2,29 mounting hole

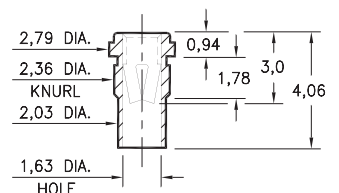

SPECIFICATIONS:

Shell Material: Brass Alloy 360, 1/2 Hard

Contact Material: Beryllium Copper Alloy 172, HT

Dimensions: Millimeters

Tolerances On: Lengths: $\pm 0,13$
Diameters: $\pm 0,051$
Angles: $\pm 2^\circ$



ORDER CODE: XXXX - X - 15 - XX - 34 - XX - XX - 0

BASIC PART #

SPECIFY SHELL FINISH:

- 01 5,08µm TIN/LEAD OVER NICKEL
- ◆ 80 5,08µm TIN OVER NICKEL (RoHS)
- ◆ 15 0,25µm GOLD OVER NICKEL (RoHS)

SPECIFY CONTACT FINISH:

- 01 5,08µm TIN/LEAD OVER NICKEL
- ◆ 80 5,08µm TIN OVER NICKEL (RoHS)
- ◆ 27 0,76µm GOLD OVER NICKEL (RoHS)

SELECT CONTACT:

#34 CONTACT (DATA ON PAGE 258)

(For alternate contact choices, see group E on page 248)



Mill-Max Mfg. Corp. • 190 Pine Hollow Road, P.O. Box 300, Oyster Bay, NY 11771 • 516-922-6000 • Fax: 516-922-9253 • www.mill-max.com

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Mill-Max:

[6659-0-15-01-34-01-10-0](#) [6659-0-15-01-34-27-10-0](#) [0358-0-15-80-34-80-10-0](#) [0356-0-15-80-34-27-10-0](#) [0347-0-15-80-34-27-10-0](#) [0347-0-15-01-34-27-10-0](#) [8360-0-15-80-34-27-10-0](#) [6659-0-15-80-34-27-10-0](#) [0343-0-15-15-34-27-10-0](#)