


PIN RECEPTACLES

FOR 1,02 - 1,27 DIAMETER PINS

0355

0355-0-15-XX-02-XX-10-0


Solder mount in 2,59 min. mounting hole

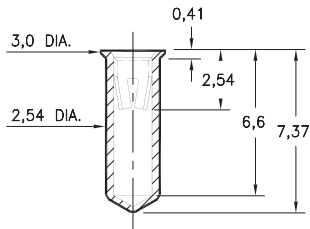

0354

0354-0-15-XX-02-XX-10-0


Pentagonal press-fit in 2,64 min. plated through-hole

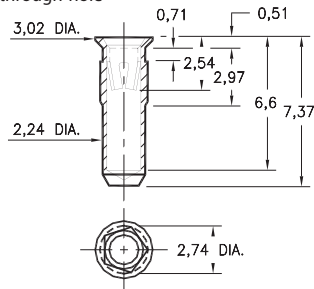

3490

3490-0-15-XX-02-XX-10-0


Press-fit in 2,31 mounting hole

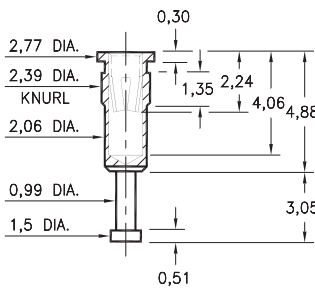

3808

3808-0-15-XX-02-XX-10-0


Press-fit in 2,29 mounting hole

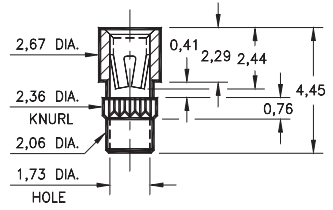

9184

9184-0-15-XX-02-XX-40-0


Bottom entry, surface mount
2,34 min. plated through-hole
Also available on carrier tape,
Order as: 9184-0-57-XX-02-XX-40-0

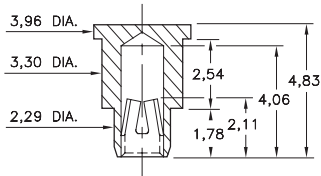

9222


9222-2-15-XX-02-XX-40-0

Bottom entry, surface mount
2,08 min. plated through-hole
Also available on carrier tape,
Order as: 9222-2-57-XX-02-XX-40-0

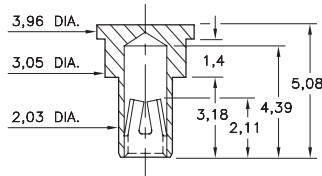

Carrier tape format for
9184 and 9222.

1,500 pieces per 330mm reel

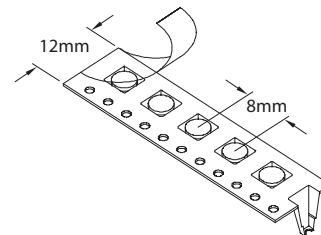

SPECIFICATIONS:

Shell Material: Brass Alloy 360, 1/2 Hard

Contact Material: Beryllium Copper Alloy 172, HT

Dimensions: Millimeters

Tolerances On: Lengths: $\pm 0,13$

Diameters: $\pm 0,051$

Angles: $\pm 2^\circ$



ORDER CODE: XXXX - X - 15 - XX - 02 - XX - XX - 0

BASIC PART #

SPECIFY SHELL FINISH:

- 01 5,08μm TIN/LEAD OVER NICKEL
- ◆ 80 5,08μm TIN OVER NICKEL (RoHS)
- ◆ 15 0,25μm GOLD OVER NICKEL (RoHS)

SPECIFY CONTACT FINISH:

- 01 5,08μm TIN/LEAD OVER NICKEL
- ◆ 80 5,08μm TIN OVER NICKEL (RoHS)
- ◆ 27 0,76μm GOLD OVER NICKEL (RoHS)

SELECT CONTACT:

#02 CONTACT (DATA ON PAGE 259)

(For alternate contact choices, see group F on page 248)



Mill-Max Mfg. Corp. • 190 Pine Hollow Road, P.O. Box 300, Oyster Bay, NY 11771 • 516-922-6000 • Fax: 516-922-9253 • www.mill-max.com

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Mill-Max:

[0354-0-15-80-02-27-10-0](#) [3808-0-15-80-02-27-10-0](#)