


# PIN RECEPTACLES

FOR .015" - .025" DIAMETER PINS

## 0669

0669-0-15-XX-30-XX-10-0


Solder mount in .060 min. mounting hole  
Also available on 16mm wide carrier tape:  
1,700 parts per 13" reel  
Order as: 0669-0-57-XX-30-XX-10-0

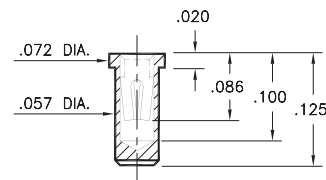

## 0670

0670-0-15-XX-30-XX-10-0


Solder mount in .060 min. mounting hole  
Also available on 16mm wide carrier tape:  
2,000 parts per 13" reel  
Order as: 0670-0-57-XX-30-XX-10-0

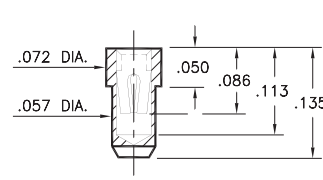

## 0673

0673-0-15-XX-30-XX-10-0


Surface mount

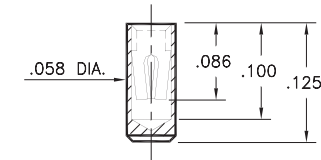

## 0666

0666-0-15-XX-32-XX-10-0


Solder mount in .064 min. mounting hole  
Also available on 16mm wide carrier tape:  
2,000 parts per 13" reel  
Order as: 0666-0-57-XX-32-XX-10-0

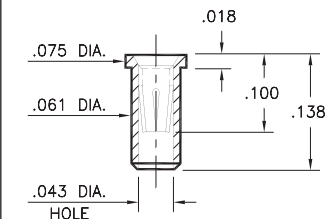

## 0341

0341-0-15-XX-30-XX-10-0


Solder mount in .073 mounting hole  
Also available on 12mm wide carrier tape:  
1,400 parts per 13" reel  
Order as: 0341-0-57-XX-30-XX-10-0

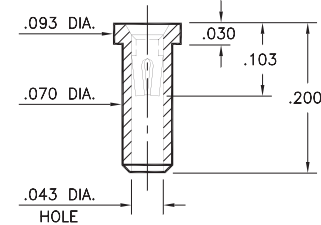

## 0252

0252-0-15-XX-32-XX-10-0


Hex press-fit in .057 plated through-hole

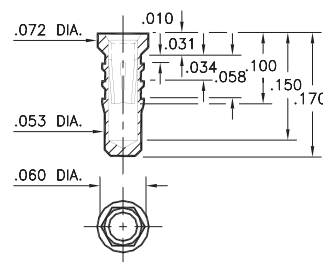

## 0678

0678-0-15-XX-32-XX-10-0


Press-fit in .057 mounting hole

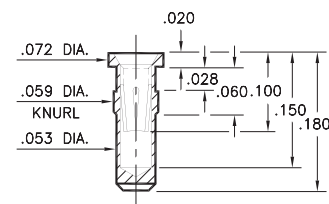

## 0676

0676-0-15-XX-30-XX-10-0


Press-fit in .057 mounting hole

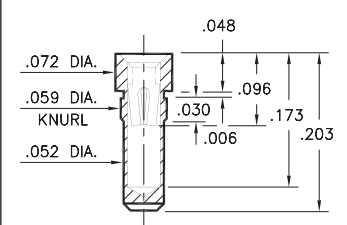

## 0697

0697-0-15-XX-30-XX-10-0


Press-fit in .057 mounting hole

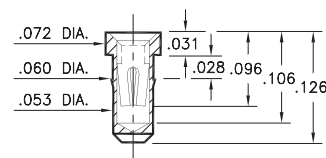

## 0668

0668-0-15-XX-30-XX-10-0


Press-fit in .057 mounting hole

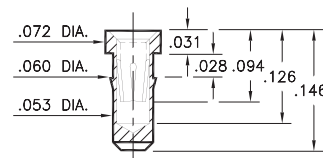

## 0253/1033

XXX3-0-15-XX-30-XX-10-0

Press-fit in .057 mounting hole

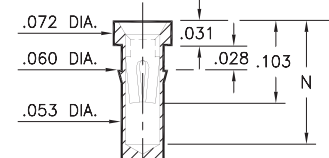

| Basic Part Number | Length L | Depth N |
|-------------------|----------|---------|
| 0253-0            | .173     | .148    |
| 1033-0            | .203     | .162    |

### SPECIFICATIONS:

Shell Material: Brass Alloy 360, 1/2 Hard

Contact Material: Beryllium Copper Alloy 172, HT

Dimensions: Inches

Tolerances On: Lengths:  $\pm .005$

Diameters:  $\pm .002$

Angles:  $\pm 2^\circ$



ORDER CODE: XXXX - X - XX - XX - XX - 10 - 0

BASIC PART #

SPECIFY SHELL FINISH:

01 200  $\mu$ " TIN/LEAD OVER NICKEL

◆ 80 200  $\mu$ " TIN OVER NICKEL (RoHS)

◆ 15 10  $\mu$ " GOLD OVER NICKEL (RoHS)

SPECIFY CONTACT FINISH:

02 100  $\mu$ " TIN/LEAD OVER NICKEL

◆ 84 100  $\mu$ " TIN OVER NICKEL (RoHS)

◆ 27 30  $\mu$ " GOLD OVER NICKEL (RoHS)

SELECT CONTACT:

#30 or #32 CONTACT (DATA ON PAGE 253)

(For alternate contact choices, see groups B and C on page 248)



Mill-Max Mfg. Corp. • 190 Pine Hollow Road, P.O. Box 300, Oyster Bay, NY 11771 • 516-922-6000 • Fax: 516-922-9253 • www.mill-max.com

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Mill-Max:

[0673-0-15-80-30-27-10-0](#) [0670-0-15-80-30-84-10-0](#) [0669-0-15-80-30-84-10-0](#) [0669-0-15-80-30-27-10-0](#) [0341-0-15-80-30-84-10-0](#)