




PRODUCT NUMBER: 1618-1-57-15-00-00-03-0

1618-X-XX-15-00-00-03-0

Low profile Target Discs, surface mount

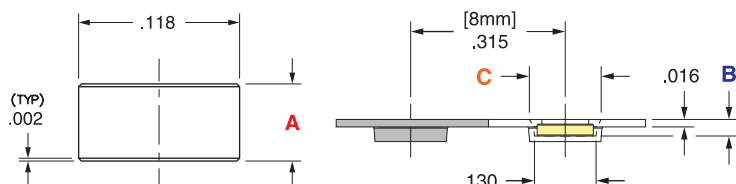

Contact Style	Target Disc Height (A)	Tape Pocket Depth (B)	Tape Pocket Opening (C)	Quantity per Reel
0	.025	.035	.151	7,200
1	.035	.045	.151	6,000
2	.045	.055	.151	5,125
3	.055	.065	.151	4,000
4	.065	.075	.152	3,850

DESCRIPTION

Spring-Loaded Target Contact with Flat Face

Current Rating:

Application Specific

Operating Temperature Range:

-55/+125° C (discontinuous)

Mounting Feature:

Surface Mount

Packaging: 57 - Vertically on Tape & Reel

Shell Plating

10 µ" Gold over Nickel

Contact Plating

ROHS



ADDITIONAL NOTES & SPECIFICATIONS

In the interest of improved design, quality and performance, Mill-Max reserves the right to make changes in its specifications without prior notice. Specifications and tolerances are provided wherever possible. Due to the wide variety of interconnects Mill-Max offers, the specific tolerances vary from product to product. If you need information regarding the tolerance of a particular part, please contact Technical Services.

© 2020 Mill-Max Mfg. Corp.

190 Pine Hollow Rd , Oyster Bay, NY 11771, USA

Phone: 516.922.6000

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Mill-Max:

1618-1-57-15-00-00-03-0